

Cable, Cord and Hose Reels



Features and Benefits

Commercial Cord Reels

- Durable steel construction for commercial and general purpose applications
- Compact size, flexible mounting options for ceiling, wall or bench
- Automatic ratchet lock holds cord at desired length and provides easy, smooth retraction of cord
- Attached plug for power cord requires no wiring



Commercial Cord Reels

- Durable light weight non-metallic housing
- Removable bracket allows reel to be dis-engaged from mount providing portability
- 40 Ft. of #12/3 cord for greater current carrying capacity
- Triple tap outlet with supplemental over current protection

Commercial Cord Reels

Description	Amps	Volts AC	Cable Length Feet (m)	Cable Type	Watts (Max)	Weight Lbs. (kg)	Catalog Number
Black Reel with triple tap outlet.	15	125	40 (12.2)	#12/3 SJTW	1,875	13.8 (6.3)	HBLC40123TT
Black Reel with wire leads.	15	125	40 (12.2)	#12/3 SJTW	1,875	13.8 (6.3)	HBLC40123
White Reel with triple tap outlet and white cord.	10	125	30 (9.1)	#16/3 SJT	1,250	8.5 (3.9)	HBLC30163TT
White Reel with single connector and white cord.	15	125	20 (6.1)	#14/3 SJT	1,875	8.5 (3.9)	HBLC20143C
Yellow Reel with Hubbell HBL5969VBLK connector.	10	125	25 (7.6)	#16/3 SJT	1,250	8.5 (3.9)	HBLC25163C
Yellow Reel with wire leads.	10	125	25 (7.6)	#16/3 SJT	1,250	8.5 (3.9)	HBLC25163**


Note: Reels supplied with 2 ft. power supply cord and molded on straight blade 15A plug.

**UL Listed only.

Specifications

Listing/Certification	UL 355.
Environment	Dry, indoor, non-hazardous locations.
Incandescent Lamp	75 watt max., auto switch, no receptacle; 100 watt max. bulb, with receptacle.
Fluorescent Lamp	10A/1200W max. with in-line receptacle; 13 watt without receptacle.

Dimensions

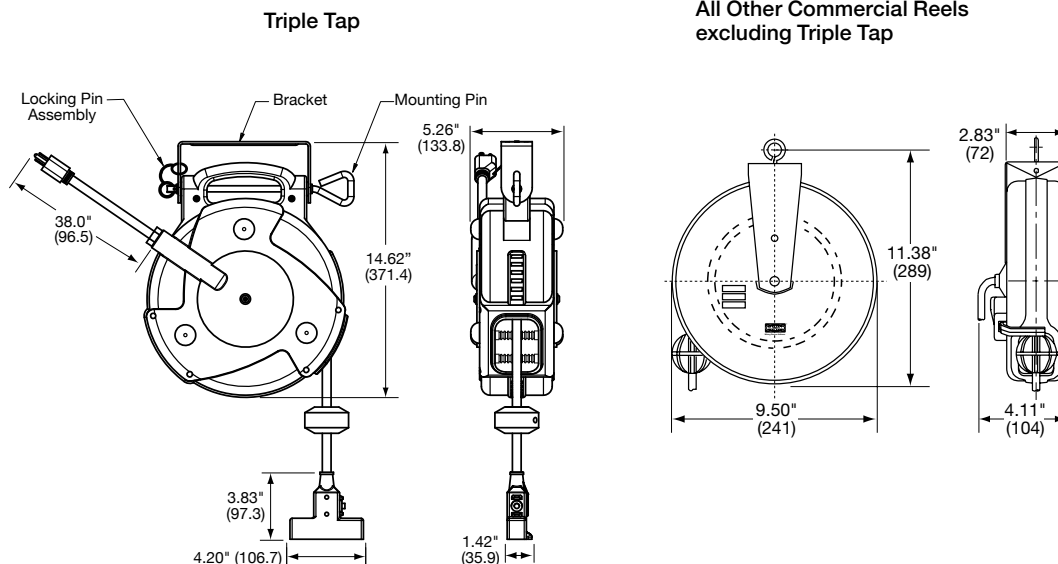

HBLC40123TT



HBLC30163TT



HBLC20143C



HBLC25163C

Dimensions in Inches (mm)