


## Features and Benefits

### Heavy Duty Commercial Standard Hospital Grade GFCI Receptacles

- Fed. Spec UL Listed, Hospital Grade
- Green power indicator and red trip indicator
- Patented AUTOGUARD® self test technology
- Flush, nylon face, back and side wired, multiple drive screws, self-grounding staple

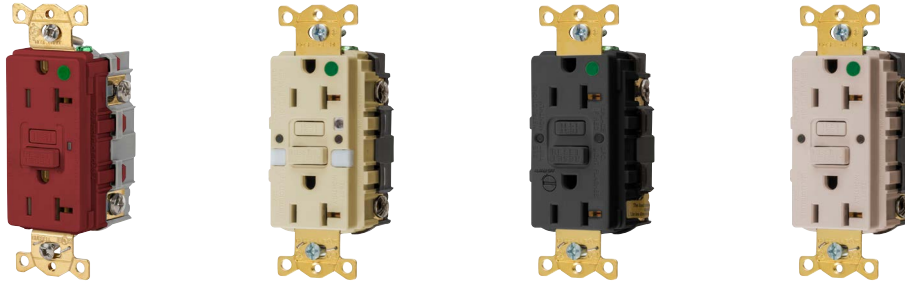

### Hospital Grade ●

Rating	Color	Standard	Night Light Two LED Night Lights	Alarm	Assembled in USA
	Black	GFR82BLK	GFRST82BKNL	GFRST82BKB	GFRST82BKU
	Brown	GFR82	GFRST82NL	GFRST82B	GFRST82U
	Gray	GFR82GRY	GFRST82GYNL	GFRST82GYB	GFRST82GYU
	Ivory	GFR82I	GFRST82INL	GFRST82IB	GFRST82IU
	Light Almond	GFR82LA	GFRST82LANL	GFRST82LAB	GFRST82LAU
	Red	GFR82R	GFRST82RNL	GFRST82RB	GFRST82RU
	White	GFR82W	GFRST82WNL	GFRST82WB	GFRST82WU
	Black	GFR83BLK	GFRST83BKNL	GFRST83BKB	GFRST83BKU
	Brown	GFR83	GFRST83NL	GFRST83B	GFRST83U
	Gray	GFR83GRY	GFRST83GYNL	GFRST83GYB	GFRST83GYU
	Ivory	GFR83I	GFRST83INL	GFRST83IB	GFRST83IU
	Light Almond	GFR83LA	GFRST83LANL	GFRST83LAB	GFRST83LAU
	Red	GFR83R	GFRST83RNL	GFRST83RB	GFRST83RU
	White	GFR83W	GFRST83WNL	GFRST83WB	GFRST83WU



### Hospital Grade ● SNAPConnect®

Rating	Color	Standard
	Black	—
	Brown	—
	Gray	—
	Ivory	SNAPGF82I
	Light Almond	SNAPGF82LA
	Red	SNAPGF82R
	White	SNAPGF82W
	Black	SNAPGF83BLK
	Brown	SNAPGF83
	Gray	SNAPGF83GRY
	Ivory	SNAPGF83I
	Light Almond	SNAPGF83LA
	Red	SNAPGF83R
	White	SNAPGF83W

### SNAPConnect® Right Angle Pigtailed Terminal

Description	Type	Catalog Number
Clear right angle terminal with 6 inch leads, 600V, #12 AWG THHN/THWN-2, Polycarbonate housing material.	Solid	SNAP1RA
	Stranded	SNAP2RA
Same as above. Assembled in USA.	Solid	SNAP1RNA
	Stranded	SNAP2RNA
Clear right angle terminal with 6 inch leads #12 AWG THHN/THWN-2; Polycarbonate housing material with WAGO terminals.	Solid	SNAP1RAM2
	Stranded	SNAP2RAM2
Same as above. Assembled in USA.	Solid	SNAP1RNAM2
	Stranded	SNAP2RNAM2

Note: GFCI type receptacles should not be used in critical care patient areas or for electrical life support equipment applications because of the possibility of power interruption. All GFCI receptacles are furnished with a matching color thermoplastic wallplate, 20 amp feed-through capability.