


## Features and Benefits

### Commercial Tamper-Resistant GFCI Receptacles

- Patented shutter design for tamper-resistant protection
- Compliant with NEC® 406.12 and NEC® 517-18(c)
- Patented AUTOGUARD® self test technology includes disconnecting power to the receptacle if critical components are damaged and GFCI protection is lost
- Alarm version provides audible notification of a trip condition

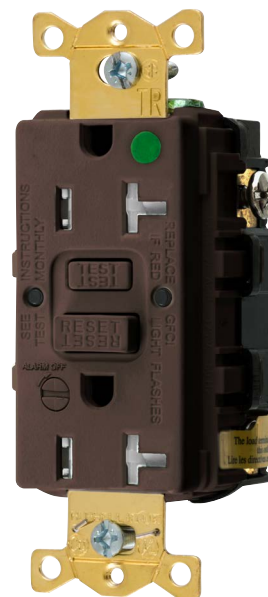

GFTRST83B



### Hospital Grade Tamper-Resistant GFCI Receptacles



Description	Rating	Color	Catalog Number	
Night Light Two LED Night Lights, Flush, nylon face, back and side wired, multiple drive screws, self-grounding staple.	15 and 20A 125V AC	Black	GFTRST82BKNL	GFTRST83BKNL
		Brown	GFTRST82NL	GFTRST83NL
		Gray	GFTRST82GYNL	GFTRST83GYNL
		Ivory	GFTRST82INL	GFTRST83INL
		Light Almond	GFTRST82LANL	GFTRST83LANL
		Red	GFTRST82RNL	GFTRST83RNL
		White	GFTRST82WNL	GFTRST83WNL
Alarm, Flush, nylon face, back and side wired, multiple drive screws, self-grounding staple.	15 and 20A 125V AC	Black	GFTRST82BKKB	GFTRST83BKKB
		Brown	GFTRST82B	GFTRST83B
		Gray	GFTRST82GYB	GFTRST83GYB
		Ivory	GFTRST82IB	GFTRST83IB
		Light Almond	GFTRST82LAB	GFTRST83LAB
		Red	GFTRST82RB	GFTRST83RB
		White	GFTRST82WB	GFTRST83WB



Note: GFCI type receptacles should not be used in critical care patient areas or for electrical life support equipment applications because of the possibility of power interruption. All GFCI receptacles are furnished with a matching color thermoplastic wallplate, 20 amp feed-through capability. See page Tech-10 for Tamper-Resistant description.

### Product Dimensions

GFCI Receptacle	
A	3.27 (83.1)
B	2.75 (69.8)
C	1.75 (44.5)
D	1.47 (37.4)
E	1.10 (27.9)

