

## Surge Protection Devices



15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP




20A 125V  
NEMA 5-20R  
UL CSA  
1 HP


### Hospital Grade • Circuit Guard® Receptacles

Description	Color	Catalog Number	
SNAPConnect® Tamper-Resistant, surge suppression duplex receptacle, smooth face, 240 joules, 15000A peak current. Requires Snap connector on page L-14, sold separately.	Blue	<b>SNAP8262S</b>	<b>SNAP8362S</b>
	Gray	<b>SNAP8262GYS</b>	<b>SNAP8362GYS</b>
	Ivory	<b>SNAP8262IS</b>	<b>SNAP8362IS</b>
	Light Almond	<b>SNAP8262LAS</b>	<b>SNAP8362LAS</b>
	Red	<b>SNAP8262RS</b>	<b>SNAP8362RS</b>
White	<b>SNAP8262WS</b>	<b>SNAP8362WS</b>	
Surge suppression receptacles with light and alarm, 240 joules, 15000A peak current.	Blue	<b>HBL8262SA</b>	<b>HBL8362SA</b>
	Gray	<b>HBL8262GYSA</b>	<b>HBL8362GYSA</b>
	Ivory	<b>HBL8262ISA</b>	<b>HBL8362ISA</b>
	Red	<b>HBL8262RSA</b>	<b>HBL8362RSA</b>
	White	<b>HBL8262WSA</b>	<b>HBL8362WSA</b>
Isolated ground, surge suppression receptacles with light and alarm, 240 joules, 15000A peak current.	Blue	<b>IG8262SA</b>	<b>IG8362SA</b>
	Gray	<b>IG8262GYSA</b>	<b>IG8362GYSA</b>
	Ivory	<b>IG8262ISA</b>	<b>IG8362ISA</b>
	Orange	<b>IG8262OSA</b>	<b>IG8362OSA</b>
	Red	<b>IG8262RSA</b>	<b>IG8362RSA</b>
White	<b>IG8262WSA</b>	<b>IG8362WSA</b>	
4-PLEX® surge suppression receptacles with lights, 80 joules, 6500A peak current.	Blue	—	<b>HBL420HS</b>
	Ivory	—	<b>HBL420HIS</b>
	Red	—	<b>HBL420HRS</b>


Note: See page Tech-10 for Tamper-Resistant and LED Power Indicators descriptions.

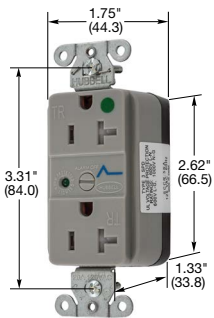

SNAP8362GYS

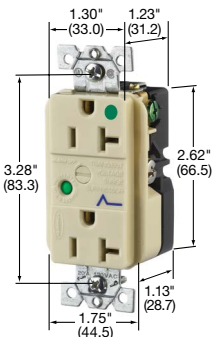

HBL8362ISA

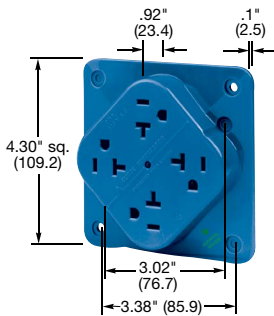

HBL420HS

### 4-PLEX® Accessories

Description	Color	Catalog Number
4-PLEX Adapter Plates for 1- and 2-gang, and 4 in. (101.6) square device boxes.	Blue	<b>HBL4APBL</b>
	Ivory	<b>HBL4API</b>
	Red	<b>HBL4APR</b>
4-PLEX Portable Box, 4 in. (101.6) square box with cord grip. Accepts up to .66 in. (16.8) diameter cord.	Ivory	<b>HBL4PBI</b>

Note: 4-PLEX Box is not UL Listed.

UL2930 Listed



### UL2930 Health Care Outlet Assembly (HCOA)

Description	# of Outlets	Cord Length	Color	15 Amp	20 Amp
UL 2930 HCOA with L-N surge protection.	6	6'	White	<b>HBL6MG6</b>	<b>HBL6MG620</b>
	6	15'	White	<b>HBL6MG15</b>	<b>HBL6MG1520</b>
UL 2930 HCOA, Relocatable Power Tap (RPT).	6	6'	White	<b>HBL6MGRPT6</b>	<b>HBL6MGRPT620</b>
	6	15'	White	<b>HBL6MGRPT15</b>	<b>HBL6MGRPT1520</b>



HBL6MGRPT620

Listed to UL1449



### SpikeShield® Surge Protective Devices (SPD) with Tamper-Resistant Receptacles and Heavy Duty Plug

Description	# of Outlets	Cord Length	Color	15 Amp	20 Amp
Type 3 SPD, Heavy Duty metal housing.	6	6'	White	<b>HBL6HG6</b>	<b>HBL6HG620</b>
	6	15'	White	<b>HBL6HG15</b>	<b>HBL6HG1520</b>
UL Type 3 SPD, Heavy Duty metal housing with 2-port USB.	4	6'	White	<b>HBL6HGUSB6</b>	—



HBL6HGUSB6

Dimensions in Inches (mm)