




15 and 20 Ampere, 125 Volts

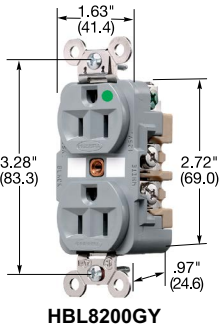


HBL8200GY

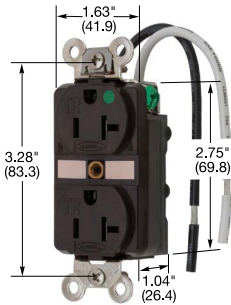


HBL8300SGA

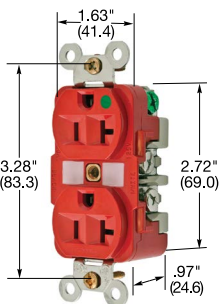

HBL8300RMRI

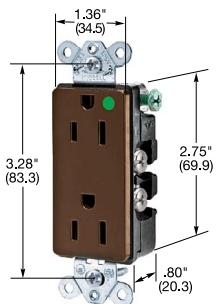

HBL2172

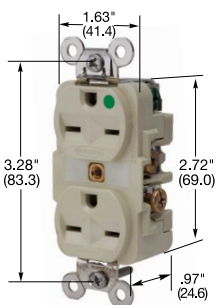

HBL8600I

Dimensions in Inches (mm)

IP20
SUITABILITY



15A 125V
NEMA 5-15R
UL CSA
0.5 HP



20A 125V
NEMA 5-20R
UL CSA
1 HP

HBL® Extra Heavy Duty Max Hospital Grade Receptacles

Duplex

Flush, thermoplastic polyester face, back and side wired.

Color	Catalog Number	
Black	HBL8200BK	-
Blue	-	HBL8300BL
Brown	HBL8200	HBL8300
Gray	HBL8200GY	HBL8300GY
Ivory	HBL8200I	HBL8300I
Light Almond	HBL8200LA	HBL8300LA
Red	HBL8200RED	HBL8300RED
White	HBL8200W	HBL8300W

Flush, LED illuminated face, back and side wired.

Gray	HBL8200ILGY	HBL8300ILGY
Ivory	HBL8200ILI	HBL8300ILI
Red	HBL8200ILR	HBL8300ILR
White	HBL8200ILW	HBL8300ILW

Tamper-Resistant receptacle with wire leads. Complies with requirements of NEC® article 517-18(c).



Brown	HBL8200SGA	HBL8300SGA
Gray	HBL8200SGGYA	HBL8300SGGYA
Ivory	HBL8200SGIA	HBL8300SGIA
Light Almond	-	HBL8300SGLA
Red	HBL8200SGRA	HBL8300SGRA
White	HBL8200SGWA	HBL8300SGWA

Isolated ground^A

Orange	IG8200	IG8300
Red	IG8200R	IG8300R

MRI Receptacle, Duplex

MRI receptacle, flush, thermoplastic polyester face, back and side wired. 100% non-ferrous.

Ivory	HBL8200IMRI	HBL8300IMRI
Light Almond	HBL8200LAMRI	HBL8300LAMRI
Red	HBL8200RMRI	HBL8300RMRI
White	HBL8200WMRI	HBL8300WMRI

Slender/Compact, Duplex

Flush, thermoplastic polyester face, back, and side wired, Fed. Spec. verified.

Brown	HBL8200H	HBL8300H
Gray	HBL8200HG	HBL8300HG
Green	-	HBL8300HGN
Ivory	HBL8200HI	HBL8300HI
Light Almond	HBL8200HLA	HBL8300HLA
Red	HBL8200HRED	HBL8300HRED
White	HBL8200HW	HBL8300HW

Style Line® Decorator*

Flush, nylon face, back and side wired.

Brown	HBL2172	HBL2182
Gray	HBL2172GY	HBL2182GY
Ivory	HBL2172I	HBL2182I
Red	HBL2172R	HBL2182R
White	HBL2172WA	HBL2182WA

Isolated ground^A

Ivory	-	IG2182I
Orange	-	IG2182
White	-	IG2182WA

Single

Flush, nylon face, back and side wired, Fed. Spec. verified.

Brown	HBL8210	HBL8310
Gray	HBL8210GY	HBL8310GY
Ivory	HBL8210I	HBL8310I
Red	HBL8210R	HBL8310R
White	HBL8210W	HBL8310W

Panel mount on 1.94 in. (49.2) centers.

Brown	HBL8284	-
Ivory	HBL8284I	HBL8384I

Isolated ground^A

Orange	IG8210	IG8310
--------	--------	--------

HBL® Extra Heavy Duty Max Hospital Grade Receptacles

250 Volts Duplex

Flush, thermoplastic polyester face, back and side wired.

Color	Catalog Number	
Brown	HBL8600	HBL8400
Ivory	HBL8600I	HBL8400I

Note: ^ASee section N for additional information on isolated ground devices.

*Not Fed. Spec. Listed.

See pages A-47 and A-48 for accessories. See section O for wallplates.

See page Tech-10 for Tamper-Resistant description.

NEC® is a registered trademark of the National Fire Protection Association (NFPA).