

Features and Benefits

Hubbell-PRO Extra Heavy Duty Receptacles

- Nylon face and base construction
- Triple-wipe power contacts
- Circuit ID marking area
- Combination Tamper-Resistant and LED for pediatric emergency circuits
- Galvanized steel mounting strap
- Automatic self-grounding staple
- Back and side wiring



2182IVLTRA

Hubbell-PRO Extra Heavy Duty Hospital Grade Receptacles



15A 125V
NEMA 5-15R
UL CSA
0.5 HP



20A 125V
NEMA 5-20R
UL CSA
1 HP

Style Line® Decorator

Hospital grade,
Style Line® decorator,
flush, nylon face,
back and side wired.
Assembled in USA.

Color
Black
Brown
Gray
Ivory
Light Almond
Red
White

Catalog Number
2172BK
2172
2172GY
2172IV
2172LA
2172RED
2172W

2182BK
2182
2182GY
2182IV
2182LA
2182RED
2182W

Hospital grade, Tamper-Resistant,
Style Line® decorator,
flush, nylon face,
back and side wired.
Assembled in USA.

Black
Brown
Gray
Ivory
Light Almond
Red
White

2172BKTRA
2172TRA
2172GYTRA
2172IVTRA
2172LATRA
2172REDTRA
2172WTRA

2182BKTRA
2182TRA
2182GYTRA
2182IVTRA
2182LATRA
2182REDTRA
2182WTRA



Hospital grade,
with Power Indicating LED,
Style Line® decorator,
flush, nylon face,
back and side wired.
Assembled in USA.

Black
Brown
Gray
Ivory
Light Almond
Red
White

2172BKL
2172L
2172GYL
2172IVL
2172LAL
2172REDL
2172WL

2182BKL
2182L
2182GYL
2182IVL
2182LAL
2182REDL
2182WL




Hospital grade, Tamper-Resistant,
with Power Indicating LED,
Style Line® decorator,
flush, nylon face,
back and side wired.
Assembled in USA.


Black
Brown
Gray
Ivory
Light Almond
Red
White

2172BKLTRA
2172LTRA
2172GYLTRA
2172IVLTRA
2172LALTRA
2172REDLTRA
2172WLTRA


2182BKLTRA
2182LTRA
2182GYLTRA
2182IVLTRA
2182LALTRA
2182REDLTRA
2182WLTRA

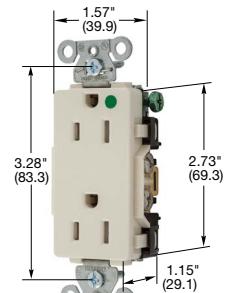

2172LATRA

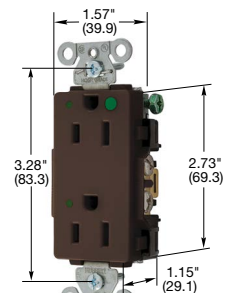

2172L

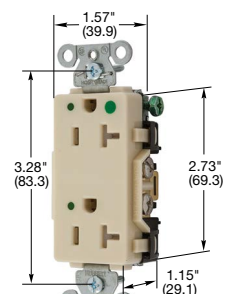

2182IVLTRA

Note: See pages A-47 and A-48 for accessories.
See page Tech-10 for Tamper-Resistant and LED Power Indicators description.
See section O for wallplates.

The products listed on this page are Assembled in USA, and many are Buy American Compliant. Please contact Hubbell with any certification requirements.

Dimensions in Inches (mm)