



## SNAPConnect® Tamper-Resistant Surge Protection Receptacle with Power Indicating LED



Description	Color	Catalog Number	
Hospital Grade ● SNAPConnect® Tamper-Resistant, surge suppression duplex receptacle, smooth face, 240 joules, 15kA peak current.	Blue	<b>SNAP8262S</b>	<b>SNAP8362S</b>
	Gray	<b>SNAP8262GYS</b>	<b>SNAP8362GYS</b>
	Ivory	<b>SNAP8262IS</b>	<b>SNAP8362IS</b>
	Light Almond	<b>SNAP8262LAS</b>	<b>SNAP8362LAS</b>
	Red	<b>SNAP8262RS</b>	<b>SNAP8362RS</b>
	White	<b>SNAP8262WS</b>	<b>SNAP8362WS</b>
Commercial Grade SNAPConnect® Tamper-Resistant, surge suppression duplex receptacle, smooth face, 240 joules, 15kA peak current.	Blue	<b>SNAP5262S</b>	<b>SNAP5362S</b>
	Gray	<b>SNAP5262GYS</b>	<b>SNAP5362GYS</b>
	Ivory	<b>SNAP5262IS</b>	<b>SNAP5362IS</b>
	Light Almond	<b>SNAP5262LAS</b>	<b>SNAP5362LAS</b>
	White	<b>SNAP5262WS</b>	<b>SNAP5362WS</b>

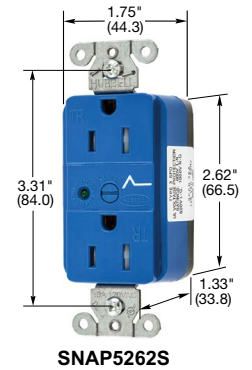


**SNAP5262S**

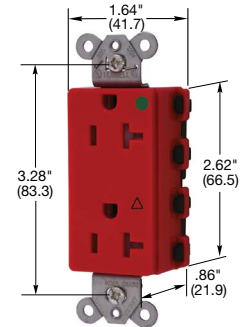


**SNAP2182RIGTRA**

## SNAPConnect® Tamper-Resistant Isolated Ground Receptacle

Description	Color	Catalog Number	
Hospital Grade ● SNAPConnect® Tamper-Resistant, isolated ground, smooth face, duplex.	Orange	<b>SNAP8200IGTRA</b>	<b>SNAP8300IGTRA</b>
	Red	<b>SNAP8200RIGTRA</b>	<b>SNAP8300RIGTRA</b>
Hospital Grade ● Style Line® decorator SNAPConnect® Tamper-Resistant, isolated ground, smooth face, duplex.	Orange	<b>SNAP2172IGTRA</b>	<b>SNAP2182IGTRA</b>
	Red	<b>SNAP2172RIGTRA</b>	<b>SNAP2182RIGTRA</b>
Commercial Grade, isolated ground.	Orange	<b>SNAP5262IGTRA</b>	<b>SNAP5362IGTRA</b>
Style Line® decorator.	Orange	<b>SNAP2152IGTRA</b>	<b>SNAP2162IGTRA</b>

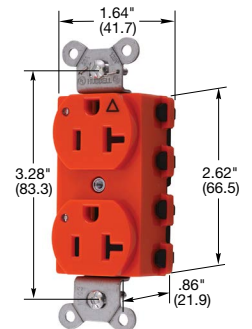


**SNAP5362IGL**

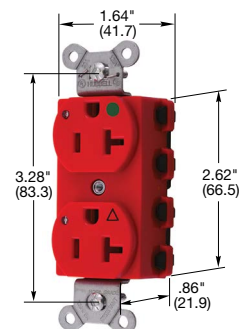

**SNAP8300RIGLTRA**

## SNAPConnect® Isolated Ground Receptacle with Power Indicating LED

Description	Color	Catalog Number	
Hospital Grade ● SNAPConnect® Tamper-Resistant, isolated ground, smooth face, duplex.	Orange	<b>SNAP8200IGL</b>	<b>SNAP8300IGL</b>
	Red	<b>SNAP8200RIGL</b>	<b>SNAP8300RIGL</b>
Hospital Grade ● Style Line® decorator SNAPConnect® Tamper-Resistant, isolated ground, smooth face, duplex.	Orange	<b>SNAP2172IGL</b>	<b>SNAP2182IGL</b>
	Red	<b>SNAP2172RIGL</b>	<b>SNAP2182RIGL</b>
Commercial Grade, isolated ground.	Orange	<b>SNAP5262IGL</b>	<b>SNAP5362IGL</b>
Style Line® decorator.	Orange	<b>SNAP2152IGL</b>	<b>SNAP2162IGL</b>

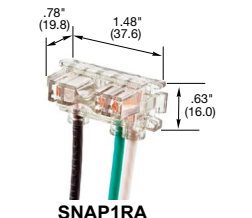

**SNAP1RA**

## SNAPConnect® Tamper-Resistant Isolated Ground Receptacle with Power Indicating LED

Description	Color	Catalog Number	
Hospital Grade ● SNAPConnect® Tamper-Resistant, isolated ground, smooth face, duplex.	Orange	<b>SNAP8200IGLTRA</b>	<b>SNAP8300IGLTRA</b>
	Red	<b>SNAP8200RIGLTRA</b>	<b>SNAP8300RIGLTRA</b>
Hospital Grade ● Style Line® decorator SNAPConnect® Tamper-Resistant, isolated ground, smooth face, duplex.	Orange	<b>SNAP2172IGLTRA</b>	<b>SNAP2182IGLTRA</b>
	Red	<b>SNAP2172RIGLTRA</b>	<b>SNAP2182RIGLTRA</b>
Commercial Grade, isolated ground.	Orange	<b>SNAP5262IGLTRA</b>	<b>SNAP5362IGLTRA</b>
Style Line® decorator.	Orange	<b>SNAP2152IGLTRA</b>	<b>SNAP2162IGLTRA</b>



## SNAPConnect® Right Angle Pigtailed Connector for General Use

Description	Solid Wire	Stranded Wire
Clear right angle terminal with 6 inch leads #12 AWG THHN/THWN-2, 600V, Polycarbonate housing material.	<b>SNAP1RA</b>	<b>SNAP2RA</b>

Note: See page Tech-10 for Tamper-Resistant and LED Power Indicators descriptions.

Dimensions in Inches (mm)