

**IG5352**

## Hubbell-PRO Heavy Duty Specification Grade



**15A 125V**  
NEMA 5-15R  
UL CSA  
0.5 HP




**20A 125V**  
NEMA 5-20R  
UL CSA  
1 HP

Description	Color	Catalog Number	
Smooth face, duplex, back and side wired.	Orange	<b>IG5252</b>	<b>IG5352</b>
	Gray	<b>IG5252GY</b>	<b>IG5352GY</b>
	Ivory	<b>IG5252I</b>	<b>IG5352I</b>
	Light Almond	<b>IG5252LA</b>	<b>IG5352LA</b>
	White	<b>IG5252W</b>	<b>IG5352W</b>
Tamper-Resistant, smooth face, duplex, back and side wired.	Orange	<b>IG5252TR</b>	<b>IG5352TR</b>
	Ivory	<b>IG5252ITR</b>	<b>IG5352ITR</b>
	White	<b>IG5252WTR</b>	<b>IG5352WTR</b>




Note: See page Tech-10 for Tamper-Resistant description.

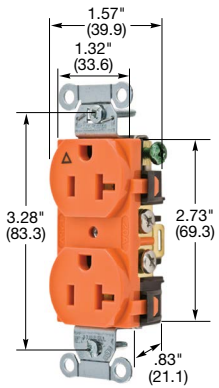

**IG20CR**

## Commercial Specification Grade

Description	Color	Catalog Number	
Smooth face, duplex, side wired.	Orange	<b>IG15CR</b>	<b>IG20CR</b>
	Gray	<b>IG15CRGRY</b>	<b>IG20CRGRY</b>
	Ivory	<b>IG15CRI</b>	<b>IG20CRI</b>
	Light Almond	<b>IG15CRLA</b>	<b>IG20CRLA</b>
	White	<b>IG15CRWHI</b>	<b>IG20CRWHI</b>
Style Line® decorator; smooth face; back and side wired.	Orange	<b>IG15DR</b>	<b>IG20DR</b>
	Gray	<b>IG15DRGRY</b>	<b>IG20DRGRY</b>
	Ivory	<b>IG15DRI</b>	<b>IG20DRI</b>
	Light Almond	<b>IG15DRLA</b>	<b>IG20DRLA</b>
	White	<b>IG15DRWHI</b>	<b>IG20DRWHI</b>

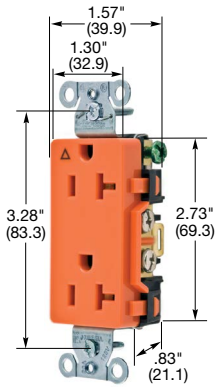

**IG20DR**

## 15A and 20A, 250V HBL® Extra Heavy Duty, Specification Grade, Isolated Ground Receptacles




**15A 250V**  
NEMA 6-15R  
UL CSA  
1.5 HP



**20A 250V**  
NEMA 6-20R  
UL CSA  
2 HP

Description	Color	Catalog Number	
Flush, nylon face, duplex, back and side wired, multiple drive screws.	Orange	<b>IG5662</b>	<b>IG5462</b>
Flush, nylon face, single.	Orange	<b>IG5661</b>	<b>IG5461</b>

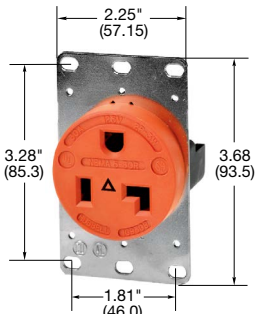

**IG9308**

**IP20**  
SUITABILITY



**30A 125V**  
NEMA 5-30R  
UL CSA  
2 HP



**30A 250V**  
NEMA 6-30R  
UL CSA  
2 HP

## 30A, 125V and 250V Isolated Ground Receptacles

Description	Color	Catalog Number	
Single receptacle, 2 pole, 3 wire grounding.	Orange	<b>IG9308</b>	<b>IG9330</b>

Dimensions in Inches (mm)