

IG5352

Hubbell-PRO Heavy Duty Specification Grade



15A 125V
NEMA 5-15R
UL CSA
0.5 HP




20A 125V
NEMA 5-20R
UL CSA
1 HP

Description	Color	Catalog Number	
Smooth face, duplex, back and side wired.	Orange	IG5252	IG5352
	Gray	IG5252GY	IG5352GY
	Ivory	IG5252I	IG5352I
	Light Almond	IG5252LA	IG5352LA
	White	IG5252W	IG5352W
Tamper-Resistant, smooth face, duplex, back and side wired.	Orange	IG5252TR	IG5352TR
	Ivory	IG5252ITR	IG5352ITR
	White	IG5252WTR	IG5352WTR




Note: See page Tech-10 for Tamper-Resistant description.

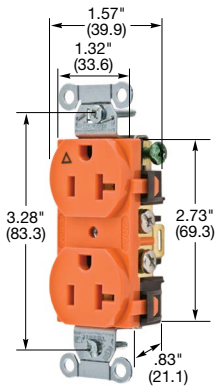

IG20CR

Commercial Specification Grade

Description	Color	Catalog Number	
Smooth face, duplex, side wired.	Orange	IG15CR	IG20CR
	Gray	IG15CRGRY	IG20CRGRY
	Ivory	IG15CRI	IG20CRI
	Light Almond	IG15CRLA	IG20CRLA
	White	IG15CRWHI	IG20CRWHI
Style Line® decorator; smooth face; back and side wired.	Orange	IG15DR	IG20DR
	Gray	IG15DRGRY	IG20DRGRY
	Ivory	IG15DRI	IG20DRI
	Light Almond	IG15DRLA	IG20DRLA
	White	IG15DRWHI	IG20DRWHI

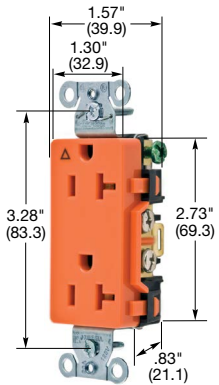

IG20DR

15A and 20A, 250V HBL® Extra Heavy Duty, Specification Grade, Isolated Ground Receptacles




15A 250V
NEMA 6-15R
UL CSA
1.5 HP



20A 250V
NEMA 6-20R
UL CSA
2 HP

Description	Color	Catalog Number	
Flush, nylon face, duplex, back and side wired, multiple drive screws.	Orange	IG5662	IG5462
Flush, nylon face, single.	Orange	IG5661	IG5461

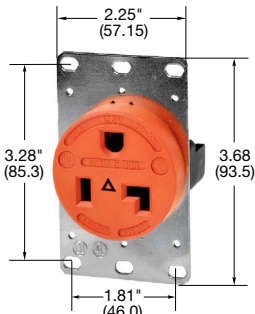

IG9308

IP20
SUITABILITY



30A 125V
NEMA 5-30R
UL CSA
2 HP



30A 250V
NEMA 6-30R
UL CSA
2 HP

30A, 125V and 250V Isolated Ground Receptacles

Description	Color	Catalog Number	
Single receptacle, 2 pole, 3 wire grounding.	Orange	IG9308	IG9330

Dimensions in Inches (mm)