

**IG4700A**

## 15A, 125V and 250V Back and Side Wired



**15A 125V**  
NEMA L5-15R  
UL/CSA



**15A 250V**  
NEMA L6-15R  
UL/CSA

Description	Poles/Wires	Color	Catalog Number	
Flush, RTP face, duplex.	2 pole, 3 wire	Orange	<b>IG4700A*</b>	<b>IG4550A*</b>
Flush, RTP face, single.	2 pole, 3 wire	Orange	<b>IG4710</b>	<b>IG4560</b>

*Note: RTP is an abbreviation for reinforced thermoplastic polyester.  
\*Supplied with break-off tabs for split circuit wiring.*



**20A 125V**  
NEMA L5-20R  
UL/CSA  
1 HP




**20A 250V**  
NEMA L6-20R  
UL/CSA  
2 HP



**20A 480V AC**  
NEMA L8-20R  
UL/CSA  
3 HP

## 20A, 125V, 250V and 480V AC Back and Side Wired

Description	Poles/Wires	Color	Catalog Number	
Flush, nylon face, single.	2 pole, 3 wire	Orange	<b>IG2310</b>	<b>IG2320</b> <b>IG2340</b>

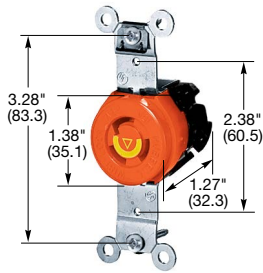

**IG4710**

## 30A, 125V and 250V Back and Side Wired




**30A 125V**  
NEMA L5-30R  
UL/CSA  
2 HP



**30A 250V**  
NEMA L6-30R  
UL/CSA  
2 HP

Description	Poles/Wires	Color	Catalog Number	
Flush, nylon face, single.	2 pole, 3 wire	Orange	<b>IG2610</b>	<b>IG2620</b>

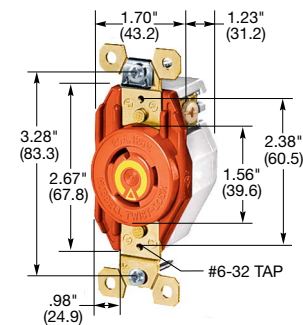

**IG2310**

## 20A, 125V/250V and 3Ø 250V AC Back and Side Wired



**20A 125/250V AC**  
NEMA L14-20R  
UL/CSA  
2 (1) HP



**20A 3Ø 250V AC**  
NEMA L15-20R  
UL/CSA  
3 HP

Description	Poles/Wires	Color	Catalog Number	
Flush, nylon face, single.	3 pole, 4 wire	Orange	<b>IG2410</b>	<b>IG2420</b>



**30A 125/250V AC**  
NEMA L14-30R  
UL/CSA  
2 (2) HP



**30A 3Ø 250V AC**  
NEMA L15-30R  
UL/CSA  
3 HP

## 30A, 125V/250V and 3Ø 250V AC Back and Side Wired

Description	Poles/Wires	Color	Catalog Number	
Flush, nylon face, single.	3 pole, 4 wire	Orange	<b>IG2710</b>	<b>IG2720</b>



**20A 3Ø**  
120/208V AC  
NEMA L21-20R  
UL/CSA  
2 HP



**30A 3Ø**  
120/208V AC  
NEMA L21-30R  
UL/CSA  
3 HP

## 20A and 30A, 3ØY 120/208V AC Back and Side Wired

Description	Poles/Wires	Color	Catalog Number	
Flush, nylon face, single.	4 pole, 5 wire	Orange	<b>IG2510</b>	<b>IG2810</b>

Dimensions in Inches (mm)