

# SpikeShield® Power Quality Products

## Features and Benefits

### UL2930 Healthcare Outlet Assembly (HCOA)


- Hubbell's UL2930 HCOAs are the industry first
- UL listed product for patient care areas
- Product is available with or without L-N surge protection
- 4 Outlet models feature straight plugs



UL2930 Listed



45° Angle Plug  
(6 outlet 15A models only)

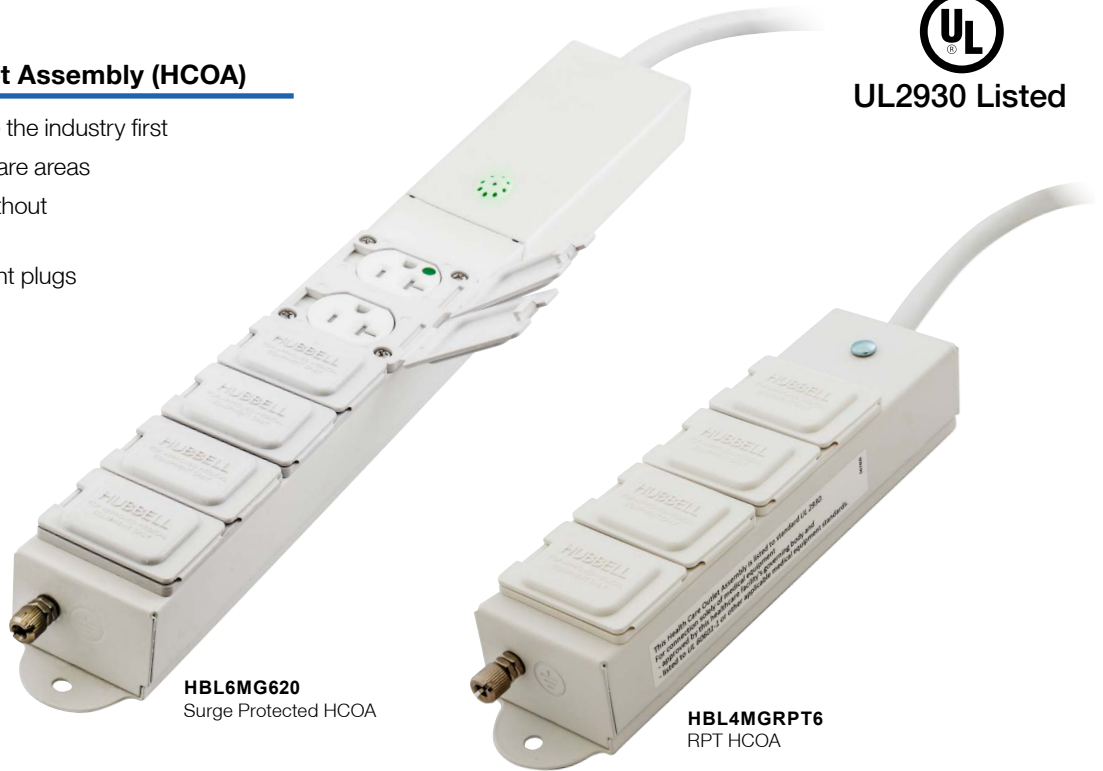

#### Housing Design and Safety

- First UL2930 product ever sold
- 15A and 20A 125V versions
- Surge or Non-surge protected models in all configurations
- Tamper-resistant flip covers
- Green LED indicates surge protection working



#### Contacts and Cord

- Equipment grounding terminal
- 6 ft. or 15 ft. cord length
- 12/3 AWG cord on 15A and 20A models
- 45° angle plug (6 outlet 15A models only)
- 90° angle plug (All 4 outlet and all 20A models)

### UL2930 Healthcare (6) Outlet Assembly (HCOA)

Description	# of Outlets	Joule Rating	Cord Length	Color	15 Amp	20 Amp
UL2930 HCOA with L-N Surge Protection	6	550	6 Ft.	White	<b>HBL6MG6</b>	<b>HBL6MG620</b>
	6	550	15 Ft.	White	<b>HBL6MG15</b>	<b>HBL6MG1520</b>
UL2930 HCOA Relocatable Power Tap (RPT)	6	N/A	6 Ft.	White	<b>HBL6MGRPT6</b>	<b>HBL6MGRPT620</b>
	6	N/A	15 Ft.	White	<b>HBL6MGRPT15</b>	<b>HBL6MGRPT1520</b>

### UL2930 Healthcare (4) Outlet Assembly (HCOA)

Description	# of Outlets	Joule Rating	Cord Length	Color	15 Amp	20 Amp
UL2930 HCOA with L-N Surge Protection	4	550	6 Ft.	White	<b>HBL4MG6</b>	<b>HBL4MG620</b>
	4	550	15 Ft.	White	<b>HBL4MG15</b>	<b>HBL4MG1520</b>
UL2930 HCOA Relocatable Power Tap (RPT)	4	N/A	6 Ft.	White	<b>HBL4MGRPT6</b>	<b>HBL4MGRPT620</b>
	4	N/A	15 Ft.	White	<b>HBL4MGRPT15</b>	<b>HBL4MGRPT1520</b>

### Hubbell HCOA Accessories

Description	Color	Catalog Number
HCOA mounting bracket allows strips to be easily mounted to IV poles or other like medical devices.	Black	<b>HBLHCOAMB</b>
HCOA replacement outlet cover	White	<b>ROCMGS</b>

