
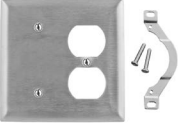

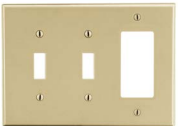
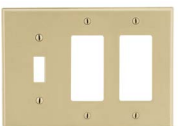


Combination Wallplates, 2-Gang

| Description | Color | Thermoplastic | | Material | Metal Catalog Number |
|---|--------------|---------------|----------|--------------|----------------------|
| | | Standard | Mid-Size | | |
| 2-Gang, 1-Blank, 1-Duplex Box Mount  | Gray | P138GY | — | Aluminum | ① |
| | Ivory | P138I | — | Brass | ① |
| | Light Almond | P138LA | — | Brass Plated | ① |
| | White | P138W | — | Chrome | ① |
| | | | | S/S 302/304 | SS138 |
| 2-Gang, 1-Blank, 1-Duplex Strap Mount  | | | | Aluminum | ① |
| | | | | Brass | ① |
| | | | | Brass Plated | ① |
| | | | | Chrome | ① |
| | | | | S/S 302/304 | SS148 |

Combination Wallplates, 3-Gang

| Description | Color | Thermoplastic | | Material | Metal Catalog Number |
|--|--------------|----------------|----------------|--------------|----------------------|
| | | Standard | Mid-Size | | |
| 3-Gang, 2-Toggle, 1-Duplex  | Brown | P28 | — | Aluminum | ① |
| | Gray | P28GY | — | Brass | ① |
| | Ivory | P28I | PJ28I | Brass Plated | ① |
| | Light Almond | P28LA | PJ28LA | Chrome | ① |
| | White | P28W | PJ28W | S/S 302/304 | ① |
| 3-Gang, 2-Toggle, 1-Decorator  | Black | P226BK | — | Aluminum | ① |
| | Brown | P226 | — | Brass | ① |
| | Gray | P226GY | — | Brass Plated | ① |
| | Ivory | P226I | PJ226I | Chrome | ① |
| | Light Almond | P226LA | PJ226LA | S/S 302/304 | SS226 |
| | White | P226W | PJ226W | | |
| 3-Gang, 1-Toggle, 2-Decorator  | Ivory | P1262I | — | Aluminum | ① |
| | Light Almond | P1262LA | — | Brass | ① |
| | White | P1262W | — | Brass Plated | ① |
| | | | | Chrome | ① |
| | | | | S/S 302/304 | ① |

Note: Thermoplastic wallplates feature pre-inserted captive screws for faster assembly in single gang configurations.
 ①Available as a custom wallplate, see pages N-32 to N-34. Consult custom wallplates section for additional openings and combinations.

Dimensions in Inches (mm)