

Fire-Classified Floor Box Solutions



Hubbell's fire-classified floor boxes are an excellent solution when there is not enough capacity in a poke through and the decking must be penetrated for electrical installations. Available in seven or eleven gang versions, our fire rated kits are compatible with our standard CFB7G6 and CFB11G6 series floor boxes.

Fire-Classified Floor Box Kits


- Preserves 2 or 3 hour fire classified floor rating
- Approved for installations using either light or normal weight concrete
- UL 514 and UL 263 Compliant
- Variety of ADA compliant cover choices for most floor types
- Four 1½ inch box bottom entry conduits

Fire-Resistant Floor Box Kit Includes


- Floor pan, conduit assemblies, hardware, leveling feet and manual
Floor box ordered separately

Installation

- For Concrete pours from 3¼ in. up to 5½ in. above upper most portion of decking
- Units can be mounted 2 ft. on center
- Fastens to deck with TEK screws or welding

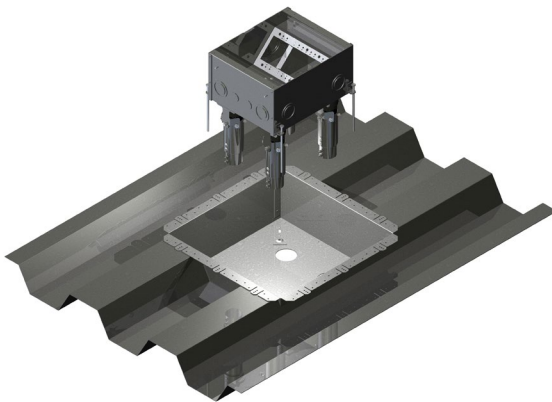

CFB7G6 Floor Box above **CFB7G6FRK**
Installed in decking

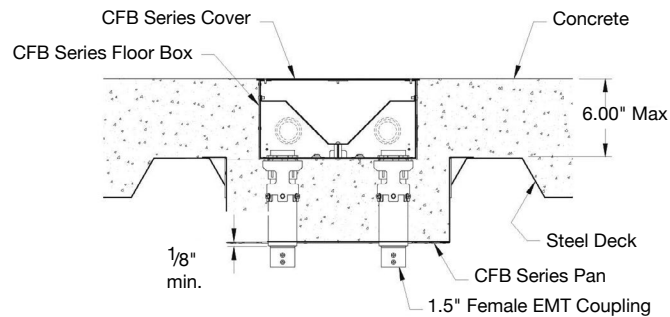


CFB7G6/CFB11G6 Series

Fire-Classified Kit for 7-Gang Floor Box

Floor box, cover and mounting plates NOT included.

Description		Catalog Number
Bottom feed conduits.	4	CFB7G6FRK
Bottom feed conduit size.	1½ in.	
Pan dimensions.	17 ³ / ₁₆ L x 17 ³ / ₁₆ W x 6 ¹ / ₂ H in.	
Minimum depth of pour above deck roof.	3¼ in.	
Maximum depth of pour above deck roof.	5½ in.	
Adjustment screw length, four per kit.	6 in.	
Required floor box (not included).	CFB7G6	

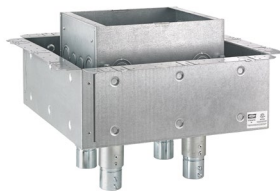


CFB7G6FRK
Kit with **CFB7G6**

Fire-Classified Kit for 11-Gang Floor Box

Floor box, cover and mounting plates NOT included.

Description		Catalog Number
Bottom feed conduits.	4	CFB11G6FRK
Bottom feed conduit size.	1½ in.	
Pan dimensions.	20 ¹ / ₁₆ L x 17 ³ / ₁₆ W x 6 ¹ / ₂ H in.	
Minimum depth of pour above deck roof.	3¼ in.	
Maximum depth of pour above deck roof.	5½ in.	
Adjustment screw length, four per kit.	6 in.	
Required floor box (not included).	CFB11G6	

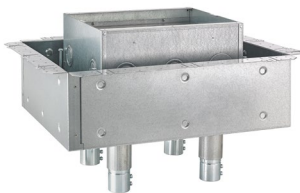

CFB11G6FRK
Kit with **CFB11G6**

Dimensions in Inches (mm)