

## Recessed 8-Gang Ballroom Series Floor Boxes

Style	CFB8FC Series	
	8-Gang	8-Gang
	<p><b>CFB8FC1</b></p>	<p><b>CFB8FC2</b></p>
Application	Carpet	Tile, Finished Concrete
Min. Depth of Pour	6.95" (176.5)	7.15" (181.6)
Adjustability	Before Pour	Before Pour
Dimensions:		
A	6.95" (176.5)	7.15" (181.6)
B	15.00" (381.0)	14.75" (374.7)
C	13.00" (330.2)	12.75" (323.9)
KO Trade Size:		
Sides	(4) 1", 1¼", 1½"	(4) 1", 1¼", 1½"
Front & Back	(4) 1", 1¼", 1½"	(4) 1", 1¼", 1½"
Bottom	(4) 1", 1¼", 1½"	(4) 1", 1¼", 1½"
Side View Depth behind mounting plate	<p>X = 2.27" (57.7) Y = 4.01" (101.9) Z = 3.13" (79.5)</p>	<p>X = 2.27" (57.7) Y = 4.01" (101.9) Z = 3.13" (79.5)</p>
Accepts industry standard size wallplates (sold separately) 4.63" Maximum Cover Height	One, two, three and four gang plates. Customer configuration dependant.	One, two, three and four gang plates. Customer configuration dependant.


Note: UL File Number E31999.

## Accessories

### On-grade Barrier

The on-grade barrier is intended for use on installations at grade level. This accessory is installed prior to the concrete pour and provides a barrier between the soil. The on-grade barrier comes with leveling feet and anchor points.

### CFBOGPAN4

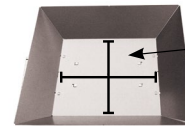

Pour Pan Dimensions:  
15.75 in. sq.  
4 in. depth

## Covers

All ballroom floor box covers are machined from Aluminum and have no additional finish options

	CFB8FC1 Covers		CFB8FC2 Covers	
Carpet Cover, with 2 egress doors (0.20" depth)	<b>CFB8CVRALU1</b>	-	-	-
Flush cover, with 2 egress doors	-	-	<b>CFB8CVRALU2</b>	-
Blank box cover	-	<b>CFB8JBC1</b>	-	<b>CFB8JBC2</b>
Cover Load Ratings*:				
Recommended Loading	20,000 lb	20,000 lb	20,000 lb	20,000 lb
Maximum Load	40,000 lb	40,000 lb	40,000 lb	40,000 lb

Note: \*Load applied through 3" (76mm) mandrel in center of cover. Loads are static and don't apply to rolling loads.

Dimensions in Inches (mm)