


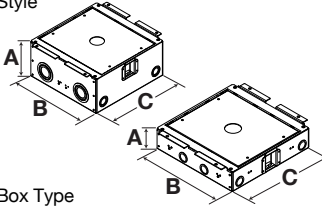

SystemOne Recessed 4-Gang Rectangular Floor Boxes, Covers and Plates For Use In Raised Access or Wood Floors

AFB series boxes are available from our factory as pre-wired assemblies with CONNEXION modular plug-n-play system

Style			
Box Type			
Standard Chicago (No Knockouts)	AFB4G50 AFB4G50CHI		AFB4G25 AFB4G25CHI
Minimum Depth from Top of Floor Tile	5.37" (136.4)		2.88" (73.2)
Cubic Inch (cm ³) Capacity per Gang	57.5 cu. in. (940 cm ³)		26.5 cu. in. (434.3 cm ³)
Dimensions – A	5.18" (131.4)		2.69" (68.3)
Dimensions – B	11.11" (282.2)		11.11" (282.2)
Dimensions – C	10.90" (276.9)		10.90" (276.9)
KO Trade Size: Ends	(2) ½", (4) 1", 1¼", 1½", 2"		(4) ½", ¾"
Sides	(4) ½", ¾", 1", 1¼"		(4) ½", ¾"
Bottom	(4) ½", ¾", 1", 1¼"		(4) ½", ¾", (4) 1", 1¼"
Floor Thickness	.62- 2.12" (15.7- 53.8)		.62- 2.12" (15.7- 53.8)
Cover Family	Rectangular		Rectangular
Temporary Cover Included	✓		✓

Note: UL File Number E31999.

Rectangular Covers (for use with raised access tiles and wood floors)

- Die cast construction available in five finishes
- UL 514A listed
- Maximum static load of 1500 lbs. with 2x safety factor*

Surface Cover Dimensions 13 in. x 13¼ in.

Finish	Without Insert	With Insert
Aluminum Powder Coat	4GAFBCVRALU	4GAFBCVRALUC
Black Powder Coat	4GAFBCVRBK	4GAFBCVRBKUC
Brass Powder Coat	4GAFBCVRBRS	4GAFBCVRBRSC
Bronze Powder Coat	4GAFBCVRBRZ	4GAFBCVRBRZC
Satin Nickel Powder Coat	4GAFBCVRNK	4GAFBCVRNKUC














Note: *Load applied through a 3 in. (76mm) mandrel in center of the cover.

Accessories

Description	Catalog Number
AFB4G series replacement dividers.	AFB4GDIVKIT

Plates - for use in 2 and 4-Gang Floor Boxes

- UL 514A listed

Plate Style	(1) Decorator Opening	(1) Duplex Opening	(2) Extron® MAA P Openings	(2) Extron® Openings	(2) 1U Hubbell iStation Openings
Cat. No.	FBMPREC	FBMPDUP	FBMPMAAP	FBMPAAP	FBMP2IM
					
Plate Style	(1) 1.5U Hubbell iStation Opening	(1) Simplex Opening 1.40 in. Diameter	(1) Twist-Lock® Opening 1.60 in. Diameter	1-Gang Blank	Cable Feed Through with Bushing
Cat. No.	FBMP15IM	FBMP139	FBMP156	FBMPBNK	FBMPFT
					
Plate Style	(1) Opening for TracJack® or Series II®	(2) Hubbell Jack Openings and (4) Jack KOs w/Label Field	(1) Opening with Hubbell ISF6 Frame for Keystone Jacks		
Cat. No.	FBMPTRAC	FBMP6DJ	FBMP6KS		
					

Extron® is a registered trademark of Extron Electronics. Crestron® is a registered trademark of Crestron Electronics, Inc. FSR® is a registered trademark of FSR Inc. TracJack®, Series II® and Ortronics® are registered trademarks of Ortronics/Legrand.

Dimensions in Inches (mm)