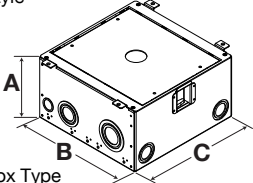



SystemOne Recessed 8*/10-Gang Rectangular Floor Boxes, Covers and Plates For Use In Raised Access or Wood Floors

AFB series boxes are available from our factory as pre-wired assemblies with CONNEXION modular plug-n-play system

Style			
Box Type			
Standard	AFB10G55		
Chicago (No Knockouts)	AFB10G55CHI		
Min. Depth from Top of Floor Tile	5.95" (151.1)		
Cubic Inch (cm ³) Capacity per Gang	(2) 25 cu. in. (407.9 cm ³), (2) 50 cu. in. (819.4 cm ³), (2) 71 cu. in. (1163.5 cm ³)		
Dimensions – A	5.74" (145.9)		
Dimensions – B	11.11" (282.2)		
Dimensions – C	10.66" (270.7)		
KO Trade Size: Ends	(2) ½", ¾", (2) ¾", 1", 1¼", 1½", (2) 1", 1¼", 1½", 2"		
Sides	(4) ¾", 1", 1¼", 1½"		
Bottom	(2) ½", ¾", (4) ½", ¾", 1", 1¼"		
Floor Thickness	.56" (1.2) - 2.12" (53.8)		
Cover Family	Rectangular		
Temporary Cover Included	✓		

Note: UL File Number E31999.



Rectangular Covers




 
 
 


 


 




 
 
 

(for use with raised access tiles and wood floors)

- Die cast construction available in five finishes
- UL 514A listed
- Maximum static load of 1500 lbs with 2x safety factor**

Finish	Surface Style Covers	
	Without Insert	With Insert
Aluminum Powder Coat	10GAFBCVRALU	10GAFBCVRALUC
Black Powder Coat	10GAFBCVRBK	10GAFBCVRBK
Brass Powder Coat	10GAFBCVRBRS	10GAFBCVRBRS
Bronze Powder Coat	10GAFBCVRBRZ	10GAFBCVRBRZ
Satin Nickel Powder Coat	10GAFBCVRNK	10GAFBCVRNK

Note: **Load applied through a 3 in. (76mm) mandrel in center of the cover.

Plates for Use in SystemOne 8*/10-Gang Floor Boxes

Plate Style	(1) Decorator Opening	(1) Duplex Opening	Blank	Decorator Opening Plate Including Hubbell ISF6GY	(2) Openings to Accommodate (6) Ortronics TracJack®
Cat. No.	FB10MPREC	FB10MPDUP	FB10MPBNK	FB10MPKEY	FB10MPTRAC
					
Plate Style	(2) Decorator	(2) Duplex Openings	(4) Extron® MAAP Modules	(4) Extron® AAP Modules	For (6) 1U Hubbell iStation Modules
Cat. No.	FB10MP2A	FB10MP2E	FB10MPMAAP	FB10MPAAP	FB10MP2B
					
Plate Style	(1) Twist-Lock® Opening 1.60 in. Dia. (Uses 2-Gangs)	(1) Simplex Opening 1.40 in. Dia. (Uses 3-Gangs)	(2) Twist-Lock® Opening 1.60 in. Dia. (Uses 3-Gangs)	(2) Simplex Opening 1.40 in. Dia. (Uses 3-Gangs)	(1) Opening for Appliance Receptacle (Uses 3-Gangs)
Cat. No.	FB10TLA	FB10TLX	FB10TLB	FB10TLY	FB10MP3GAPP
					
Plate Style	(3) Twist-Lock® Opening 1.60 in. Dia. (Uses 5-Gangs)	(3) Simplex Opening 1.40 in. Dia. (Uses 5-Gangs)	(2) 2-Gang. Meets NEMA Spacing. Ideal for Crestron® DM-TX Product and Power (Uses 5-Gangs)	(4) Single Service Openings Utilizing NEMA Wallplate (Uses 5-Gangs)	
Cat. No.	FB10TLC	FB10TLZ	FB10MPNEMA2XG*	FB10MPNEMA4G*	
					

Note: *Use with FB10MPNEMA2XG and/or FB10MPNEMA4G for 8-gang configuration.

Extron® is a registered trademark of Extron Electronics. Crestron® is a registered trademark of Crestron Electronics, Inc. FSR® is a registered trademark of FSR Inc. TracJack®, Series II® and Ortronics® are registered trademarks of Ortronics/Legrand.

Dimensions in Inches (mm)