
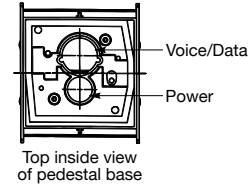


Pedestal FRPT Series

Painted and Brushed Aluminum Series



Dimensions

2-Gang – FR280 Series (Use with PT27A Only)

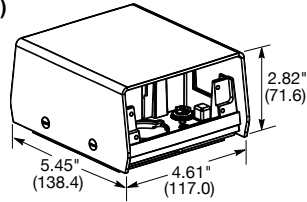



Total Cubic Inch Capacity (Single-Service)	39.00 in. (638.8cm ³)
Cubic Inch Capacity (when divided for multi-service)	Power 19.5 in. (319.4cm ³) Voice/Data 19.5 in. (319.4cm ³)
Service Pedestal Construction	Heavy gauge galvanized steel frame with aluminum housing and face plates.
Pedestal Finish	Textured black or gray epoxy paint.

4-Gang – FR480 (Use with PT27A or PT7XC)

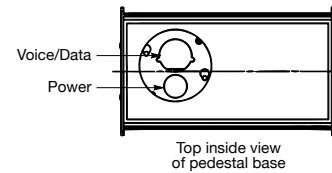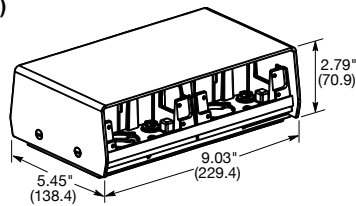



Total Cubic Inch Capacity (Single-Service)	78.00 in. (1277.6cm ³)
Cubic Inch Capacity (when divided for multi-service)	Power 39.00 in. (638.8cm ³) Voice/Data 39.00 in. (638.8cm ³)
Service Pedestal Construction	Heavy gauge galvanized steel frame with aluminum housing and face plates.
Pedestal Finish	Textured black or gray epoxy paint.

6-Gang – FR680 (Use with PT27A or PT7XC)

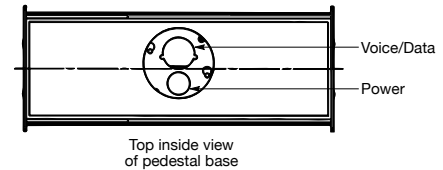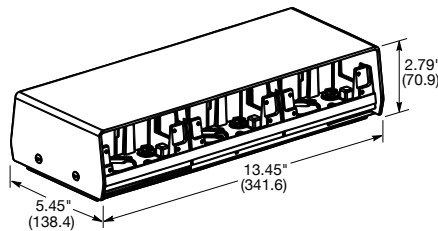

Total Cubic Inch Capacity (Single-Service)	117.00 in. (1916.4cm ³)
Cubic Inch Capacity (when divided for multi-service)	Power 58.5 in. (958.2cm ³) Voice/Data 58.5 in. (958.2cm ³)
Service Pedestal Construction	Heavy gauge galvanized steel frame with aluminum housing and face plates.
Pedestal Finish	Textured black or gray epoxy paint.

2-Gang – FR80AL (Use with PT7XC Only)

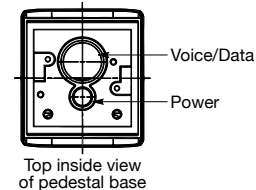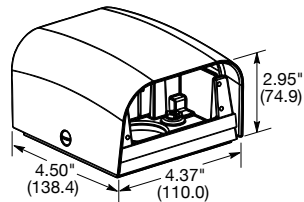

Total Cubic Inch Capacity (single service)	33.00 in. (540.9 cu cm ³)
Cubic Inch Capacity (when divided for multi-service)	Power 8.80 in. (144.2cm ³) Voice/Data 26.70 in. (437.6cm ³)
Service Pedestal Construction	Heavy gauge aluminum frame with satin anodized aluminum housing with 302/304 stainless steel face plates.
Pedestal Finish	Brushed.

Dimensions in Inches (mm)