



SNAPConnect® USB Charger Duplex Receptacles

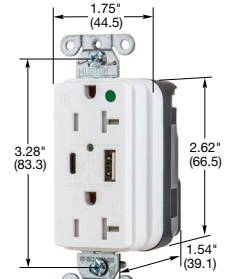


Description	Color	15A 125V AC	20A 125V AC
Hospital Grade SNAPConnect USB Charger, Tamper-Resistant Style Line® decorator duplex receptacle, 15 or 20 Amp, 125 Volt AC with one type A & one type-C USB port, 3 Amp up to 9 Volt USB output.	Black	SNAP8200UACBK	SNAP8300UACBK
	Brown	SNAP8200UAC	SNAP8300UAC
	Gray	SNAP8200UACGY	SNAP8300UACGY
	Ivory	SNAP8200UACI	SNAP8300UACI
	Light Almond	SNAP8200UACLA	SNAP8300UACLA
	Red	SNAP8200UACR	SNAP8300UACR
	White	SNAP8200UACW	SNAP8300UACW
SNAPConnect USB Charger, Tamper-Resistant Style Line® decorator duplex receptacle, 15 or 20 Amp, 125 Volt AC with one type A & one type-C USB port, 3 Amp up to 9 Volt USB output.	Black	SNAP15UACBK	SNAP20UACBK
	Brown	SNAP15UAC	SNAP20UAC
	Gray	SNAP15UACGY	SNAP20UACGY
	Ivory	SNAP15UACI	SNAP20UACI
	Light Almond	SNAP15UACLA	SNAP20UACLA
	White	SNAP15UACW	SNAP20UACW
Clear right angle terminal with 6 inch leads #12 AWG THHN/THWN-2; Polycarbonate housing material.	Solid	SNAP1RNA	SNAP1RNA
	Stranded	SNAP2RNA	SNAP2RNA



SNAP8300UACW

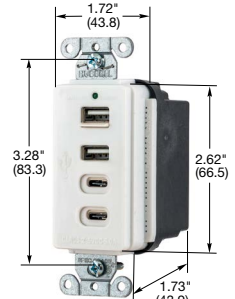

USB4W

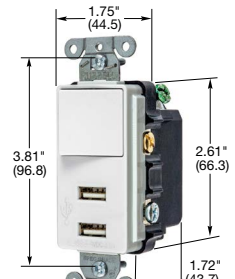

USB102W

4 Port USB Charger Outlets



Description	Color	Catalog Number
USB Charger Outlets, 4 USB ports, two Type A & two Type-C ports, 5 Amp up to 9 Volt DC, Style Line® decorator.	Black	USB4ACBK
	Brown	USB4AC
	Gray	USB4ACGY
	Ivory	USB4ACI
	Light Almond	USB4ACLA
	White	USB4ACW


Switch Combo Outlets



Description	Color	Catalog Number
Switch Combo Outlet, two USB type 2.0 ports, 2.1 Amp, 5 Volt DC, Style Line® decorator.	Black	USB102BK
	Brown	USB102
	Gray	USB102GY
	Ivory	USB102I
	Light Almond	USB102LA
	White	USB102W

2X2 USB Work Surface Pop-Up Boxes

Surface Dimensions	Cut Out Dimensions	Product Depth	Maximum Surface Thickness	Finish	Catalog Number
5" x 5"	4.62" x 4.62"	3.55"	1.125"	Brushed Aluminum	WSBUSB2X2ALU
5" x 5"	4.62" x 4.62"	3.55"	1.125"	Black Powder Coat	WSBUSB2X2BLK

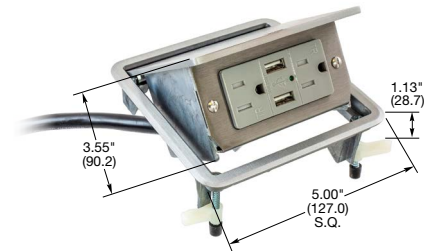


WSBUSB2X2ALU

PlugTrak® Raceway with USB Charger Outlets

USB type 2.0 ports, 2.4 Amp, 5 Volt DC, 15 Amp, 125 Volt AC receptacles.

Material	Length	Ends	# of USB Ports	# of Single Receptacles	Color	Catalog Number
Steel	3 ft.	6 in. leads	2	2	Ivory	HBL20GB312UIV
Steel	6 ft.	6 in. leads	4	4	Ivory	HBL20GB612UIV
Aluminium	3 ft.	6 in. leads	2	2	Aluminum	HBLALU20GB312U
Aluminium	6 ft.	6 in. leads	4	4	Aluminum	HBLALU20GB612U
Non-metallic	6 ft.	6 in. leads	4	8	Office White	PT156112U*
Portable - Plug in						
Steel	40 in.	6 ft. cord and plug	2	4	Ivory	HBL20C215UIV
Non-metallic	36 in.	6 ft. cord and plug	2	4	Office White	PT153112UP*

Note: *For additional colors add "BK" for Black or "W" for white.

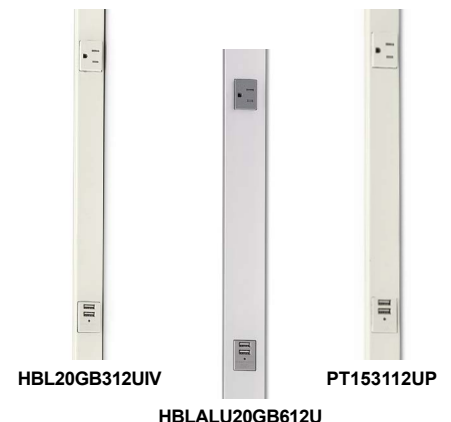

HBL20GB312UIV

HBLALU20GB612U

PT153112UP

Dimensions in Inches (mm)