



SNAPConnect® USB Charger Duplex Receptacles




Description	Color	15A 125V AC	20A 125V AC
Hospital Grade SNAPConnect USB Charger, Tamper-Resistant Style Line® decorator duplex receptacle, 15 or 20 Amp, 125 Volt AC with one type A & one type-C USB port, 3 Amp up to 9 Volt USB output.	Black Brown Gray Ivory Light Almond Red White	SNAP8200UACBK SNAP8200UAC SNAP8200UACGY SNAP8200UACI SNAP8200UACLA SNAP8200UACR SNAP8200UACW	SNAP8300UACBK SNAP8300UAC SNAP8300UACGY SNAP8300UACI SNAP8300UACLA SNAP8300UACR SNAP8300UACW
SNAPConnect USB Charger, Tamper-Resistant Style Line® decorator duplex receptacle, 15 or 20 Amp, 125 Volt AC with one type A & one type-C USB port, 3 Amp up to 9 Volt USB output.	Black Brown Gray Ivory Light Almond White	SNAP15UACBK SNAP15UAC SNAP15UACGY SNAP15UACI SNAP15UACLA SNAP15UACW	SNAP20UACBK SNAP20UAC SNAP20UACGY SNAP20UACI SNAP20UACLA SNAP20UACW
Clear right angle terminal with 6 inch leads #12 AWG THHN/THWN-2; Polycarbonate housing material.	Solid Stranded	SNAP1RA SNAP2RA	SNAP1RA SNAP2RA

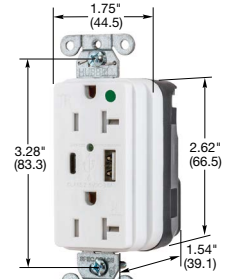

SNAP8300UACW

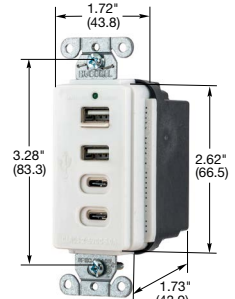

USB4W

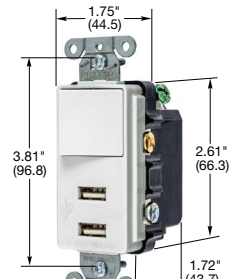

USB102W

4 Port USB Charger Outlets



Description	Color	Catalog Number
USB Charger Outlets, 4 USB ports, two Type A & two Type-C ports, 5 Amp up to 9 Volt DC, Style Line® decorator.	Black Brown Gray Ivory Light Almond White	USB4ACBK USB4AC USB4ACGY USB4ACI USB4ACLA USB4ACW


Switch Combo Outlets



Description	Color	Catalog Number
Switch Combo Outlet, two USB type 2.0 ports, 2.1 Amp, 5 Volt DC, Style Line® decorator.	Black Brown Gray Ivory Light Almond White	USB102BK USB102 USB102GY USB102I USB102LA USB102W

2X2 USB Work Surface Pop-Up Boxes

Surface Dimensions	Cut Out Dimensions	Product Depth	Maximum Surface Thickness	Finish	Catalog Number
5" x 5"	4.62" x 4.62"	3.55"	1.125"	Brushed Aluminum	WSBUSB2X2ALU
5" x 5"	4.62" x 4.62"	3.55"	1.125"	Black Powder Coat	WSBUSB2X2BLK

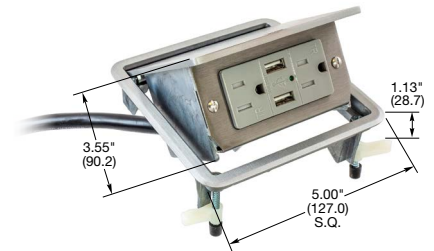

WSBUSB2X2ALU

PlugTrak® Raceway with USB Charger Outlets

USB type 2.0 ports, 2.4 Amp, 5 Volt DC, 15 Amp, 125 Volt AC receptacles.

Material	Length	Ends	# of USB Ports	# of Single Receptacles	Color	Catalog Number
Steel	3 ft.	6 in. leads	2	2	Ivory	HBL20GB312UIV
Steel	6 ft.	6 in. leads	4	4	Ivory	HBL20GB612UIV
Aluminium	3 ft.	6 in. leads	2	2	Aluminum	HBLALU20GB312U
Aluminium	6 ft.	6 in. leads	4	4	Aluminum	HBLALU20GB612U
Non-metallic	6 ft.	6 in. leads	4	8	Office White	PT156112U*
Portable - Plug in						
Steel	40 in.	6 ft. cord and plug	2	4	Ivory	HBL20C215UIV
Non-metallic	36 in.	6 ft. cord and plug	2	4	Office White	PT153112UP*



HBL20GB312UIV



HBLALU20GB612U



PT153112UP

Note: *For additional colors add "BK" for Black or "W" for white.

Dimensions in Inches (mm)