

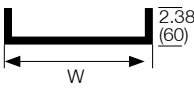
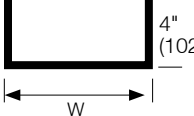
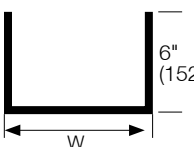
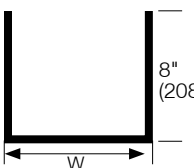
Wire Basket Tray System

Round Cross-Wire Basket Tray



Features

- T-weld construction prevents snags
- 5mm round wire minimum
- High load rating
- Easy to cut and fabricate fittings in the field
- 100% recycled steel
- 2" x 4" mesh opening
- Use factory support hardware or fabricate supports at the job site
- Painted tray includes factory installed masking to ensure proper grounding at splices; no need to remove paint during installation

10 Feet per Length 118.3" (3m) 10 pc. min. order qty. 2" Deep Tray	Tray Width	Load (Lb/ft)	Tray Weight per Length (Lb)	Splice Quantity*		Finish	
				90° Sweep Elbow	Straight Splice	Pre-Galvanized	Black Powder Coat
	4" (102)	45	7	2	2	HBT0204	HBT0204BK
	6" (152) ●	50	9	3	4	HBT0206	HBT0206BK
	8" (203) ●	52	10.5	4	4	HBT0208	HBT0208BK
	12" (305) ●	58	12	6	4	HBT0212	HBT0212BK
	16" (406) ●	70	15	7	4	HBT0216	HBT0216BK
	18" (457) ●	70	23	9	4	HBT0218	HBT0218BK
	20" (508) ●	73	25	9	5	HBT0220	HBT0220BK
	22" (559)	73	27	12	5	HBT0222	HBT0222BK
	24" (610) ●	75	31	12	5	HBT0224	HBT0224BK
	26" (660)	73	33	13	6	HBT0226	HBT0226BK
	28" (711)	73	35	14	6	HBT0228	HBT0228BK
	30" (762)	70	38	15	6	HBT0230	HBT0230BK
32" (813)	70	39	16	6	HBT0232	HBT0232BK	
	4" (102)	49	12	2	4	HBT0404	HBT0404BK
	6" (152) ●	49	13	3	5	HBT0406	HBT0406BK
	8" (203) ●	78	15	4	6	HBT0408	HBT0408BK
	12" (305) ●	78	23	6	6	HBT0412	HBT0412BK
	16" (406) ●	108	27	7	7	HBT0416	HBT0416BK
	18" (457) ●	116	29	9	7	HBT0418	HBT0418BK
	20" (508) ●	116	31	9	7	HBT0420	HBT0420BK
	22" (559)	116	33	12	8	HBT0422	HBT0422BK
	24" (610) ●	116	35	12	8	HBT0424	HBT0424BK
	28" (711)	108	39	14	9	HBT0428	HBT0428BK
	8" (203) ●	116	23	4	6	HBT0608	HBT0608BK
	12" (305) ●	123	27	6	6	HBT0612	HBT0612BK
	16" (406) ●	123	31	7	7	HBT0616	HBT0616BK
	18" (457) ●	127	33	9	7	HBT0618	HBT0618BK
	20" (508) ●	127	35	9	7	HBT0620	HBT0620BK
	22" (559) ●	127	37	12	8	HBT0622	HBT0622BK
	24" (610) ●	150	39	12	8	HBT0624	HBT0624BK
	8" (203) ●	116	27	4	8	HBT0808	HBT0808BK
	12" (305) ●	116	31	6	8	HBT0812	HBT0812BK
	16" (406) ●	116	35	7	9	HBT0816	HBT0816BK
	18" (457) ●	116	37	9	9	HBT0818	HBT0818BK
	20" (508) ●	116	39	9	9	HBT0820	HBT0820BK

Field Configurable Fittings

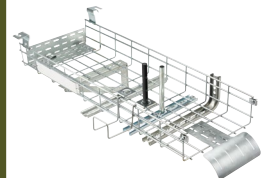


90° Sweep Elbow
Use appropriate quantity of splice kits



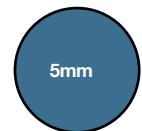
Tee Fitting
Use one HBTC5 corner splice per each

Supports and Hardware



Ordering Information
See page U-12

Wire Diameter



.1969" Dia.
"Round" Wire Design

Note: ●UL Classified as equipment ground conductor (painted tray cUL Classified only).
All dimensions are +/- 0.25". Custom paint colors available in addition to Black Powder Coat (Contact Hubbell).
*See page U-13 for details and page U-14 for wire fill and maximum load chart.
HBT0202 (2x2 tray) available as special order. MOQ 40 pcs. Top wire utilizes side weld.

Dimensions in Inches (mm)