

# Hose and Cable Protection Systems


## ProTrak™ Systems

For Pedestrian and Light Vehicle Traffic

- High density polyurethane construction supports heavy loads and is weather resistant
- Modular interlocking design for easy installation, breakdown and storage
- Safety surface pattern reduces slipping and skidding
- High visibility safety yellow and black
- Anti-slip pad kits available



ProTrak™ Systems	Trak			Channel			Catalog Number
	A	B	C	D	E	Weight	
Description	Length in. (mm)	Width in. (mm)	Height in. (mm)	Width in. (mm)	Height in. (mm)	lbs. (kg)	
1 Channel, drop over, yellow	36.0" (914)	5.25" (133)	.75" (19.0)	1.50" (38.1)	.50" (12.7)	3.00 (1.40)	<b>PROTRK115Y</b>
1 Channel, drop over, black	36.0" (914)	5.25" (133)	.75" (19.0)	1.50" (38.1)	.50" (12.7)	3.00 (1.40)	<b>PROTRK115BK</b>
1 Channel, drop over, yellow	36.0" (914)	10.75" (273)	1.50" (38.1)	4.00" (101.6)	1.00" (25.4)	8.00 (3.60)	<b>PROTRK140Y</b>
1 Channel, drop over, black	36.0" (914)	10.75" (273)	1.50" (38.1)	4.00" (101.6)	1.00" (25.4)	8.00 (3.60)	<b>PROTRK140BK</b>
1 Channel, hinged cover, yellow	36.0" (914)	10.81" (274)	1.25" (31.8)	2.25" (57.2)	.75" (19.0)	7.80 (3.54)	<b>PROTRK1225Y</b>
1 Channel, hinged cover, black	36.0" (914)	10.81" (274)	1.25" (31.8)	2.25" (57.2)	.75" (19.0)	7.80 (3.54)	<b>PROTRK1225BK</b>

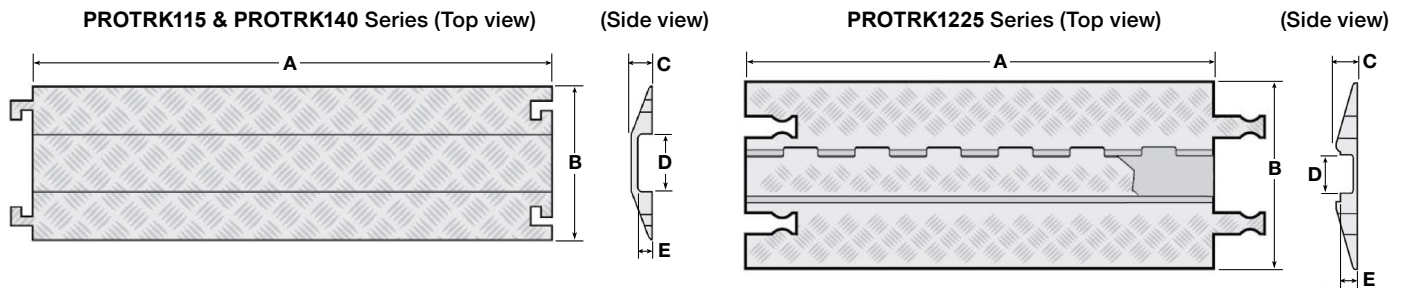

## Accessories

ProTrak Series	Anti-Slip Pad Kits*
PROTRK115	<b>PROTRK1ASPK</b>
PROTRK140	<b>PROTRK2ASPK</b>
PROTRK1225	<b>PROTRK3ASPK</b>

\*One kit per section



## Load Capacity

Product	Test Fixture Footprint Inches (mm)	Tire Load lbs. +/- 20%	Axle Load lbs. +/- 20%
		70°F (21°C)	70°F (21°C)
PROTRK115	6.9" x 17.3" (175 X 439)	10,500	21,000
PROTRK140	6.9" x 17.3" (175 X 439)	10,500	21,000
PROTRK1225	6.9" x 17.3" (175 X 439)	13,000	26,000

Dimensions in Inches (mm)