

T-Type Grips

Kellems® Flexible T-Type Pulling Grips are made of high strength galvanized steel strand. They feature double weave mesh for positive holding power in medium to heavy pulling jobs. The grip eye will easily attach to a swivel.

IMPORTANT:

Read all breaking strength, safety and technical data relating to this product.


Refer to pages W-17 and W-18.

Application

T-Type Pulling Grips are used for the installation of underground power cables, communication lines and service lines into factories, construction projects and for general underground electrical construction. Available in two mesh lengths, short for medium pulls and standard for general purpose pulling.

Benefits

- Will pull a single cable or cable bundles
- Patented flexible eye design provides flexibility to follow line of pull
- A dependable, reusable pulling tool
- Easily installed and removed
- Mates easily with a swivel, see page W-16

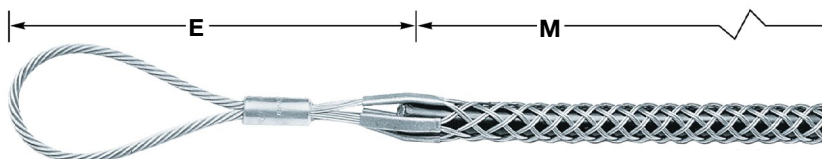

T-Type Grips

Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs.	Working Load Lbs.	E Inches (cm)	M Inches (cm)	Catalog Number
Short					
.50"-.62" (1.27-1.57)	4,500	900	8" (20.32)	21" (53.34)	033041082
.63"-.74" (1.60-1.88)	5,600	1,120	8" (20.32)	24" (60.96)	033041083
.75"-.99" (1.90-2.51)	6,800	1,360	9" (22.86)	24" (60.96)	033041084
1.00"-1.49" (2.54-3.78)	9,600	1,920	9" (22.86)	24" (60.96)	033041085
1.50"-1.99" (3.81-5.05)	16,400	3,280	11" (27.94)	24" (60.96)	033041086
2.00"-2.49" (5.08-6.32)	18,500	3,700	12" (30.48)	24" (60.96)	033041087
2.50"-2.99" (6.35-7.59)	24,500	4,900	12" (30.48)	24" (60.96)	033041088
3.00"-3.49" (7.62-8.86)	24,500	4,900	14" (35.56)	24" (60.96)	033041089
3.50"-3.99" (8.89-10.13)	31,000	6,200	14" (35.56)	26" (66.04)	033041090
Standard					
.75"-.99" (1.90-2.51)	6,800	1,360	9" (22.86)	36" (91.44)	033041091
1.00"-1.49" (2.54-3.78)	9,600	1,920	9" (22.86)	36" (91.44)	033041092
1.50"-1.99" (3.81-5.05)	16,400	3,280	11" (27.94)	36" (91.44)	033041093
2.00"-2.49" (5.08-6.32)	18,500	3,700	12" (30.48)	36" (91.44)	033041094
2.50"-2.99" (6.35-7.59)	24,500	4,900	12" (30.48)	36" (91.44)	033041095
3.00"-3.49" (7.62-8.86)	24,500	4,900	14" (35.56)	36" (91.44)	033041096
3.50"-3.99" (8.89-10.13)	31,000	6,200	14" (35.56)	40" (101.60)	033041097

Note: E- Eye length. M-Mesh length at nominal diameter.
See page W-18 for multiple cables in a single pulling grip.