

Slack Pulling Grips

Slack Pulling Grips are offered in two styles made of galvanized steel. The closed type is used when the cable end is accessible. When not accessible, there are split rod closing styles. All grips feature a single offset eye for easy attachment to a pulling line.


IMPORTANT:

Read all breaking strength, safety and technical data relating to this product.

Refer to pages W-17 and W-18.

Benefits

- Easy attachment to pulling lines
- Galvanized steel for strength

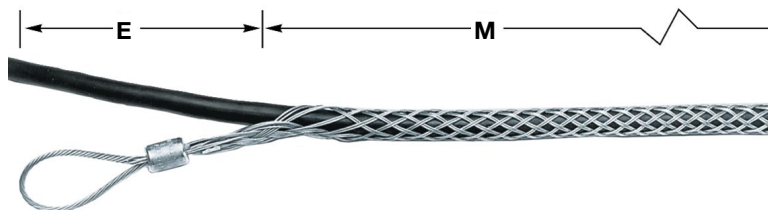


Slack Grip-Closed Mesh, Offset Eye, Double Weave, Galvanized Steel

Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs.	Working Load Lbs.	E Inches (cm)	M Inches (cm)	Catalog Number
Standard					
.75"- .99" (1.90-2.51)	2,600	520	7" (17.78)	12" (30.48)	03308003
1.00"-1.24" (2.54-3.15)	4,000	800	8" (20.32)	15" (38.10)	03308004
1.25"-1.49" (3.17-3.78)	5,400	1,080	8" (20.32)	16" (40.64)	03308005
1.50"-1.74" (3.81-4.42)	6,600	1,320	8" (20.32)	20" (50.80)	03308006
1.75"-1.99" (4.44-5.05)	10,000	2,000	10" (25.40)	18" (45.72)	03308007
2.00"-2.49" (5.08-6.32)	11,000	2,200	10" (25.40)	19" (48.26)	03308008
2.50"-2.99" (6.35-7.59)	11,000	2,200	10" (25.40)	20" (50.80)	03308009
3.00"-3.49" (7.62-8.86)	14,500	2,900	12" (30.48)	21" (53.34)	03308010
3.50"-3.99" (8.89-10.13)	14,500	2,900	12" (30.48)	22" (55.88)	03308011

Note: E- Eye length. M-Mesh length at nominal diameter.

See page W-18 for multiple cables in a single pulling grip.

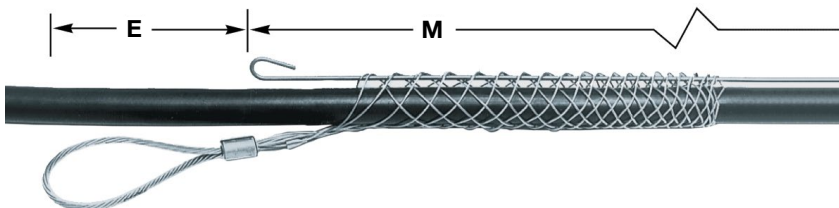

Slack Grip-Split Mesh, Rod Closing, Offset Eye, Single Weave, Galvanized Steel

Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs.	Working Load Lbs.	E Inches (cm)	M Inches (cm)	Catalog Number
.50"- .61" (1.27-1.55)	1,500	300	7" (17.78)	6" (15.24)	03310001
.62"- .74" (1.57-1.88)	1,800	360	7" (17.78)	8" (20.32)	03310002
.75"- .99" (1.90-2.51)	2,200	440	7" (17.78)	10" (25.40)	03310003
1.00"-1.24" (2.54-3.15)	3,400	680	8" (20.32)	12" (30.48)	03310004
1.25"-1.49" (3.17-3.78)	4,500	900	8" (20.32)	14" (35.56)	03310005
1.50"-1.74" (3.81-4.42)	5,800	1,160	9" (22.86)	15" (38.10)	03310006
1.75"-1.99" (4.44-5.05)	7,600	1,520	10" (25.40)	16" (40.64)	03310007
2.00"-2.49" (5.08-6.32)	9,000	1,800	10" (25.40)	19" (48.26)	03310008
2.50"-2.99" (6.35-7.59)	11,000	2,200	10" (25.40)	20" (50.80)	03310009
3.00"-3.49" (7.62-8.86)	12,000	2,400	12" (30.48)	21" (53.34)	03310010
3.50"-3.99" (8.89-10.13)	12,000	2,400	12" (30.48)	24" (60.96)	03310011

Note: E- Eye length. M-Mesh length at nominal diameter.

See page W-35 for closing instructions.

See page W-18 for multiple cables in a single pulling grip.

Dimensions in Inches (mm)