

Service Drop Grips

Universal Eye, Tin-Coated Bronze.

IMPORTANT:

Read all breaking strength, safety and technical data relating to this product.

Refer to pages W-33 and W-34.

Light Duty, Universal Eye, Closed Mesh, Single Weave

For permanent support when cable end is available to be installed.


Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs.	Working Load Lbs.	E Inches (cm)	M Inches (cm)	Catalog Number
.23"-.31" (.58-.79)	290	29	9" (22.86)	3.75" (9.52)	02216016
.29"-.37" (.74-.94)	290	29	10" (25.40)	4.25" (10.79)	02216017
.35"-.44" (.89-1.12)	500	50	10" (25.40)	4.75" (12.06)	02216018
.41"-.50" (1.04-1.27)	500	50	11" (27.94)	5" (12.70)	02216019
.46"-.56" (1.17-1.42)	660	66	12" (30.48)	5.25" (13.33)	02216020
.52"-.62" (1.32-1.57)	790	79	13" (33.02)	6.25" (15.87)	02216021
.58"-.68" (1.47-1.73)	790	79	13" (33.02)	6.5" (16.51)	02216022
.64"-.75" (1.63-1.90)	790	79	13" (33.02)	6.75" (17.14)	02216023
.70"-.81" (1.78-2.06)	790	79	13" (33.02)	7.25" (18.41)	02216024
.75"-.87" (1.90-2.21)	1,020	102	14" (35.56)	8" (20.32)	02216025
.81"-.94" (2.06-2.39)	1,020	102	14" (35.56)	8.25" (20.95)	02216026
.87"-1.00" (2.21-2.54)	1,020	102	14" (35.56)	8.75" (22.22)	02216027
.94"-1.06" (2.39-2.69)	1,020	102	15" (38.10)	9" (22.86)	02216028
1.00"-1.18" (2.54-3.00)	1,020	102	15" (38.10)	9.5" (24.13)	02216029
1.06"-1.25" (2.69-3.17)	1,020	102	15" (38.10)	9.5" (24.13)	02216030



Heavy Duty, Universal Eye, Closed Mesh, Multi-Weave

For permanent support when cable end is available to be installed.

Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs.	Working Load Lbs.	E Inches (cm)	M Inches (cm)	Catalog Number
.23"-.31" (.58-.79)	500	50	11" (27.94)	4.5" (11.43)	02217016
.28"-.37" (.74-.94)	500	50	11" (27.94)	5.5" (13.97)	02217017
.35"-.44" (.89-1.12)	870	87	12" (30.48)	6.5" (16.51)	02217018
.41"-.50" (1.04-1.27)	870	87	12" (30.48)	7.5" (19.05)	02217019
.46"-.56" (1.17-1.42)	1,050	105	12" (30.48)	8" (20.32)	02217020
.52"-.62" (1.32-1.57)	1,050	105	13" (33.02)	8.5" (21.59)	02217021
.58"-.68" (1.47-1.73)	1,050	105	13" (33.02)	9.5" (24.13)	02217022
.64"-.75" (1.63-1.90)	1,390	139	13" (33.02)	9.5" (24.13)	02217023
.70"-.81" (1.78-2.06)	1,390	139	14" (35.56)	10.5" (26.67)	02217024
.75"-.87" (1.90-2.21)	1,390	139	14" (35.56)	10.5" (26.67)	02217025
.81"-.94" (2.06-2.39)	1,390	139	14" (35.56)	10.5" (26.67)	02217026
.87"-1.00" (2.21-2.54)	1,790	179	14" (35.56)	11.5" (29.21)	02217027
.94"-1.06" (2.39-2.69)	1,790	179	15" (38.10)	12.5" (31.75)	02217028
1.00"-1.18" (2.54-3.00)	1,790	179	15" (38.10)	13.5" (34.29)	02217029
1.06"-1.25" (2.69-3.17)	1,790	179	15" (38.10)	14.5" (36.83)	02217030

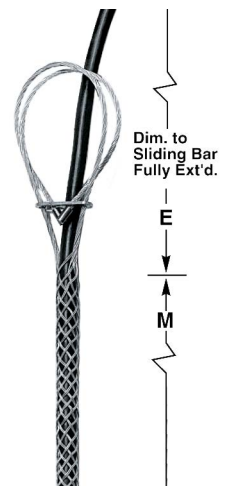

Note: E-Eye length. M-Mesh length at nominal diameter.

Dimensions in Inches (mm)