

## Hose Containment Grips

Kellems® Hose Containment Grips are used on high pressure, flexible hose lines to prevent the hose from whipping violently in the event of hose failure at the fitting. These grips will prevent serious injury to personnel and damage to equipment by holding the hose in place in the event of hose failure.


Kellems® patented Hose Containment Grips are made of stainless steel double weave mesh construction for high strength and come complete with hose clamps.

### IMPORTANT:

Read all breaking strength, safety and technical data relating to this product.

## Types of Attachment


The six attachment methods shown below provide unlimited flexibility of attachment to meet any condition.

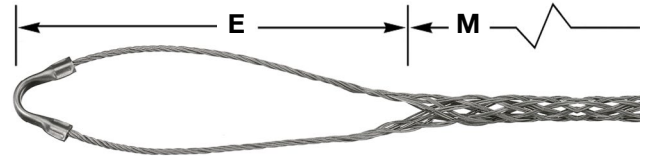

### Type A

Single Eye, used where fastening is made with eyebolts or similar anchor terminations.


Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs.	Working Load Lbs.	E Inches (cm)	M Inches (cm)	Catalog Number
.38"-.69" (.97-1.75)	2,900	290	10" (25)	24" (61)	<b>014021285</b>
.50"-.94" (1.27-2.39)	3,400	340	10" (25)	24" (61)	<b>014021230</b>
1.00"-1.56" (2.54-3.96)	9,400	940	10" (25)	36" (91)	<b>014021453</b>
1.25"-1.94" (3.18-4.93)	14,400	1,440	48" (122)	60" (152)	<b>014021593</b>
2.75"-3.44" (6.99-8.74)	12,500	1,250	10" (25)	48" (122)	<b>014021524</b>

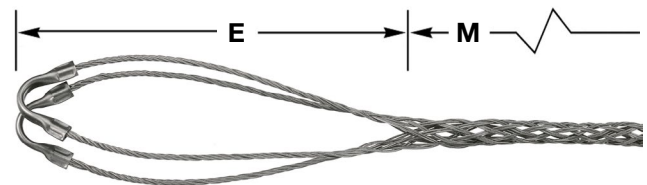

### Type E

Double Eye Grip, used where fastening is made with eyebolts or similar anchor terminations.

Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs.	Working Load Lbs.	E Inches (cm)	M Inches (cm)	Catalog Number
.50"-.94" (1.27-2.39)	4,250	425	8" (20)	24" (61)	<b>014021224</b>
.75"-1.25" (1.91-3.18)	6,000	600	8" (20)	24" (61)	<b>014021223</b>
1.00"-1.56" (2.54-3.96)	8,000	800	8" (20)	24" (61)	<b>014021279</b>

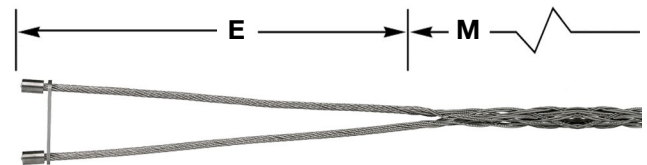

### Type U

Universal Bale Grip, used to fasten around a structure or closed eye.

Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs.	Working Load Lbs.	E Inches (cm)	M Inches (cm)	Catalog Number
.31"-.56" (.79-1.42)	2,100	210	12" (30)	24" (61)	<b>014021304</b>
.38"-.69" (.97-1.75)	2,600	260	12" (30)	24" (61)	<b>014021308</b>
.50"-.94" (1.27-2.39)	3,100	310	12" (30)	24" (61)	<b>014021138</b>
.50"-.94" (1.27-2.39)	3,100	310	24" (61)	24" (61)	<b>014021139</b>
.75"-1.25" (1.91-3.18)	4,500	450	12" (30)	24" (61)	<b>014021140</b>
1.00"-1.56" (2.54-3.96)	6,000	600	12" (30)	24" (61)	<b>014021142</b>
1.25"-1.94" (3.18-4.93)	6,000	600	12" (30)	36" (91)	<b>014021527</b>

Note: E- Eye length. M-Mesh length at nominal diameter.

It should be emphasized that Kellems® Hose Containment Grips are not to be used as a pressure reinforcing device for hose systems. These grips are custom made. Consult Technical Services for details.

Dimensions in Inches (mm)