


## Hose Containment Grips

Kellems Hose Containment Grips are supplied in diameters, length and attachments to meet individual requirements. Contact the Wiring Device-Kellems factory for specific information. These grips help meet OSHA Federal Register 1926-302 (b), 1926-603 (9), (10), JIC H-1-1973 (H13.11) and JIC P-1-1975 (P11.34) requirements.

### IMPORTANT:


Read all breaking strength, safety and technical data relating to this product.

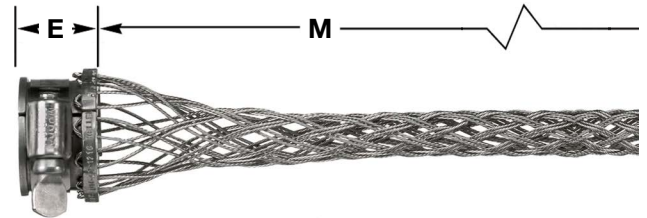

### Type F

Split fitting to fit AN-818 nuts. Fitting is positioned over nut and located with internal flange. A hose clamp is furnished and required to hold the fitting in correct position.

Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs.	Working Load Lbs.	E Inches (cm)	M Inches (cm)	Catalog Number
.38"-.69" (.97-1.75)	2,900	290	1" (2.54)	24" (61)	<b>014021208</b>
.50"-.94" (1.27-2.39)	3,400	340	1" (2.54)	24" (61)	<b>014021156</b>
.50"-.94" (1.27-2.39)	3,400	340	1" (2.54)	12" (30)	<b>014021185</b>
.50"-.94" (1.27-2.39)	3,400	340	1" (2.54)	12" (30)	<b>014021186</b>
.50"-.94" (1.27-2.39)	3,400	340	1" (2.54)	24" (61)	<b>014021216</b>
.75"-1.25" (1.91-3.18)	6,000	600	1" (2.54)	24" (61)	<b>014021113</b>
.75"-1.25" (1.91-3.18)	6,000	600	1" (2.54)	12" (30)	<b>014021120</b>
.75"-1.25" (1.91-3.18)	6,000	600	1" (2.54)	24" (61)	<b>014021301</b>
1.00"-1.56" (2.54-3.96)	6,000	600	1" (2.54)	24" (61)	<b>014021157</b>
1.00"-1.56" (2.54-3.96)	8,000	800	1.12" (2.84)	24" (61)	<b>014021366</b>
1.25"-1.94" (3.18-4.93)	8,000	800	1.12" (2.84)	36" (91)	<b>014021314</b>

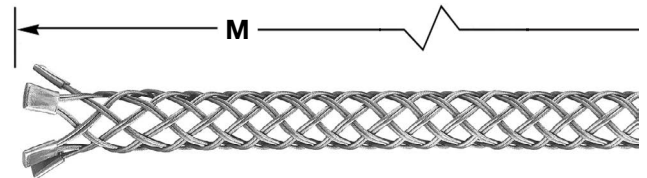

### Type T

Tube Grips obtain complete grip coverage when hose is partially covered at either end with attachment grips. Type T-Grips fill in the exposed hose area between the two end grips. A telescoped assembly permits overlap to any degree desired beyond the 3" minimum.

Cable Diameter Range Inches (cm)	Approx. Breaking Strength Lbs.	Working Load Lbs.	E Inches (cm)	M Inches (cm)	Catalog Number
.50"-.94" (1.27-2.39)	3,400	340	—	24" (61)	<b>014021152</b>
.75"-1.25" (1.91-3.18)	6,000	600	—	24" (61)	<b>014021085</b>
1.44"-2.19" (3.66-5.56)	12,500	1,250	—	48" (122)	<b>014021075</b>

Note: E- Eye length. M-Mesh length at nominal diameter.



### Type Y

Threaded bolt (5/16 – 18 x 1 1/2" long), used to fasten through drilled holes in a plate.

Note: Available upon request.

It should be emphasized that Kellems® Hose Containment Grips are not to be used as a pressure reinforcing device for hose systems. Kellems® Hose Containment Grips are supplied in diameters, length and attachments to meet individual requirements. Contact Technical services for specific information.

Dimensions in Inches (mm)