

## Deluxe Cord Grips

Aluminum Fittings, Stainless Steel Mesh, Liquidtight for Insulated Cables.


### IMPORTANT:

Read all safety and technical data relating to this product.

Refer to pages W-61 through W-68.

### Straight Male Thread

NPT Thread Size Inches	Grip Diameter Range Inches (cm)		Form Size	Catalog Number
3/8	.250"-.312"	(.63-.79)	F1	<b>07401001</b>
	.312"-.375"	(.79-.95)		<b>07401002</b>
	.375"-.437"	(.95-1.11)		<b>07401003</b>
1/2	.187"-.250"	(.47-.63)	F2	<b>07401004</b>
	.250"-.375"	(.63-.95)		<b>07401006</b>
	.375"-.500"	(.95-1.27)		<b>07401008</b>
1/2	.500"-.625"	(1.27-1.59)	F3	<b>07401010</b>
	.625"-.750"	(1.59-1.90)		<b>074011247*</b>
	.750"-.875"	(1.90-2.22)		<b>074011248*</b>
3/4	.187"-.250"	(.47-.63)	F2	<b>07401011</b>
	.250"-.375"	(.63-.95)		<b>07401013</b>
	.375"-.500"	(.95-1.27)		<b>07401015</b>
3/4	.500"-.625"	(1.27-1.59)	F3	<b>07401017</b>
	.625"-.750"	(1.59-1.90)		<b>07401018</b>
	.750"-.875"	(1.90-2.22)		<b>074011249*</b>
1	.375"-.500"	(.95-1.27)	F4	<b>074011195</b>
	.500"-.625"	(1.27-1.59)		<b>07401019</b>
	.625"-.750"	(1.59-1.90)		<b>07401021</b>
1	.750"-.875"	(1.90-2.22)	F4	<b>07401023</b>
	.875"-.1.000"	(2.22-2.54)		<b>07401025</b>
	1.000"-.1.125"	(2.54-2.86)		<b>074011250*</b>
1	1.125"-.1.250"	(2.86-3.17)	F5	<b>074011028*</b>
	1.250"-.1.375"	(3.17-3.49)		<b>074011029*</b>
	.750"-.875"	(1.90-2.22)		<b>074011251</b>
1 1/4	.875"-.1.000"	(2.22-2.54)	F5	<b>07401026</b>
	1.000"-.1.125"	(2.54-2.86)		<b>07401027</b>
	1.125"-.1.250"	(2.86-3.17)		<b>07401028</b>
1 1/4	1.250"-.1.375"	(3.17-3.49)	F5	<b>074011178*</b>
	.750"-.875"	(1.90-2.22)		<b>074011252</b>
	.875"-.1.000"	(2.22-2.54)		<b>07401029</b>
1 1/2	1.000"-.1.125"	(2.54-2.86)	F5	<b>07401030</b>
	1.125"-.1.250"	(2.86-3.17)		<b>07401031</b>
	1.250"-.1.375"	(3.17-3.49)		<b>07401032</b>
1 1/2	1.312"-.1.437"	(3.33-3.65)	F6	<b>074011253</b>
	1.437"-.1.562"	(3.65-3.97)		<b>074011254*</b>
	1.562"-.1.687"	(3.97-4.28)		<b>074011255*</b>
1 1/2	1.687"-.1.812"	(4.28-4.60)	F6	<b>074011256*</b>
	1.750"-.1.875"	(4.44-4.76)		<b>074011257*</b>
	1.250"-.1.375"	(3.17-3.49)		<b>074011258</b>
2	1.312"-.1.437"	(3.33-3.65)	F6	<b>074011259</b>
	1.437"-.1.562"	(3.65-3.97)		<b>07401033</b>
	1.562"-.1.687"	(3.97-4.28)		<b>07401034</b>
2	1.687"-.1.812"	(4.28-4.60)	F6	<b>07401035</b>
	1.750"-.1.875"	(4.44-4.76)		<b>074011260</b>
	1.812"-.1.937"	(4.60-4.92)		<b>074011261</b>
2	1.937"-.2.062"	(4.92-5.24)	F7	<b>074011262*</b>
	2.062"-.2.187"	(5.24-5.55)		<b>074011263*</b>
	2.187"-.2.312"	(5.55-5.87)		<b>074011264*</b>
2	2.312"-.2.437"	(5.87-6.19)	F7	<b>074011265*</b>
	1.688"-.1.812"	(4.29-4.60)		<b>074011030</b>
	1.812"-.1.937"	(4.60-4.92)		<b>074011031</b>
2 1/2	1.937"-.2.062"	(4.92-5.24)	F7	<b>074011032</b>
	2.062"-.2.187"	(5.24-5.55)		<b>074011033</b>
	2.187"-.2.312"	(5.55-5.87)		<b>074011034</b>
2 1/2	2.312"-.2.437"	(5.87-6.19)	F7	<b>074011266*</b>
	1.937"-.2.062"	(4.92-5.24)		<b>074011036</b>
	2.062"-.2.187"	(5.24-5.55)		<b>074011037</b>
3	2.187"-.2.312"	(5.55-5.87)	F7	<b>074011038</b>
	2.312"-.2.437"	(5.87-6.19)		<b>074011039</b>
	2.437"-.2.625"	(6.19-6.67)		<b>074011186</b>
3	2.625"-.2.812"	(6.67-7.14)	F8	<b>074011187</b>
	2.812"-.3.000"	(7.14-7.62)		<b>074011188</b>
	3.000"-.3.250"	(7.62-8.25)		<b>074011189*</b>

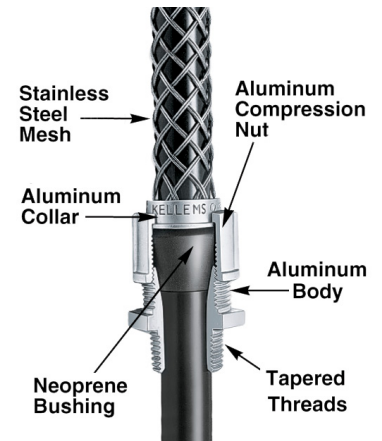

Note: Kellems® Deluxe Cord Grips are suitable for use in hazardous locations per Class I Div. 2, Class II Div. 1 & 2, Class III Div. 1 & 2 of the National Electric Code Sections 501.10(b)(2), 502.10(a)(2), 502.10(b)(2), 503.10(a)(2) and 503.10(b).  
\*Cable jacket may have to be stripped to pass through connector body.

Dimensions in Inches (mm)