


## Av Wall Boxes

### Gangable boxes

Deliver data, AV, and power side-by-side with these oversized in-wall boxes. Designed to install independently or ganged together for multiple devices. Perfect for Cat6 and 6A fiber optic cables that require a larger bend radius.

- 4" depth accepts any device
- Knockouts from 1/2" up to 2"
- Accepts low voltage partition
- NEMA spaced device mounting, accepts industry standard wallplates
- Adjustable stud mounting brackets and far side support
- Suitable for masonry application

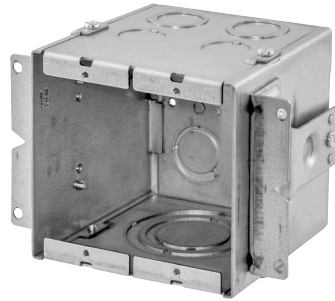

### Gangable AV Wall Boxes

Box Description	Knockouts			Catalog Number
	Top	Bottom	Back	
2-Gang, 2 in. KO, 54 in <sup>3</sup> capacity, 4.21" X 4.06" X 4"	(2) 1/2" (2) 1/2" - 3/4" TKO	(1) 1", 1 1/4", 1 1/2", 2"	(2) 1/2"-3/4"	<b>HBL985</b>
3-Gang, 2 in. KO, 79 in <sup>3</sup> capacity, 4.21" X 5.87" X 4"	(3) 1/2" (3) 1/2" - 3/4" TKO	(1) 1/2" (1) 1/2" - 3/4" TKO (1) 1", 1 1/4", 1 1/2", 2"	(3) 1/2"-3/4"	<b>HBL986</b>
4-Gang, 2 in. KO, 104 in <sup>3</sup> capacity, 4.21" X 7.69" X 4"	(4) 1/2" (4) 1/2" - 3/4" TKO	(1) 1/2" (1) 1/2" - 3/4" TKO (2) 1", 1 1/4", 1 1/2", 2"	(4) 1/2"-3/4"	<b>HBL987</b>
6-Gang, 2 in. KO, 154 in <sup>3</sup> capacity, 4.21" X 11.31" X 4"	(6) 1/2" (6) 1/2" - 3/4" TKO	(1) 1/2" (1) 1/2" - 3/4" TKO (2) 1", 1 1/4", 1 1/2", 2"	(6) 1/2"-3/4"	<b>HBL988</b>



### Low Voltage AV Wallbox Partition

For use with	Type	Catalog Number
HBL985, HBL986, HBL987 and HBL988	Solid divider With pass-thru capability	<b>HBL989</b> <b>HBL989AVD</b>

Dimensions in Inches (mm)