
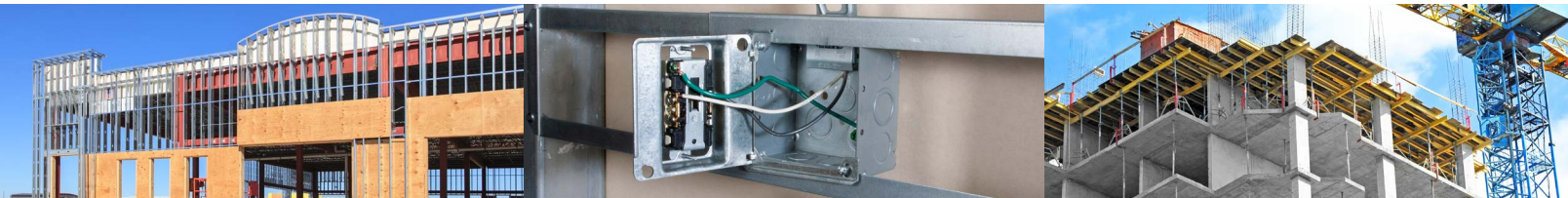


4" Square boxes

Regular or STAB-IT® boxes

These popular boxes are available with our unique connectors built into the box. Terminate MC cable in one third the time of other clamps. Models are available with connectors for two or four cables. Available mounting brackets and cable management offer the first means of support.

- 2-cable STAB-IT connectors install 3 times faster than traditional connectors
- Designed for quick installation of flex, MC, MCI, MCI-A, MC-PCS, AC, and HCF Cable
- HBL232MSCM & HBL232MS includes far-side support on back
- Includes ground wires, box mounting brackets and cable clamps
- Easier installation for labor savings

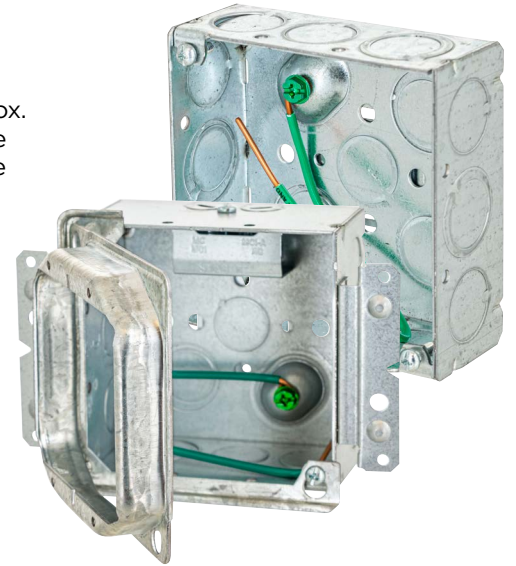

Boxes

Boxes are 4" square, 2-1/8" deep. They are constructed with welded steel and have raised grounds. The boxes have 30.3 in.³ capacity.

Box Description	Side Knock Outs			Back Knock Outs		
	Concentric	TKO	Cable Pry-outs	Concentric	TKO	Catalog Number
Standard	(8) 1/2"	(4) 1/2"-3/4"		(2) 1/2"	(2) 1/2"-3/4"	HBL232
10" Solid #12 Ground Pigtail	(8) 1/2"	(4) 1/2"-3/4"		(2) 1/2"	(2) 1/2"-3/4"	HBL232SM
(1) STAB-IT Connector, 8" Solid #12 Ground Pigtail	(6) 1/2"	(3) 1/2"-3/4"	2	(1) 1/2"	(1) 1/2"-3/4"	HBL232S
(1) STAB-IT Connector, 8" Solid #12 Ground Pigtail, Back- Far Side Support, and (2) Mounting Brackets	(6) 1/2"	(3) 1/2"-3/4"	2	(1) 1/2"	(1) 1/2"-3/4"	HBL232MS
(1) STAB-IT Connector, 8" Solid #12 Ground Pigtail, and (1) Cable Management Clamp	(6) 1/2"	(3) 1/2"-3/4"	2	(1) 1/2"	(1) 1/2"-3/4"	HBL232SCM
(1) STAB-IT Connector, 8" Solid #12 Ground Pigtail, Back- Far Side Support, (1) Cable Management Clamp, and (2) Mounting Brackets	(6) 1/2"	(3) 1/2"-3/4"	2	(1) 1/2"	(1) 1/2"-3/4"	HBL232MSCM
(2) STAB-IT Connectors, 8" Solid #12 Ground Pigtail, Back- Far Side Support, (2) Cable Management Clamp, and (2) Mounting Brackets	(6) 1/2"	(3) 1/2"-3/4"	4	(1) 1/2"	(1) 1/2"-3/4"	HBL244MSCM
(2) STAB-IT Connectors, 8" Solid #12 Ground Pigtail	(4) 1/2"	(2) 1/2"-3/4"	4	(1) 1/2"		HBL248S



Boxes

Boxes are 4" square, 1 1/2" deep, and have 21 in.³ capacity. Use with standard cable connectors.

Box Description	Side Knock Outs		Back Knock Outs		
	Concentric	TKO	Concentric	TKO	Catalog Number
Welded Steel, Raised Ground, 8" Solid #12 Ground Pigtail	(8) 1/2"	(4) 1/2"-3/4"	(2) 1/2"	(2) 1/2"-3/4"	HBL189F
Welded Steel, Raised Ground, 10" Solid #12 Ground Pigtail	(8) 1/2"	(4) 1/2"-3/4"	(2) 1/2"	(2) 1/2"-3/4"	HBL189SM*
Welded Steel, Long Side Mounting Brackets	(8) 1/2"	(4) 1/2"-3/4"	(3) 1/2"	(2) 1/2"-3/4"	HBL196
Welded Steel, Raised Ground, 10" Solid #12 Ground Pigtail	(8) 1/2", (4) 3/4"		(2) 1/2", (2) 3/4"		HBL232SCM

*cULus

Dimensions in Inches (mm)