

## Wallplate Frames, Delivery Bezels, Modules and Gangable AV Wallboxes



### Hubbell iSTATION Modular Wallplate Frames

Single-service, low voltage


| Color        | 1-Gang        | 2-Gang        | 3-Gang        | 4-Gang        |
|--------------|---------------|---------------|---------------|---------------|
| Black        | <b>IMF1BK</b> | <b>IMF2BK</b> | <b>IMF3BK</b> | <b>IMF4BK</b> |
| Gray         | <b>IMF1GY</b> | <b>IMF2GY</b> | <b>IMF3GY</b> | <b>IMF4GY</b> |
| Ivory        | <b>IMF1EI</b> | <b>IMF2EI</b> | <b>IMF3EI</b> | <b>IMF4EI</b> |
| Office White | <b>IMF1OW</b> | <b>IMF2OW</b> | <b>IMF3OW</b> | <b>IMF4OW</b> |
| White        | <b>IMF1W</b>  | <b>IMF2W</b>  | <b>IMF3W</b>  | <b>IMF4W</b>  |

Multi-service, power and low voltage

| Color        | 1-Gang Decorator<br>1-Gang iSTATION | 2-Gang Decorator | 1-Gang Decorator<br>2-Gang iSTATION | 1-Gang Decorator<br>3-Gang iSTATION | 2-Gang Decorator<br>2-Gang iSTATION |
|--------------|-------------------------------------|------------------|-------------------------------------|-------------------------------------|-------------------------------------|
| Black        | <b>IMFP1D1BK</b>                    | <b>IMFP2BK</b>   | <b>IMFP1D2BK</b>                    | <b>IMFP1D3BK</b>                    | <b>IMFP2D2BK</b>                    |
| Gray         | <b>IMFP1D1GY</b>                    | <b>IMFP2GY</b>   | <b>IMFP1D2GY</b>                    | <b>IMFP1D3GY</b>                    | <b>IMFP2D2GY</b>                    |
| Ivory        | <b>IMFP1D1EI</b>                    | <b>IMFP2EI</b>   | <b>IMFP1D2EI</b>                    | <b>IMFP1D3EI</b>                    | <b>IMFP2D2EI</b>                    |
| Office White | <b>IMFP1D1OW</b>                    | <b>IMFP2OW</b>   | <b>IMFP1D2OW</b>                    | <b>IMFP1D3OW</b>                    | <b>IMFP2D2OW</b>                    |
| White        | <b>IMFP1D1W</b>                     | <b>IMFP2W</b>    | <b>IMFP1D2W</b>                     | <b>IMFP1D3W</b>                     | <b>IMFP2D2W</b>                     |

### Hubbell iSTATION Stainless Steel Plates

| 1-Gang       | 2-Gang       | 3-Gang       | 4-Gang       |
|--------------|--------------|--------------|--------------|
| <b>IMSS1</b> | <b>IMSS2</b> | <b>IMSS3</b> | <b>IMSS4</b> |

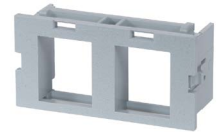

### Delivery Bezels and Modules

| Color        | Raceway Bezel   | Hubbell iSTATION Bezel<br>for Third-Party Raceway | Furniture Boxes |
|--------------|-----------------|---|-----------------|
| Black        | -               | -   | <b>HBLIMFBK</b> |
| Gray         | <b>KPIMBZGY</b> | <b>HWAPLGY</b>                                    | <b>HBLIMFGY</b> |
| Ivory        | -               | -   | <b>HBLIMFI</b>  |
| Office White | <b>KPIMBZOW</b> | <b>HWAPLOW</b>                                    | -               |
| White        | -               | <b>HWAPLW</b>                                     | <b>HBLIMFWA</b> |

### Third-Party Raceway Modules

Unloaded, 2-port, 10-pack

| Color  | Catalog Number   |
|--------|------------------|
| Black  | <b>HWM2KBK10</b> |
| Gray   | <b>HWM2KGY10</b> |
| Ivory* | <b>HWM2KI10</b>  |
| White  | <b>HWM2KW10</b>  |

Note: \*Equivalent to Hubbell Office White.

### Two and Three Gangable AV Wallboxes

| Box  | Dimensions                      | Top Knockouts              | Bottom Knockouts                                    | Back Knockouts  | Catalog Number |
|--|---------------------------------|----------------------------|---|-----------------|----------------|
| 2-Gang, 2" KO,<br>54in <sup>3</sup> capacity | H: 4.21"<br>W: 4.06"<br>D: 4.0" | (2) ½"<br>(2) ½" – ¾" TKO* | (1) 1", 1¼",<br>1½" & 2"                            | (2) ½" – ¾" TKO | <b>HBL985</b>  |
| 3-Gang, 2" KO,<br>79in <sup>3</sup> capacity | H: 4.21"<br>W: 5.87"<br>D: 4.0" | (3) ½"<br>(3) ½" – ¾" TKO* | (1) ½"<br>(1) ½" – ¾" TKO*<br>(1) 1", 1¼", 1½" & 2" | (3) ½" – ¾" TKO | <b>HBL986</b>  |

Note: \*TKO (Tangential Knockout).



### Low Voltage AV Wallbox Partitions

| Compatible With   | Description               | Quantity | Catalog Number   |
|-------------------|---------------------------|----------|------------------|
| HBL985 and HBL986 | Solid divider             | 1        | <b>HBL989</b>    |
|                   | With pass-thru capability | 1        | <b>HBL989AVD</b> |

