

Dimmers and Fan Speed Controls

Features

Standard rocker, toggle, slide and rotary styles for any interior design.

- Optimum CFL and LED Control
- Low End Adjustment for Fine Tuning
- For single-pole and 3-way applications
- Decorator and Traditional Toggle Styling Available
- Ivory, Light Almond, and White available for all SKUs
- No Neutral Required
- 0-10V Low Voltage loads supported with Decorator and Rocker styles



LCD300DW



LCD150SW

LED/CFL Dimmers

Description	Color	Rocker Dimmer	Slide Dimmer	Toggle Dimmer
LED/CFL 200W, Incandescent/Halogen 600W, 120V AC, 60Hz, single pole/three way	Ivory	LCD150DI	LCD150SI	-
	Light Almond	LCD150DLA	LCD150SLA	-
	White	LCD150DW	LCD150SW	-
LED/CFL 150W, Incandescent/Halogen 600W, 120V AC, 60Hz, single pole/three way	Ivory	-	-	LCD150TI
	Light Almond	-	-	LCD150TLA
	White	-	-	LCD150TW
LED/CFL 300W, Incandescent/Halogen 600W, 120V AC, 60Hz, single pole/three way, with indicator light	Ivory	LCD300DI	-	-
	Light Almond	LCD300DLA	-	-
	White	LCD300DW	-	-



LCD150TW



LCD0108SW

Low Voltage Dimmers

Description	Color	Rocker Dimmer	Slide Dimmer
01-10V Low Voltage Loads, 10 A @120V AC, 5 A @277V AC, 60Hz, single pole/three way	Ivory	LCD0108DI	LCD0108SI
	Light Almond	LCD0108DLA	LCD0108SLA
	White	LCD0108DW	LCD0108SW

Fan Speed Controls, 3 Speed

Description	Toggle	Rotary ON/OFF Knobs Provided
Termination	Single Pole/Three Way	Single Pole
Rating	1.5A 120V AC	1.5A 120V AC
Ivory	RAYFSQFI	-
Light Almond	RAYFSQFLA	-
White	RAYFSQFW	-
Ivory/White	-	RFSQ2FDK

Replacement Knobs

Rotary Fan Control Replacement Knobs
-
R28032406
-
R28032401
-



R28032401

R28032406




RFSQ2FDK

Fan Speed Controls, 3 Speed

Description	Rocker Slide Adjustment	Slide Control Slide to OFF
Termination	Single Pole/Three Way	Single Pole
Rating	1.5A 120V AC	1.5A 120V AC
Ivory	RDVFSQFI	RSFSQFI
Light Almond	RDVFSQFLA	RSFSQFLA
White	RDVFSQFW	RSFSQFW

Replacement Knobs

Slide Control Replacement Knobs
-
-
RSKI
RSKLA
RSKW

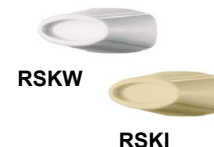

RSKW

RSKI



RSFSQFW