


## GFCI Receptacles with Auto Grounding

### Features

- Patented AUTOGUARD® self test technology includes disconnecting power to the receptacle if critical components are damaged and GFCI protection is lost
- Internal back wiring clamp and guide for quick and secure termination
- Night light option includes light sensor controls for automatic ON and OFF, custom dual lens for optimum light output



Meets UL Standard 943  
Class A GFCI

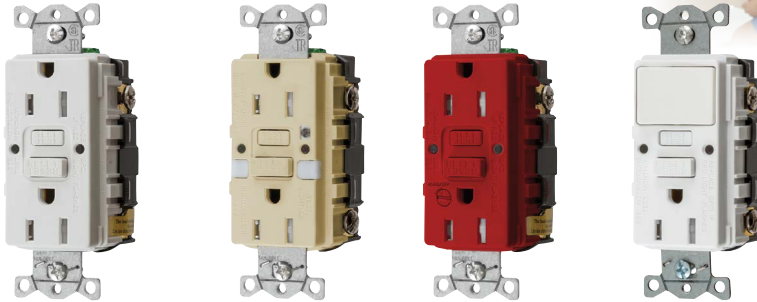

### Tamper-Resistant

Rating	Color	Standard	Night Light Two LED Night Lights	Alarm	Combination Switch 15A 120V Switch
	Almond	GFTRST15AL	GFTRST15ALNL	GFTRST15ALB	—
	Black	GFTRST15BK	GFTRST15BKNL	GFTRST15BKB	—
	Brown	GFTRST15	GFTRST15NL	GFTRST15B	—
	Gray	GFTRST15GY	GFTRST15GYNL	GFTRST15GYB	—
	Ivory	GFTRST15I	GFTRST15INL	GFTRST15IB	GFSPST15I
	Light Almond	GFTRST15LA	GFTRST15LANL	GFTRST15LAB	GFSPST15LA
	Red	GFTRST15R	GFTRST15RNL	GFTRST15RB	—
	White	GFTRST15W	GFTRST15WNL	GFTRST15WB	GFSPST15W
	Almond	GFTRST20AL	GFTRST20ALNL	GFTRST20ALB	—
	Black	GFTRST20BK	GFTRST20BKNL	GFTRST20BKB	—
	Brown	GFTRST20	GFTRST20NL	GFTRST20B	—
	Gray	GFTRST20GY	GFTRST20GYNL	GFTRST20GYB	—
	Ivory	GFTRST20I	GFTRST20INL	GFTRST20IB	—
	Light Almond	GFTRST20LA	GFTRST20LANL	GFTRST20LAB	—
	Red	GFTRST20R	GFTRST20RNL	GFTRST20RB	—
	White	GFTRST20W	GFTRST20WNL	GFTRST20WB	—



### Tamper-Resistant Weather Resistant



Rating	Color	Standard	Isolated Ground
	Almond	GFTWRST15AL	GFTWRST15ALIG
	Black	GFTWRST15BK	GFTWRST15BKIG
	Brown	GFTWRST15	GFTWRST15IG
	Gray	GFTWRST15GY	GFTWRST15GYIG
	Ivory	GFTWRST15I	GFTWRST15IIG
	Light Almond	GFTWRST15LA	GFTWRST15LAIG
	Red	GFTWRST15R	GFTWRST15RIG
	White	GFTWRST15W	GFTWRST15WIG
	Almond	GFTWRST20AL	GFTWRST20ALIG
	Black	GFTWRST20BK	GFTWRST20BKIG
	Brown	GFTWRST20	GFTWRST20IG
	Gray	GFTWRST20GY	GFTWRST20GYIG
	Ivory	GFTWRST20I	GFTWRST20IIG
	Light Almond	GFTWRST20LA	GFTWRST20LAIG
	Red	GFTWRST20R	GFTWRST20RIG
	White	GFTWRST20W	GFTWRST20WIG

Note: See page Tech-10 for Weather and Tamper-Resistant descriptions.  
See section K for complete Hubbell GFCI offering.