

Straight Blade Devices



15 and 20 Ampere, 125 and 250 Volts



15A 125V
NEMA 5-15R
UL CSA
0.5 HP








20A 125V
NEMA 5-20R
UL CSA
1 HP

SNAPConnect®

Extra Heavy Duty Receptacles

Style Line® Decorator

Specification	Color	Catalog Number	Catalog Number	
Specification grade, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below.	Black	SNAP2152BKA	SNAP2162BKA	
	Brown	SNAP2152A	SNAP2162A	
	Gray	SNAP2152GYA	SNAP2162GYA	
	Ivory	SNAP2152IA	SNAP2162IA	
	Light Almond	SNAP2152LAA	SNAP2162LAA	
	Red	SNAP2152RA	SNAP2162RA	
Specification grade, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	White	SNAP2152WA	SNAP2162WA	
	Black	SNAP2152BKNA	SNAP2162BKNA	
	Brown	SNAP2152NA	SNAP2162NA	
	Gray	SNAP2152GYNA	SNAP2162GYNA	
	Ivory	SNAP2152INA	SNAP2162INA	
	Light Almond	SNAP2152LANA	SNAP2162LANA	
Specification grade, Tamper-Resistant, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Red	SNAP2152RNA	SNAP2162RNA	
	White	SNAP2152WNA	SNAP2162WNA	
	Black	SNAP2152BKTRA	SNAP2162BKTRA	
	Blue	SNAP2152BLTRA	SNAP2162BLTRA	
	Brown	SNAP2152TRA	SNAP2162TRA	
	Gray	SNAP2152GYTRA	SNAP2162GYTRA	
Specification grade, Tamper-Resistant, Split Circuit, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Ivory	SNAP2152ITRA	SNAP2162ITRA	
	Light Almond	SNAP2152LATRA	SNAP2162LATRA	
	Red	SNAP2152RTRA	SNAP2162RTRA	
	White	SNAP2152WTRA	SNAP2162WTRA	
	Black	SNAP2152BKSCTRA	SNAP2162BKSCTRA	
	Blue	SNAP2152BLSCTRA	SNAP2162BLSCTRA	
Specification grade, Tamper-Resistant, Split Circuit, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Brown	SNAP2152SCTRA	SNAP2162SCTRA	
	Gray	SNAP2152GYSCTRA	SNAP2162GYSCTRA	
	Ivory	SNAP2152ISCTRA	SNAP2162ISCTRA	
	Light Almond	SNAP2152LASCTRA	SNAP2162LASCTRA	
	Red	SNAP2152RSCTRA	SNAP2162RSCTRA	
	White	SNAP2152WSCTRA	SNAP2162WSCTRA	
Isolated ground ^A , Spec. grade, TR.	Orange	SNAP2152IGTRA	SNAP2162IGTRA	
Spec. grade, with Power Indicating LED, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Black	SNAP2152BKL	SNAP2162BKL	
	Blue	SNAP2152BLL	SNAP2162BLL	
	Brown	SNAP2152L	SNAP2162L	
	Gray	SNAP2152GYL	SNAP2162GYL	
	Ivory	SNAP2152IL	SNAP2162IL	
	Light Almond	SNAP2152LAL	SNAP2162LAL	
Isolated ground ^A , Spec. grade, with LED.	Red	SNAP2152RL	SNAP2162RL	
	White	SNAP2152WL	SNAP2162WL	
	Orange	SNAP2152IGL	SNAP2162IGL	
	Specification grade, Tamper-Resistant, with Power Indicating LED, Style Line® decorator, flush, nylon face, modular receptacle which requires pigtailed connector below. Assembled in USA.	Black	SNAP2152BKLTRA	SNAP2162BKLTRA
		Blue	SNAP2152BLLTRA	SNAP2162BLLTRA
		Brown	SNAP2152LTRA	SNAP2162LTRA
Gray		SNAP2152GYLTRA	SNAP2162GYLTRA	
Ivory		SNAP2152ILTRA	SNAP2162ILTRA	
Light Almond		SNAP2152LALTRA	SNAP2162LALTRA	
Isolated ground ^A , Spec. grade, TR with LED.	Red	SNAP2152RLTRA	SNAP2162RLTRA	
	White	SNAP2152WLTRA	SNAP2162WLTRA	
	Orange	SNAP2152IGLTRA	SNAP2162IGLTRA	

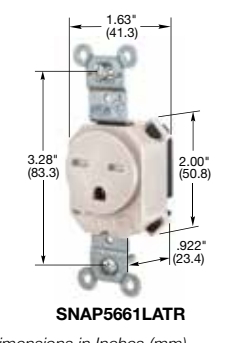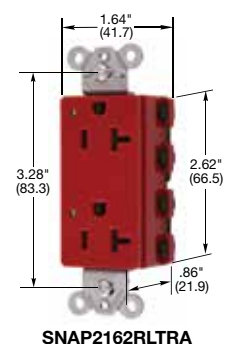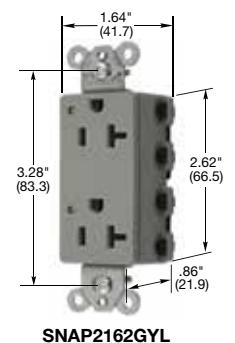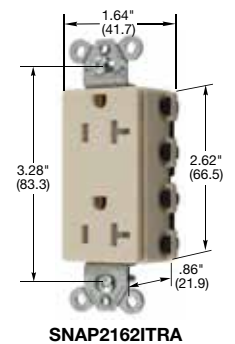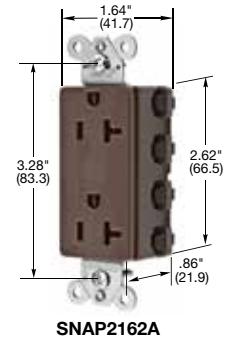

Note: ^ASee section N additional information on isolated ground devices.
See page Tech-10 for Tamper-Resistant and LED Power Indicators descriptions.
See pages A-47 and A-48 for accessories.
See section O for wallplates.

SNAPConnect® 250V Extra Heavy Duty Standard Single Receptacles

Description	Color	15A 250V	20A 250V
Spec. grade, single modular receptacle Tamper-Resistant, smooth nylon face. Requires pigtailed connector on page A-13.	Black	SNAP5661BKTR	SNAP5461BKTR
	Brown	SNAP5661BTR	SNAP5461BTR
	Gray	SNAP5661GYTR	SNAP5461GYTR
	Ivory	SNAP5661ITR	SNAP5461ITR
	Light Almond	SNAP5661LATR	SNAP5461LATR
	White	SNAP5661WTR	SNAP5461WTR

Dimensions in Inches (mm)