

# Straight Blade Devices

15 and 20 Ampere, 125 Volts



15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP



20A 125V  
NEMA 5-20R  
UL CSA  
1 HP




Meets UL  
Standard 943  
Class A GFCI



## SNAPConnect® GFCI LED


Description	Color	Catalog Number	
SNAPConnect GFCI LED, self-grounding staple, requires connector below, sold separately. Add "NA" suffix for devices Assembled in USA.	Black	<b>GFRST15SNAPBK</b>	<b>GFRST20SNAPBK</b>
	Brown	<b>GFRST15SNAP</b>	<b>GFRST20SNAP</b>
	Gray	<b>GFRST15SNAPGY</b>	<b>GFRST20SNAPGY</b>
	Ivory	<b>GFRST15SNAPI</b>	<b>GFRST20SNAPI</b>
	Light Almond	<b>GFRST15SNAPLA</b>	<b>GFRST20SNAPLA</b>
	Red	<b>GFRST15SNAPR</b>	<b>GFRST20SNAPR</b>
	White	<b>GFRST15SNAPW</b>	<b>GFRST20SNAPW</b>

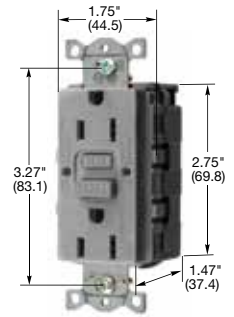

GFRST15SNAPGY

## SNAPConnect® GFCI LED, Tamper and Weather Resistant

Description	Color	Catalog Number	
SNAPConnect GFCI TR/WR, self-grounding staple, requires connector below, sold separately. Add "NA" suffix for devices Assembled in USA.	Black	<b>GFTWRST15SNAPBK</b>	<b>GFTWRST20SNAPBK</b>
	Brown	<b>GFTWRST15SNAP</b>	<b>GFTWRST20SNAP</b>
	Gray	<b>GFTWRST15SNAPGY</b>	<b>GFTWRST20SNAPGY</b>
	Ivory	<b>GFTWRST15SNAPI</b>	<b>GFTWRST20SNAPI</b>
	Light Almond	<b>GFTWRST15SNAPLA</b>	<b>GFTWRST20SNAPLA</b>
	Red	<b>GFTWRST15SNAPR</b>	<b>GFTWRST20SNAPR</b>
	White	<b>GFTWRST15SNAPW</b>	<b>GFTWRST20SNAPW</b>

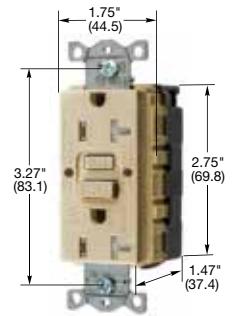

GFTWRST20SNAPI

Note: GFCI type receptacles should not be used in critical care patient areas or for electrical life support equipment applications because of the possibility of power interruption. All GFCI receptacles are furnished with a matching color thermoplastic wallplate, 20 amp feed-through capability.



15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP




20A 125V  
NEMA 5-20R  
UL CSA  
1 HP



## SNAPConnect® USB Charger, Duplex Receptacles


Description	Color	Catalog Number	
SNAPConnect USB Charger, Tamper-Resistant Style Line® decorator duplex receptacle, 15 or 20 Amp, 125 Volt AC with one type A & one type-C USB port, 3 Amp up to 9 Volt USB output.	Black	<b>SNAP15UACBK</b>	<b>SNAP20UACBK</b>
	Brown	<b>SNAP15UAC</b>	<b>SNAP20UAC</b>
	Gray	<b>SNAP15UACGY</b>	<b>SNAP20UACGY</b>
	Ivory	<b>SNAP15UACI</b>	<b>SNAP20UACI</b>
	Light Almond	<b>SNAP15UACLA</b>	<b>SNAP20UACLA</b>
	White	<b>SNAP15UACW</b>	<b>SNAP20UACW</b>

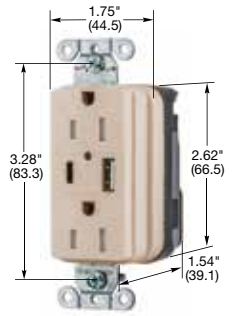

SNAP15UACLA

## SNAPConnect® Surge Protection, Tamper-Resistant Receptacle with Power Indicating LED


Description	Color	Catalog Number	
SNAPConnect Surge suppression, Tamper-Resistant, smooth face, duplex receptacle.	Blue	<b>SNAP5262S</b>	<b>SNAP5362S</b>
	Gray	<b>SNAP5262GYS</b>	<b>SNAP5362GYS</b>
	Ivory	<b>SNAP5262IS</b>	<b>SNAP5362IS</b>
	Light Almond	<b>SNAP5262LAS</b>	<b>SNAP5362LAS</b>
	White	<b>SNAP5262WS</b>	<b>SNAP5362WS</b>

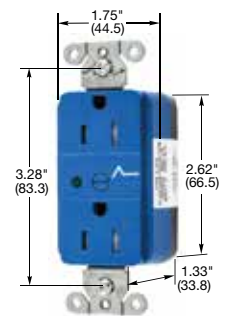

SNAP5262S

## SNAPConnect® Tester

Description	Catalog Number
Circuit Tester for SNAPConnect receptacle terminals, GFCI and standard receptacles.	<b>SNAPCTG</b>

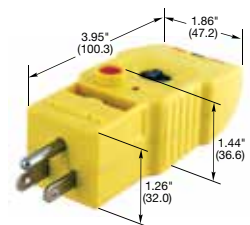

SNAPCTG

Note: See page Tech-10 for Tamper-Resistant, Weather Resistant and LED Power Indicators descriptions.

Dimensions in Inches (mm)