

# Straight Blade Devices



15 and 20 Ampere, 125 and 250 Volts




15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP




20A 125V  
NEMA 5-20R  
UL CSA  
1 HP

## Hubbell-PRO Extra Heavy Duty Specification Grade Receptacles


Duplex	Color	Catalog Number	
Smooth polycarbonate face, duplex, back and side wired.	Black	5252BK	5352BK
	Brown	5252B	5352B
	Gray	5252G	5352G
	Ivory	5252I	5352I
	Light Almond	5252LA	5352LA
	Red	5252R	5352R
	White	5252W	5352W
Finder groove polycarbonate face, duplex, back and side wired.	Black	5262BLK	5362BLK
	Blue	5262BL	5362BL
	Brown	5262B	5362B
	Gray	5262G	5362G
	Ivory	5262I	5362I
	Light Almond	5262LA	5362LA
	Red	5262R	5362R
	White	5262W	5362W

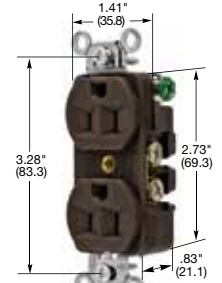


5262B

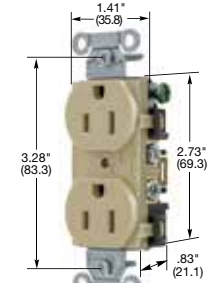


5252AI

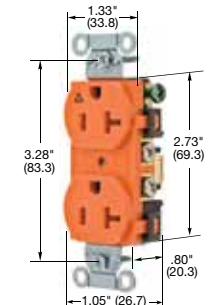

IG5352

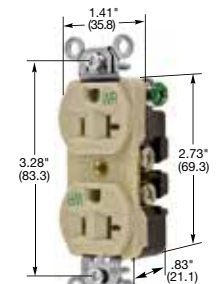

5362IWR

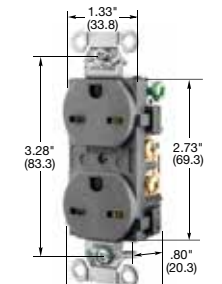

5662GY

Dimensions in Inches (mm)

## Hubbell-PRO Heavy Duty Specification Grade Receptacles

Duplex	Color	Standard Duplex		Isolated Ground <sup>A</sup>	
		15A 125V NEMA 5-15R	20A 125V NEMA 5-20R	15A 125V NEMA 5-15R	20A 125V NEMA 5-20R
Smooth polycarbonate face, duplex, back and side wired.	Black	5252ABLK	5352ABLK	-	-
	Brown	5252AB	5352AB	-	-
	Gray	5252AG	5352AG	IG5252GY	IG5352GY
	Ivory	5252AI	5352AI	IG5252I	IG5352I
	Light Almond	5252ALA	5352ALA	IG5252LA	IG5352LA
	Orange	-	-	IG5252	IG5352
	Red	5252AR	5352AR	-	-
	White	5252AW	5352AW	IG5252W	IG5352W
Smooth polycarbonate face, Tamper-Resistant, duplex, back and side wired.	Black	5252BLKTR	5352BLKTR	-	-
	Brown	5252BTR	5352BTR	-	-
	Gray	5252GTR	5352GTR	-	-
	Ivory	5252ITR	5352ITR	IG5252ITR	IG5352ITR
	Light Almond	5252LATR	5352LATR	-	-
	Orange	-	-	IG5252TR	IG5352TR
	Red	5252RTR	5352RTR	-	-
	White	5252WTR	5352WTR	IG5252WTR	IG5352WTR
Finder groove polycarbonate face, duplex, back and side wired.	Black	5262ABLK	5362ABLK	CR5252IGBK	CR5352IGBK
	Blue	5262ABL	5362ABL	-	CR5352IGBL
	Brown	5262AB	5362AB	-	-
	Gray	5262AG	5362AG	CR5252IGGY	CR5352IGGY
	Ivory	5262AI	5362AI	CR5252IGI	CR5352IGI
	Light Almond	5262ALA	5362ALA	-	-
	Orange	-	-	CR5252IG	CR5352IG
	Red	5262AR	5362AR	-	-
White	5262AW	5362AW	CR5252IGW	CR5352IGW	
Weather resistant, Finder groove nylon face, duplex, back and side wired.	Black	5262BKWR	5362BKWR	-	-
	Brown	5262WR	5362WR	-	-
	Gray	5262GYWR	5362GYWR	-	-
	Ivory	5262IWR	5362IWR	-	-
	White	5262WWR	5362WWR	-	-

Note: <sup>A</sup>See section N for additional information on isolated ground devices.  
See page A-47 for accessories and section O for wallplates.  
See page Tech-10 for Tamper and Weather Resistant descriptions.  
Horsepower ratings listed above are AC only.



15A 250V  
NEMA 6-15R  
UL CSA  
1.5 HP



20A 250V  
NEMA 6-20R  
UL CSA  
2 HP

## Hubbell-PRO 250V Heavy Duty Specification Grade Receptacles

Description	Color	Catalog Number	
Smooth nylon face, duplex, back and side wired.	Black	5662BK	5462BK
	Blue	5662BL	5462BL
	Brown	5662B	5462B
	Gray	5662GY	5462GY
	Green	5662GN	5462GN
	Ivory	5662IV	5462IV
	Light Almond	5662LA	5462LA
	Red	5662R	5462R
	White	5662WHI	5462WHI