

# Straight Blade Devices



15 and 20 Ampere, 125 Volts



15A 125V  
NEMA 5-15R  
UL CSA  
0.5 HP




20A 125V  
NEMA 5-20R  
UL CSA  
1 HP


## Commercial Specification Grade Receptacles

Duplex	Color	Catalog Number	
Smooth polycarbonate face, duplex, back and side wired.	Black	<b>BR15BLK</b>	<b>BR20BLK</b>
	Blue	<b>BR15BL</b>	<b>BR20BL</b>
	Brown	<b>BR15</b>	<b>BR20</b>
	Gray	<b>BR15GRY</b>	<b>BR20GRY</b>
	Green	<b>BR15GN</b>	<b>BR20GN</b>
	Ivory	<b>BR15I</b>	<b>BR20I</b>
	Light Almond	<b>BR15LA</b>	<b>BR20LA</b>
	Red	<b>BR15R</b>	<b>BR20R</b>
	White	<b>BR15WHI</b>	<b>BR20WHI</b>
Tamper-Resistant, smooth polycarbonate face, duplex, back and side wired.	Black	<b>BR15BLKTR</b>	<b>BR20BLKTR</b>
	Blue	<b>BR15BLTR</b>	<b>BR20BLTR</b>
	Brown	<b>BR15TR</b>	<b>BR20TR</b>
	Gray	<b>BR15GRYTR</b>	<b>BR20GRYTR</b>
	Green	<b>BR15GNTR</b>	<b>BR20GNTR</b>
	Ivory	<b>BR15ITR</b>	<b>BR20ITR</b>
	Light Almond	<b>BR15LATR</b>	<b>BR20LATR</b>
	Red	<b>BR15RTR</b>	<b>BR20RTR</b>
	White	<b>BR15WHITR</b>	<b>BR20WHITR</b>
Weather Resistant, smooth polycarbonate face, duplex, back and side wired.	Black	<b>BR15BLKWR</b>	<b>BR20BLKWR</b>
	Brown	<b>BR15WR</b>	<b>BR20WR</b>
	Gray	<b>BR15GRYWR</b>	<b>BR20GRYWR</b>
	Ivory	<b>BR15IWR</b>	<b>BR20IWR</b>
	Light Almond	<b>BR15LAWR</b>	<b>BR20LAWR</b>
	White	<b>BR15WHIWR</b>	<b>BR20WHIWR</b>
Weather and Tamper-Resistant, smooth polycarbonate face, duplex, back and side wired.	Black	<b>BR15BLKWRTR</b>	<b>BR20BLKWRTR</b>
	Brown	<b>BR15WRTR</b>	<b>BR20WRTR</b>
	Gray	<b>BR15GRYWRTR</b>	<b>BR20GRYWRTR</b>
	Ivory	<b>BR15IWRTR</b>	<b>BR20IWRTR</b>
	Light Almond	<b>BR15LAWRTR</b>	<b>BR20LAWRTR</b>
	White	<b>BR15WHIWRTR</b>	<b>BR20WHIWRTR</b>
Isolated ground <sup>A</sup> , smooth nylon face, duplex, side wired only.	Gray	<b>IG15CRGRY</b>	<b>IG20CRGRY</b>
	Ivory	<b>IG15CRI</b>	<b>IG20CRI</b>
	Light Almond	<b>IG15CRLA</b>	<b>IG20CRLA</b>
	Orange	<b>IG15CR</b>	<b>IG20CR</b>
	White	<b>IG15CRWHI</b>	<b>IG20CRWHI</b>
Isolated ground <sup>A</sup> , Style Line <sup>®</sup> decorator*, smooth nylon face, duplex, back and side wired.	Gray	<b>IG15DRGRY</b>	<b>IG20DRGRY</b>
	Ivory	<b>IG15DRI</b>	<b>IG20DRI</b>
	Light Almond	<b>IG15DRLA</b>	<b>IG20DRLA</b>
	Orange	<b>IG15DR</b>	<b>IG20DR</b>
	White	-	<b>IG20DRWHI</b>


Note: <sup>A</sup>See section N for additional information on isolated ground devices.  
See page A-47 for accessories.  
See page Tech-10 for Tamper and Weather Resistant descriptions.  
See section O for wallplates.

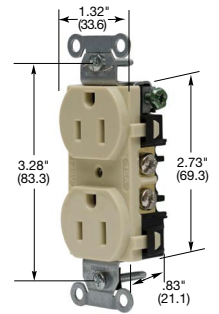


**BR15I**

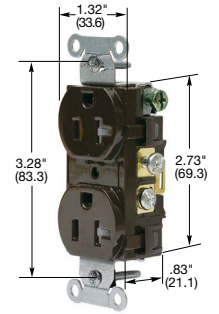


**BR20TR**

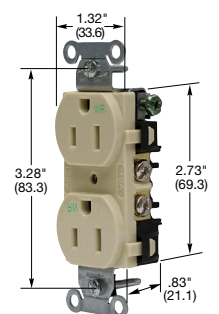

**BR15IWR**

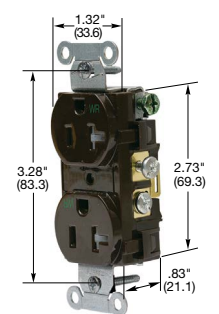

**BR20WRTR**

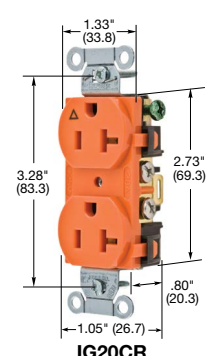

**IG20CR**

Dimensions in Inches (mm)