

# Twist-Lock® Devices

## Accessories for 20 and 30 Amp 3, 4 and 5 Wire Devices

### Insulgrip® Plug and Connector Body Latching Kit

The Hubbell latching kit provides both improved safety and security through a double locking feature that makes unintentional disconnection virtually impossible – even under high vibration situations. The plug and connector body lock once when first connected, then again when you push the special position locking slide into place.



SK2

### Insulgrip® Latching Kit

Description	For 3 Wire Devices	For 4 & 5 Wire Devices
For all 20A and 30A Twist-Lock Insulgrip plugs and connectors.	<b>SK2</b>	<b>SK3</b>

### Valise®

**IP55\***  
SUITABILITY

### Weatherproof, Seal-Tite®, Triple Seal Boots

Description	For 3 Wire Devices	For 4 & 5 Wire Devices
Yellow Seal-Tite® elastomer triple seal cover for use with Valise plugs when used in cord set and Valise connector bodies when used with flanged inlet.	<b>HBL60CM31V</b>	–
Yellow Seal-Tite® elastomer triple seal cover for use with Valise connector bodies.	<b>HBL60CM32V</b>	–



HBL60CM31V

Note: \*When installed and used properly with plug and connector body combinations.

### Insulgrip®


**IP55\***  
SUITABILITY

### Weatherproof, Seal-Tite®, Triple Seal Boots

Description	For 3 Wire Devices	For 4 & 5 Wire Devices
Black elastomer boot for plugs when used in a cord set and connector bodies when used in flanged inlets.	<b>HBL6031</b>	<b>HBL6035</b>
Same as above except yellow.	<b>HBL60CM31</b>	<b>HBL60CM35</b>
Black elastomer boot for connector bodies when used in a cord set.	<b>HBL6032</b>	<b>HBL6036</b>
Same as above except yellow.	<b>HBL60CM32</b>	<b>HBL60CM36</b>



HBL6032

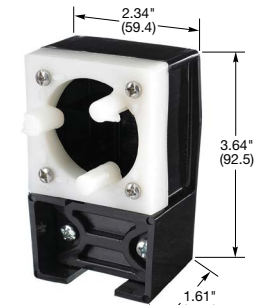

HBL3WAA


### Angle Adapter

Description	For 3 Wire Devices	For 4 & 5 Wire Devices
Nylon, angle adapter for Insulgrip plugs and connector bodies, cord grip range .325"-.930" (8.3-24).	<b>HBL3WAA</b>	<b>HBL45WAA</b>

### PLUGOUT® Lockout Devices

Description	For 3 Wire Devices	For 4 & 5 Wire Devices
Lockout device for attachable 20 and 30A locking plugs, straight body or angle types, with or without weatherproof covers.	<b>HLD</b>	<b>HLD</b>
Lockout device for 20 and 30A 3 wire angle plugs and watertight Safety-Shroud® Twist-Lock® plugs.	<b>HLD2</b>	<b>HLD2</b>

Note: See section BB for additional information on PLUGOUT Lockout devices.  
\*When installed and used properly with plug and connector body combinations.

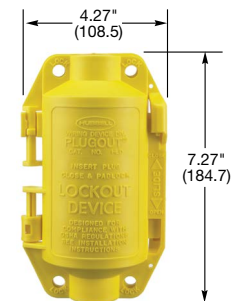

HLD

For quick visual identification of circuits or configurations.

### Colored Cord Clamps\*

Description	Color	For 3 Wire Devices	For 4 & 5 Wire Devices
For use with 20A and 30A Insulgrip® Twist-Lock® Plugs and Connectors. Cord diameter: 3 wire .350"-.930" (9-24), 4 & 5 wire .350" – 1.150" (9-29)	Black	<b>HBLTL2CCBK</b>	<b>HBLTL3CCBK</b>
	Blue	<b>HBLTL2CCBL</b>	<b>HBLTL3CCBL</b>
	Brown	<b>HBLTL2CCBR</b>	<b>HBLTL3CCBR</b>
	Dark Blue	<b>HBLTL2CCDB</b>	<b>HBLTL3CCDB</b>
	Green	<b>HBLTL2CCGR</b>	<b>HBLTL3CCGR</b>
	Orange	<b>HBLTL2CCOR</b>	<b>HBLTL3CCOR</b>
	Red	<b>HBLTL2CCRD</b>	<b>HBLTL3CCRD</b>
	Teal	<b>HBLTL2CCTL</b>	<b>HBLTL3CCTL</b>
	White	<b>HBLTL2CCWH</b>	<b>HBLTL3CCWH</b>
	Yellow	<b>HBLTL2CCYL</b>	<b>HBLTL3CCYL</b>



Note: \*Clamp only. Contains no screws. Order in increments of 10. Not UL Listed or CSA Certified.

Dimensions in Inches (mm)