


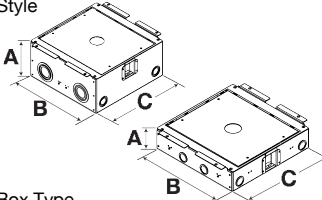

SystemOne Recessed 4-Gang Rectangular Floor Boxes, Covers and Plates For Use In Raised Access or Wood Floors

AFB series boxes are available from our factory as pre-wired assemblies with CONNEXION modular plug-n-play system

Style			
Box Type			
Standard	AFB4G50	AFB4G25	
Chicago (No Knockouts)	AFB4G50CHI	AFB4G25CHI	
Minimum Depth from Top of Floor Tile	5.37" (136.4)	2.88" (73.2)	
Cubic Inch (cm ³) Capacity per Gang	57.5 cu. in. (940 cm ³)	26.5 cu. in. (434.3 cm ³)	
Dimensions – A	5.18" (131.4)	2.69" (68.3)	
Dimensions – B	11.11" (282.2)	11.11" (282.2)	
Dimensions – C	10.90" (276.9)	10.90" (276.9)	
KO Trade Size: Ends	(2) ½", (4) 1", 1¼", 1½", 2"	(4) ½", ¾"	
Sides	(4) ½", ¾", 1", 1¼"	(4) ½", ¾"	
Bottom	(4) ½", ¾", 1", 1¼"	(4) ½", ¾", (4) 1", 1¼"	
Floor Thickness	.62- 2.12" (15.7- 53.8)	.62- 2.12" (15.7- 53.8)	
Cover Family	Rectangular	Rectangular	
Temporary Cover Included	✓	✓	

Note: UL File Number E31999.

Rectangular Covers (for use with raised access tiles and wood floors)

- Die cast construction available in five finishes
- UL 514A listed
- Maximum static load of 1500 lbs. with 2x safety factor*

Surface Cover Dimensions 13 in. x 13¼ in.		
Finish	Without Insert	With Insert
Aluminum Powder Coat	4GAFBCVRALU	4GAFBCVRALUC
Black Powder Coat	4GAFBCVRBK	4GAFBCVRBKC
Brass Powder Coat	4GAFBCVRBRS	4GAFBCVRBRSC
Bronze Powder Coat	4GAFBCVRBRZ	4GAFBCVRBRZC
Satin Nickel Powder Coat	4GAFBCVRNK	4GAFBCVRNKC













Note: *Load applied through a 3 in. (76mm) mandrel in center of the cover.

Accessories

Description	Catalog Number
AFB4G series replacement dividers.	AFB4GDIVKIT

Plates - for use in 2 and 4-Gang Floor Boxes

- UL 514A listed

Plate Style	(1) Decorator Opening	(1) Duplex Opening	(2) Extron® MAAP Openings	(2) Extron® Openings	(2) 1U Hubbell iStation Openings	(1) 1.5U Hubbell iStation Opening
Cat. No.	FBMPREC	FBMPDUP	FBMPMAAP	FBMPAAP	FBMP2IM	FBMP15IM
						
Plate Style	(1) Simplex Opening 1.40 in. Diameter	(1) Twist-Lock® Opening 1.60 in. Diameter	1-Gang Blank	Cable Feed Through with Bushing	(1) Opening for TracJack® or Series II®	(1) Opening with Hubbell ISF6 Frame for Keystone Jacks
Cat. No.	FBMP139	FBMP156	FBMPBNK	FBMPFT	FBMPTRAC	FBMP6KS
						

Extron® is a registered trademark of Extron Electronics. Crestron® is a registered trademark of Crestron Electronics, Inc.
FSR® is a registered trademark of FSR Inc. TracJack®, Series II® and Ortronics® are registered trademarks of Ortronics/Legrand.

Dimensions in Inches (mm)