


# Hose and Cable Protection Systems

## FloorTrak® Floor Cable Cover

For Pedestrian Traffic in Office and Public Areas

- Flexible and rigid PVC material
- Protects and reduces trip hazards
- Available in four different sizes and five PVC colors to blend with the various decors
- Withstands temperatures of 0°F to +120°F (-18°C to +49°C)

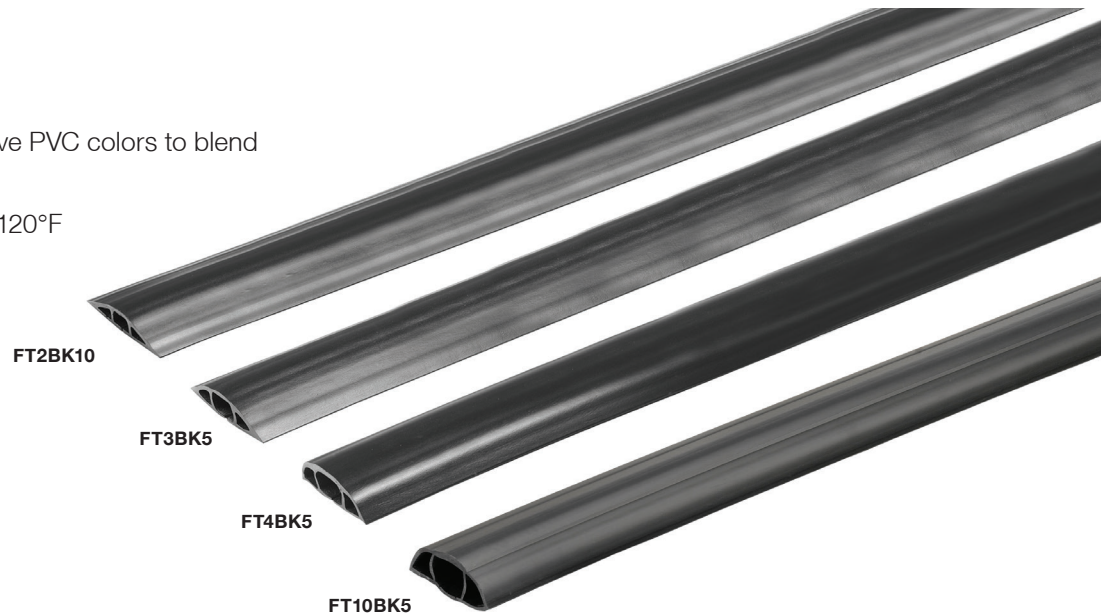

### FloorTrak® 2\*

Color	Length Feet (meters)	Catalog Number
Black	10.0' (3.05)	<b>FT2BK10</b>
Brown	10.0' (3.05)	<b>FT2BR10</b>
Beige	10.0' (3.05)	<b>FT2BG10</b>
Gray	10.0' (3.05)	<b>FT2GY10</b>
Yellow	10.0' (3.05)	<b>FT2Y10</b>



### FloorTrak® 4

Color	Length Feet (meters)	Catalog Number
Black	5.0' (1.52)	<b>FT4BK5</b>
Black	25.0' (7.62)	<b>FT4BK25</b>
Gray	25.0' (7.62)	<b>FT4GY25</b>
Yellow	5.0' (1.52)	<b>FT4Y5</b>
Yellow	25.0' (7.62)	<b>FT4Y25</b>



### FloorTrak® 3\*

Color	Length Feet (meters)	Catalog Number
Black	5.0' (1.52)	<b>FT3BK5</b>
Black	25.0' (7.62)	<b>FT3BK25</b>
Brown	5.0' (1.52)	<b>FT3BR5</b>
Brown	25.0' (7.62)	<b>FT3BR25</b>
Beige	5.0' (1.52)	<b>FT3BG5</b>
Beige	25.0' (7.62)	<b>FT3BG25</b>
Gray	5.0' (1.52)	<b>FT3GY5</b>
Gray	25.0' (7.62)	<b>FT3GY25</b>
Yellow	5.0' (1.52)	<b>FT3Y5</b>
Yellow	25.0' (7.62)	<b>FT3Y25</b>



### FloorTrak® 10 (Heavy Duty)

Color	Length Feet (meters)	Catalog Number
Black	3.0' (.914)	<b>FT10BK3</b>
Black	5.0' (1.52)	<b>FT10BK5</b>
Yellow	3.0' (.914)	<b>FT10Y3</b>
Yellow	5.0' (1.52)	<b>FT10Y5</b>



### Accessories


Description	Catalog Number
1" Wide, 75' Roll Double-Sided Adhesive Tape.	<b>FTT1</b>
2" Wide, 75' Roll Double-Sided Adhesive Tape.	<b>FTT2</b>



Note: \*ADA Compliant Section 4.5.2.

### Dimensions

FloorTrak®	FT2 in. (mm)	FT3 in. (mm)	FT4 in. (mm)	FT10 (Heavy Duty) in. (mm)
Width (A)	2.75" (69.9)	3.00" (76.2)	3.25" (82.6)	5.6" (142.24)
Height (B)	.53" (13.5)	.75" (19.1)	1.10" (27.9)	1.7" (43.18)
Center Hole (Cx Dx)	.60" x .31" (15.2) x (7.9)	.75" x .50" (19.1) x (12.7)	1.21" x .75" (30.7) x (19.1)	1.81" x 1.25" (45.98 x 31.75)

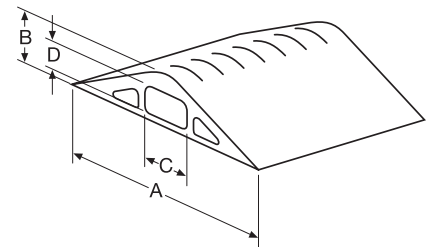

### Specifications

Material	Rigid PVC.
Operating Temperature	0°F to +120°F (-18°C to +49°C).

Dimensions in Inches (mm)