

SRT1

Drive Edge-Lit Surface/Ceiling/Garage Luminaire size 1

CEILING/SURFACE/GARAGE



FEATURES

- For ceiling mount and parking garage applications from an 8-15 foot mounting height; Two lumen packages and two optical distributions available.
- Edge-Lit flat lens for optimal visual comfort and uniformity across the lens
- Die-cast aluminum housing that maximizes heat dissipation and ensures long electrical component life and luminaire performance
- 120-277V Universal Voltage Operation
- 0-10V dimming drivers
- Available in 6 durable and long lasting paint finishes
- IP65, listed to UL 1598 for use in wet locations
- Occupancy sensor available for complete on/off and dimming operation
- Up light option available providing approximately 800 lumens

ORDERING INFORMATION

SERIES	ENGINE	CCT	DISTRIBUTION	VOLTAGE	FINISH	OPTIONS
SRT1 Edge-Lit Parking Garage Size 1	20 20W Nominal 2,500 lm	3K7 3000K, 70 CRI 3K8 3000K, 80 CRI	5QW Type 5 Square Wide 5C Type 5 Concentrated	UNV 120-277V 120 120V 208 208V 240 240V 277 277V	BL Black Textured DB Dark Bronze Textured GT Graphite Textured GYS Gray Silver Smooth PS Plat. Silver Smooth WH White Textured CC Custom Color	WG Wire Guard UD³ Uplight F¹ Single Fuse (120, 277V) LD3² 36" Lead Length LD6² 72" Lead Length LD9² 108" Lead Length SP10K³ 10kA Surge protection with end of life LED indicator LMB Less mounting bracket
	35 35W Nominal 4,000 lm	35K7 3500K, 70 CRI 4K7 4000K, 70 CRI				
	55 55W Nominal 6,000 lm	4K8 4000K, 80 CRI 5K7 5000K, 70 CRI				

Notes:

- 1 Must specify voltage
- 2 Standard wire lead length 24"
- 3 SP10K LED indicator not available with uplight

 

ACCESSORIES AND SERVICES

Accessories	
SRT1-WG	Wire Guard for SRT1 version
SRT1-MB	Mounting Bracket for pre-installation
SRT1-BRD-XX	Bird Deterrent for size 1 version, not available with uplight
SCP-REMOTE	Remote control for SCP option, order at least on per project to program and control

CONTROL OPTIONS

NX Stand Alone	
NXOS12F	NX Distributed Intelligence™, PIR Occ. Sensor, Dimming Daylight Harvesting, up to 12' MH
Sensor Controls	
SCP-8F	Remote control programmable line voltage sensor up to 8' MH
SCP-20F	Remote control programmable line voltage sensor up to 20' MH

DIMENSIONS

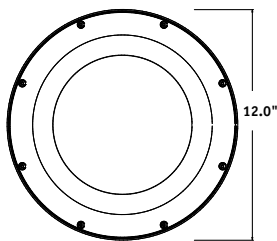

Weight:
8.0 lbs
(3.6 kg)