

Drive Edge Lit Surface/Ceiling/Garage Luminaire size 2

FEATURES

- For ceiling mount and parking garage applications from an 8-20 foot mounting height; Multiple lumen packages and optical distributions are available making the SRT2 luminaire both versatile and functional.
- Edge-Lit flat lens for optimal visual comfort and uniformity across the lens
- Die-cast aluminum housing that maximizes heat dissipation and ensures long electrical component life and luminaire performance
- Four distribution types: Type 5QW, Type 5C, Type 5R and asymmetric
- 120-277V universal voltage & 347/480V operation
- 0-10V dimming drivers
- Available in 6 durable and long lasting paint finishes
- IP65, listed to UL 1598 for use in wet locations
- Occupancy sensor available for complete on/off and dimming operation
- NX Distributed Intelligence available for wireless controls
- Up light option available providing approximately 800 lumens



CEILING/SURFACE/GARAGE

ORDERING INFORMATION

SERIES	ENGINE	CCT	DISTRIBUTION	VOLTAGE	FINISH	OPTIONS
SRT2 Edge-Lit Parking Garage Size 2	30 30W Nominal 4,000 lm	3K7 3000K, 70 CRI	5QW Type 5 Square Wide	UNV 120-277V	BL Black Textured	WG Wire Guard
	50 50W Nominal 6,000 lm	3K8 3000K, 80 CRI	5RW¹ Type 5 Rectangular Wide	120 120V	DB Dark Bronze Textured	UD³ Up-Light
	65 65W Nominal 8,000 lm	35K8 3500K, 80 CRI	5C Type 5 Concentrated	208 208V	GT Graphite Textured	F² Single Fuse (120, 277V)
	85 85W Nominal 10,000 lm	4K7 4000K, 70 CRI	ASY¹ Asymmetric (Type 3/4)	240 240V	GYS Gray Silver Smooth	F² Double Fuse (208, 240, 480V)
	100 100W Nominal 12,000 lm	4K8 4000K, 80 CRI		277 277V	PS Plat. Silver Smooth	EH² Battery Backup Unit (-20°C)
	120 120W Nominal 14,000 lm	5K7 5000K, 70 CRI		347 347V	WH White Textured	
	140 140W Nominal 16,000 lm			480 480V	CC Custom Color	


Notes:

- 1 30 - 85W Light engines only
- 2 Must specify voltage, 120V or 270V for E and EH
- 3 Universal voltage only

ACCESSORIES AND SERVICES

Accessories	
SRT2-WG	Wire Guard for SRT2 version
SRT-MB	Mounting Bracket for pre-installation
SRT2-BRD	Bird Deterrent for SRT2 versions
SRT2-TM	Trunnion/Yoke accessory for size 2 version, not available with uplight

DIMENSIONS

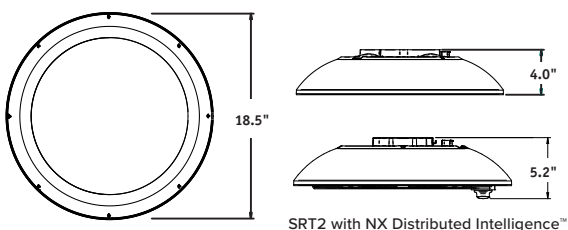

Weight:
15.0 lbs
(5.8 kg)

CONTROL OPTIONS

NX Stand Alone	
NX0S12F	NX Distributed Intelligence™, PIR Occ. Sensor, Dimming Daylight Harvesting, up to 12' MH
NX0SP30F	NX Distributed Intelligence™, PIR Occ. Sensor, Dimming Daylight Harvesting, up to 30' MH
NX Networked – Wireless ¹	
NXWE	NX Distributed Intelligence™ Wireless Enabled (module+ratio)
NX0SW12F	NX Distributed Intelligence™, PIR Occ. Sensor, Dimming Daylight Harvesting, up to 12' MH
NX0SW130F	NX Distributed Intelligence™, PIR Occ. Sensor, Dimming Daylight Harvesting, up to 30' MH
wiSCAPE – Wireless ¹	
WIR	Wireless Controls, wiSCAPE®
WIRSC	wiSCAPE® + occupancy sensor
WIR924³	UL924 Listed Wireless Controls, wiSCAPE®
WIRSC924³	UL924 Listed wiSCAPE® + occupancy sensor
Sensor Controls	
SCP-8F	Remote control programmable line voltage sensor up to 8' MH
SCP-20F	Remote control programmable line voltage sensor up to 20' MH
SCP924-8F³	UL924 Listed Remote control programmable line voltage sensor up to 8' MH
SCP924-20F³	UL924 Listed Remote control programmable line voltage sensor up to 20' MH