

LLHP

LED Linear High Bay Premium

INDUSTRIALS

LED



(2' High Lumen Shown)

FEATURES

- Highly efficient LEDs provide up to 101 lumens per watt at 70 CRI
- Long-life, 60,000 hour LEDs at L90 reduce life cycle maintenance costs
- 2' size provides nominal lumen packages from 12,950 to 27,750
- 3' size provides nominal lumen packages from 37,850 to 42,100
- Aisle, Medium, or Wide distribution options
- Individual optics for each LED allow for precise control of light distribution
- Operates in a wide range of ambient temperatures
- Extruded aluminum housing acts as heat sink; downward sloping fins minimize debris buildup
- Optional occupancy sensor sits securely within the housing frame
- Fixed output or 0-10V dimming available
- Product designed for quick and easy suspension mounting with aircraft cabling
- CSA listed and suitable for damp locations
- Five year warranty (Terms and Conditions apply)

ORDERING INFORMATION


LLHP							
MODEL	SIZE	COLOR TEMP	LUMEN OUTPUT	DISTRIBUTION	DRIVER	VOLTAGE	OPTIONS
LLHP LED Linear High Bay	2 2' 3 3'	30 3000K 40 4000K 50 5000K	L Low Lumen (2' size) H High Lumen (2' size) VL Very High Lumen (3' size) <small>See Product Availability Table below.</small>	A Aisle M Medium W Wide	E Fixed Output ED 0-10V Dimming	U 120V-277V 120 120V 277 277V 347 347V 480 480V	F3C5 3-Conductor Cord 5' F3C10 3-Conductor Cord 10' F3C15 3-Conductor Cord 15' C6TL15_ 6' Cord and Twist-Lock Plug 15A (Add Volt 1=120, 2=277) CP6TL20_ 6' Cord and Twist-Lock Plug 20A (Add Volt 1=120, 2=277) WG Wire Guard (factory installed) OS1 Occupancy Sensor 120-277 Single Relay LG2EM Prewired for Dual-Lite LightGear® Inverter, 250 VA/Watts (purchase separately) ^{1,2}

ACCESSORIES (ORDER SEPARATELY)

- CP6TL15_ 6' Cord and Twist-Lock Plug 15A (Add Volt 1=120, 2=277)
- CP6TL20_ 6' Cord and Twist-Lock Plug 20A (Add Volt 1=120, 2=277)
- LHVQM5 Aircraft Cable 5' Pair
- LHVQM10 Aircraft Cable 10' Pair
- LHVQM15 Aircraft Cable 15' Pair

¹ LG2EM is prewired for one LED array when applied to high (H) or very high (VL) lumen output.

² LG Series must be purchased from Dual-Lite as a separate system. Visit www.dual-lite.com for product details.

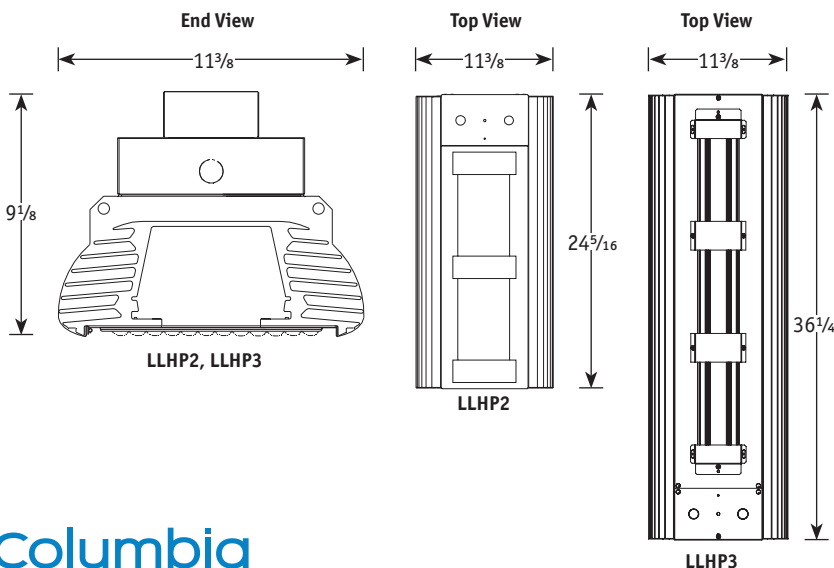

PRODUCT AVAILABILITY

DISTRIBUTION	SIZE	LUMEN PACKAGE	NOMINAL LUMENS	NOMINAL WATTS	Efficacy
Aisle	2'	L	12,950	143	91
	2'	H	24,850	281	88
	3'	VL	37,850	425	89
Medium	2'	L	14,350	142	101
	2'	H	27,750	281	99
	3'	VL	41,800	425	98
Wide	2'	L	13,900	143	98
	2'	H	27,000	281	97
	3'	VL	42,100	425	99

Lumens vary according to color temperatures and other factors. See specific photometric test(s).