

# LXEW

## Industrial Enclosed & Gasketed LED High Bay

EXTREME ENVIRONMENT

LED



createchange

### FEATURES

- High efficacy LED in choice of lumen packages
- Available in narrow or wide distribution
- Long-life, 60,000 hour LEDs at L80 (projected over 150,000 hours) for reduced life cycle maintenance costs
- IP65, IP66, and IP67 standard
- 1500 PSI High Pressure Hose down rating
- UL Sanitation Certified per NSF Standards
- 5VA (f1) fire rated materials
- Fiberglass housing with F1 weatherability rating, standard
- Lens firmly secured with tamper resistance ready latches
- Lens is tethered and gear tray hinges for ease of maintenance
- Drivers include minimum 6kV surge protection
- Pour-in-place gasket and cam latches seal enclosure
- Quick and simple hanging systems include v-hook (standard); optional rigid or flexible surface mount brackets
- Frost or clear acrylic lens, impact modified to 100% DR equivalency
- -20°C up to +45°C ambient operation; see table provided for details
- DLC® (DesignLights Consortium) Qualified, with some Premium Qualified configurations - see [www.designlights.org](http://www.designlights.org)
- Five year warranty (Terms & Conditions apply)

 

### ORDERING INFORMATION

<b>LXEW</b>	<b>4</b>					
MODEL	COLOR TEMP	LENS	DISTRIBUTION	VOLTAGE	OPTIONS	
LXEW Industrial Enclosed & Gasketed LED High Bay	30 3000K 35 3500K 40 4000K 50 5000K	FA Frost Impact Resistant Acrylic (std.) CA Clear Impact Resistant Acrylic CP Clear UV Stabilized Polycarbonate	N Narrow Distribution W Wide Distribution	U 120V-277V 347 347V <sup>1</sup> 480 480V <sup>1</sup>	GLR Fast Blow Fuse SSL Stainless Steel Tamper Resistant Ready Latches TP Tamper Proof Latches ELL14 Emergency Battery Pack Installed, 1400 Lumens <sup>2,3</sup> F3C8W 3 Wire 8' Wet Cord F3C15W 3 Wire 15' Wet Cord F4C8W 4 Wire 8' Wet Cord F4C15W 4 Wire 15' Wet Cord F5C8W 5 Wire 8' Wet Cord F5C15W 5 Wire 15' Wet Cord F6C6W 6 Wire 6' Wet Cord SWH Single Wet Hub ½" NPT Hub DWH Dual Wet Hub ½" NPT Hub	
SIZE	LUMEN OUTPUT	DRIVER				
4 4'	L Low Watt M Medium Lumen MH Medium High Lumen H High Lumen HV High Very High Lumen V Very High Lumen X Extra High Lumen	E Fixed Output ED 0-10V Dimming				

### ACCESSORIES (ORDER SEPARATELY)

- LHVQM5** Aircraft Cable, 5' (Pair)
- LHVQM10** Aircraft Cable, 10' (Pair)
- XEWMHSS** Mounting Strap Hardware Kit, Stainless Steel
- XEWRSBZN** Rigid Surface Mounting Bracket Kit, Zinc Plate
- XEWRSBSS** Rigid Surface Mounting Bracket Kit, Stainless Steel
- XEWFSBSS** Surface Mounting Bracket Kit, Stainless Steel

<sup>1</sup> Not available with V and X packages  
<sup>2</sup> Not Available with 347V/480V  
<sup>3</sup> Not Available with HV, V, X lumen packages

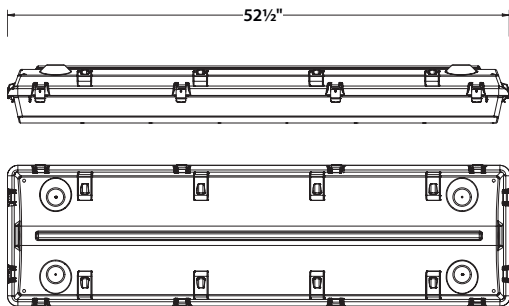

### PRODUCT AVAILABILITY

SIZE	LUMEN PACKAGE	NOMINAL LUMENS RANGE	NOMINAL WATTS	LUMENS/WATT	AMBIENT MAX. (UNIV. VOLTAGE)
4'	L	11,079 - 12,495	91	122 - 137	45
	M	15,349 - 16,539	122	126 - 136	45
	MH	16,580 - 18,689	138	121 - 136	45
	H	20,714 - 22,321	174	119 - 129	35
	HV	23,805 - 25,651	188	126 - 136	30
	V	29,040 - 32,557	260	112 - 126	30
	X	35,357 - 38,099	328	108 - 116	25

Lumens vary according to color temperatures and other factors. See specific photometric test(s).