

ALF

Linear LED Floodlight/Wall Mount



ALF-6LU



ALF-12LU

- ALF is excellent for small floodlighting applications such as signs, façade, landscape accent or small area illumination
- The compact, low profile size allows the flood to be easily hidden or blend into the landscape environment
- Knuckle mount: Universal 1/2" swivel knuckle has serrated teeth for sure aiming
- Wall mount: Cast aluminum cover/quick mount plate and universal adapter allows easy installation to 3 1/2 or 4" standard junction boxes; Tilt for increased forward throw
- Universal voltage driver is 120-277V, 50/60Hz
- Impact resistant tempered glass lens seals to housing with silicone gaskets
- Dark bronze durable powder paint finish
- Wide 6x5 NEMA beam spread covers three times the set back distance with uniform light
- Listed to UL 1598 for use in wet locations
ALF-6: IP65, ALF12: IP64w



tradeSELECT®

STOCK ORDERING INFORMATION

Catalog Number	System Watts	Number of LEDs	Voltage ¹	Delivered Lumens	Max Candle Power	CCT	Beam Pattern	# Drivers/Current	Weight lbs. (kg)	PKG. CODE
1/2" Knuckle Mount										
ALF-6LU-5K-BZ	10.2w	6	120-277V	1122	667	5000K	6 X 5	1@470mA	4.0 (1.8)	FCC
ALF-12LU-5K-BZ	20.9w	12	120-277V	2303	1395	5000K	6 X 5	2@470mA	8.0 (3.6)	FCC


¹ Unit should not be used above 240V in Canada

EQUIVALENCY INFORMATION

Series Number	Equivalency			Energy Savings
	MH	HPS	CFL	
ALF-6LU	70w	70w	26w	89%
ALF-12LU	100w	100w	42w	83%

ADDITIONAL ACCESSORIES ON PG. 214-217

DIMENSIONS

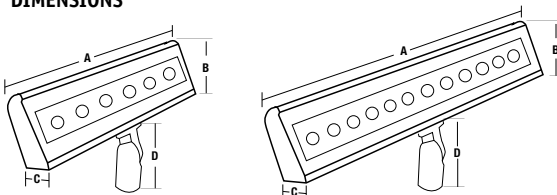

A	B	C	D
12/24"	3 1/2"	1 1/2"	3 1/2"
305/609.6 mm	89 mm	38 mm	89 mm