

Perimaliter® PGM3

Vertical Lamp Position Glass Refractor Wallpack

- Cast aluminum door with borosilicate glass refractor; Bottom hinge allows door removal; Twin HubbellGard® screw closure for positive seal
- Cast aluminum back housing provides firm mounting and heat dissipation; Mounts over recessed wiring boxes; Has two 1/2" conduit hubs for feed-through wiring. Top hub for field installation of photocontrol
- Specular aluminum reflector, vertical lamp and refractor prisms combine for excellent perimeter lighting; Provides 5 times spacing-to-mounting height
- PGM3 is 250w max
- Socket is porcelain medium base with spring-loaded center contact, for all offerings below 250w; 250w units are mogul base
- Bronze powder paint finish is standard, other finishes available, consult factory
- Listed to UL 1598 for use in wet locations



WALLPACKS



ORDERING INFORMATION

Catalog Number	Wattage	Lamp Type	Voltage	Ballast	Lamp Included/Base	Weight lbs. (kg)
Pulse Start Metal Halide						
PGM3-100P-18-BZ-L	100	PSMH	Quad Tap	HX-HPF	Yes/Med.	25 (11.3)
PGM3-150P-18-BZ	150	PSMH	Quad Tap	HX-HPF	No/Med.	25 (11.3)
PGM3-150P-18-BZ-L	150	PSMH	Quad Tap	HX-HPF	Yes/Med.	25 (11.3)
PGM3-250P-18-BZ	250	PSMH	Quad Tap	CWA-HPF	No/Mog.	27 (12.2)
PGM3-250P-18-BZ-L	250	PSMH	Quad Tap	CWA-HPF	Yes/Mog.	27 (12.2)
High Pressure Sodium						
PGM3-070S-18-BZ	70	HPS	Quad Tap	AL-HPF	No/Med.	23 (10.4)
PGM3-100S-18-BZ	100	HPS	Quad Tap	AL-HPF	No/Med.	24 (10.9)
PGM3-150S-18-BZ-L	150	HPS	Quad Tap	AL-HPF	Yes/Med.	25 (11.3)
Less Ballast						
PGM3-LB	250Max	None	None	None	No/Mog.	15 (6.8)

- Notes:
- L - Indicates lamp included with the fixture
 - Above units (-18) are Quad Tap (120,208,240,277V) 480V available on 150/250w units, change 8 to 5
 - For TriTap Canadian ballast (120,277,347V) change 8 to 6
 - BZ - Dark Bronze finish is standard; For alternate finish - consult factory for price adder and availability
 - BL - Black, GR - Gray, WH - White, PS - Platinum
 - 50HZ ballastry is available - consult factory

REPLACEMENT PART

Catalog Number	Description
80033990104	Lens door assembly, bronze


ACCESSORIES - Order Separately

Catalog Number	Description
PBT-1	Photocontrol, button type, 120V
PBT-234	Photocontrol, button type, 208, 240, 277V
PG-PS ¹	Polycarbonate shield for refractor
PG-WG ¹	Wire guard for refractor
PVL3V	Full cut-off visor, formed aluminum, bronze finish

¹ Guard and shield can be used on the same fixture

OPTIONS - Add Suffix

Catalog Number	Description
-EM	Double contact socket for remote power (less lamp) all units
-QSS	Quartz restrike system including relay (less lamp) all units (double contact bayonet socket)
-UST	Substantially transformed version in the U.S. meeting level 2 of the Buy American Act

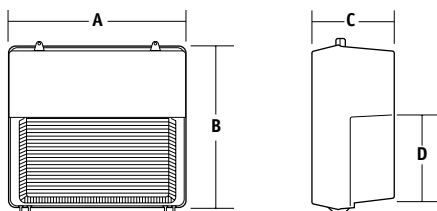

	A	B	C	D
PGM3	14 7/8"	15"	8"	6 13/16"
	378 mm	381 mm	203 mm	173 mm