

# SG1

## SLING Wall/Flood

Slender wallpack/floodlight available in two sizes for a variety of applications including: building perimeter/security lighting, entrances, stairways, loading docks or facades for schools, apartments or commercial buildings.

- Die-cast aluminum housing with corrosion resistant powder coat finish
- SG1 – Replaces 70w-150w HID
- 120V-277V, 50/60HZ, 347V and 480V available in SG2 housing
- Available in 3000K, 4000K and 5000K CCT
- 4 x 1/2" threaded conduit hubs for surface conduit
- Mounts to 4" junction boxes

- Stock versions include 120-277V PC with a cover offering choice to engage PC or not. PC is installed in top hub.
- IP65 and listed to UL1598 for use in wet locations
- DesignLights Consortium® (DLC) qualified. Please refer to the DLC website for specific product qualifications at [www.designlights.org](http://www.designlights.org)
- Listed for -40°C to 40°C applications
- PC option available, see below
- Diffused comfort lens provides glare control and improved uniformity. Available as an option or accessory



tradeSELECT®



LED WALLPACKS

### STOCK ORDERING INFORMATION

Catalog Number	CCT/CRI	Wattage	Mounting Height	Voltage	Color	Lumens	LPW	Weight lbs. (kg)
SG1-10-PCU	5000K/70	11W	8-12ft	120-277V	Dark Bronze	1349	122	4.3 (2)
SG1-10-4K-PCU	4000K/70					1424	129	
SG1-20-PCU	5000K/70	21w	8-12ft			2263	108	
SG1-20-4K-PCU	4000K/70					2310	110	
SG1-30-PCU	5000K/70	29w	10-15ft			3270	113	
SG1-30-4K-PCU	4000K/70					3060	105	
SG1-40-PCU	5000K/70	38w	10-15ft			4008	105	
SG1-40-4K-PCU	4000K/70					4070	106	

### MADE-TO-ORDER ORDERING INFORMATION



FAMILY	CCT/CRI	DISTRIBUTION	VOLTAGE	COLOR/FISH	CONTROL OPTIONS	OPTIONS
SG1-10 Size 1, 10w	3K7 3000K, 70 CRI	FT Fwd Throw	UNV 120V-277V	DB Textured Dark Bronze	PCU Button Photocontrol 120-277V	CS Comfort lens
SG1-20 Size 1, 20w	4K7 4000K, 70 CRI			BL Textured Black		
SG1-30 Size 1, 30w	5K7 5000K, 70 CRI			WH Textured White		
SG1-40 Size 1, 40w				GYS Smooth Gray		
				PS Smooth Plat. Silver		
				CC Custom Color		

### STOCK ACCESSORIES - Order separately


Catalog Number	Description	Weight lbs. (kg)
SG1-CS	Acrylic comfort lens for SG1	1 (.45)
SG1-YOKE	SG1 Series Yoke/Floodlight mount kit, includes visor	2.0 (1.0)
SG1-KNUCKLE	SG1 Series Knuckle/Floodlight mount kit, includes visor	2.0 (1.0)
SCP-REMOTE*	Remote control for SCP option. Order at least one per project to program and control fixtures	1 (.45)
SG1-SPC	Vandal Resistant Lens (shield polycarbonate), SG1	3 (1.5)
SG1-WCP	Universal Wall Cover Plate, Dark Bronze, SG1	10 (5)

\*Must order minimum of one remote control to program dimming settings, 0-10V fully adjustable dimming with automatic daylight calibration and different time delay settings, 120V or 277V only

### PERFORMANCE INFORMATION

Series Number	Equivalency			Energy Savings
	MH	HPS	CFL	
SG1-20	100W	100W	2x32W	84%
SG1-30	150W	150W	2x42W	84%

### DIMENSIONS

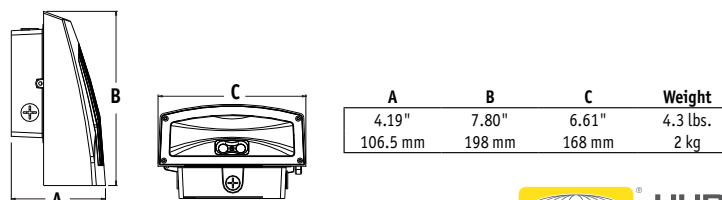

HUBBELL Outdoor Lighting