

SLING Wall/Flood

Slender wallpack/floodlight available in two sizes for a variety of applications including: building perimeter/security lighting, entrances, stairways, loading docks or facades for schools, apartments or commercial buildings.

- Die-cast aluminum housing with corrosion resistant powder coat finish
- SG2 – Replaces 150w-250w HID
- 120V-277V, 50/60HZ, 347V and 480V available in SG2 housing
- Available in 3000K, 4000K and 5000K CCT
- 4 x 1/2" threaded conduit hubs for surface conduit
- Mounts to 4" junction boxes

- Stock versions include 120-277V PC with a cover offering choice to engage PC or not; PC is installed in top hub.
- IP65 and listed to UL1598 for use in wet locations
- DesignLights Consortium® (DLC) qualified. Please refer to the DLC website for specific product qualifications at www.designlights.org
- Listed for -40°C to 40°C applications
- PC, occupancy sensor, wireless control and battery backup options available, see below.
- Diffused comfort lens provides glare control and improved uniformity. Available as an option or accessory



tradeSELECT®

LED WALLPACKS

STOCK ORDERING INFORMATION

Catalog Number	CCT/CRI	Wattage	Mounting Height	Voltage	Color	Lumens	LPW	Weight lbs. (kg)
SG2-50-PCU	5000K/70	51w	12-18ft	120-277V	Dark Bronze	5548	110	11 (5)
SG2-50-4K-PCU	4000K/70					5526	109	
SG2-80-PCU	5000K/70	80w	15-25ft			8061	101	
SG2-80-4K-PCU	4000K/70					8079	101	

MADE-TO-ORDER ORDERING INFORMATION



FAMILY	CCT/CRI	DISTRIBUTION	VOLTAGE	COLOR/FISH	CONTROL OPTIONS	OPTIONS
SG2-50 Size 2, 50w	3K7 3000K, 70 CRI	FT Fwd Throw	UNV 120V-277V	DB Textured Dark Bronze	PCU Button Photocontrol 120-277V	CS Comfort lens
SG2-80 Size 2, 80w	4K7 4000K, 70 CRI 5K7 5000K, 70 CRI		120 120V	BL Textured Black	SCP ^{1,2,3} Sensor Control, Programmable	E ^{1,2} Battery 0°C
			208 208V	WH Textured White	SWP ^{1,2} SiteSync, Precommission	EH ^{1,2} Battery w/ heater -20°C
			240 240V	GYS Smooth Gray	SWPM ^{1,2} SiteSync, Precommission, Motion	
			277 277V	PS Smooth Plat. Silver	Specify MTG HT for SC & SWPM	
			UHV 347-480V	CC Custom Color	8F Up to 8'	20F Up to 20'

¹ Available in SG2 only, UHV available in SG2-50 only

² Sensor controls & battery backup can not be used with flood accessory or kit or for inverted/up mounting, 120-277V only for SCP/SC, 120 or 277 only for SWP, SWPM, E & EH

³ Must order minimum of one remote control to program dimming settings, 0-10V fully adjustable dimming or on/off with automatic daylight calibration and different time delay settings, 120-277V only, PCU option not applicable

STOCK ACCESSORIES - Order separately


Catalog Number	Description	Weight lbs. (kg)
SG2-CS	Acrylic comfort lens for SG2	1 (.45)
SG2-YOKE	SG2 Series Yoke/Floodlight mount kit, includes visor	2.0 (1.0)
SG2-KNUCKLE	SG2 Series Knuckle/Floodlight mount kit, includes visor	2.0 (1.0)
SCP-REMOTE*	Remote control for SCP option. Order at least one per project to program and control fixtures	1 (.45)
SG2-PMA-3-XX	3" Pole Mount adapter for SG2, both square and round, XX= finish	7 (3.5)
SG2-PMA-4-XX	4" Pole Mount adapter for SG2, both square and round, XX= finish	7 (3.5)
SG2-PMA-5-XX	5" Pole Mount adapter for SG2, both square and round, XX= finish	7 (3.5)
SG2-PMA-6-XX	6" Pole Mount adapter for SG2, both square and round, XX= finish	7 (3.5)
SG2-SPC	Vandal Resistant Lens (shield polycarbonate), SG2	3 (1.5)
SG2-WCP-H	Horizontal Mount Wall Cover Plate, Dark Bronze, SG2	10 (5)
SG2-WCP-V	Vertical Mount Wall Cover Plate, Dark Bronze, SG2	10 (5)
SG2XL-WCP-H	Horizontal Mount Wall Cover Plate, DB, SG2 with battery or sensor	10 (5)
SG2XL-WCP-V	Vertical Mount Wall Cover Plate, DB, SG2 with battery or sensor	10 (5)

*Must order minimum of one remote control to program dimming settings, 0-10V fully adjustable dimming with automatic daylight calibration and different time delay settings, 120V or 277V only

PERFORMANCE INFORMATION

Series Number	Equivalency			Energy Savings
	MH	HPS	CFL	
SG2-50	175W	150W	2x42W+	75%
SG2-80	250W	250W	2x42W+	75%

DIMENSIONS

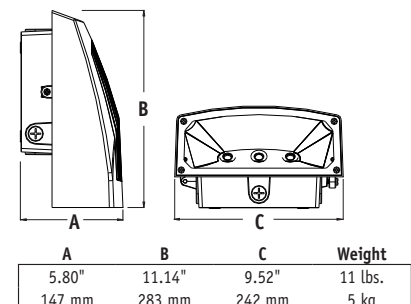

HUBBELL Outdoor Lighting