

INTERCEPT® VFS

Flood

FLOODLIGHTING



IP65

INTERCEPT® VFS is designed for exterior sports lighting with superior high output, high efficiency and available in a variety of NEMA distributions. Utilizing low glare LED optics, the INTERCEPT® provides the highest level of uniformity and illumination needed for playing surfaces and minimizes wasted light typically emitted by traditional sources.

- Scalable LED modules allow for an optimized configuration for various lumen output targets
- Low glare shields provide industry leading glare reduction with minimal effect on light output
- Luminaire rests in heavy duty yoke to

allow for both horizontal and vertical adjustment

- Dynamic thermal management design that maximizes heat dissipation, substantially increasing life of the luminaire
- Three lumen packages with up to 90,000 lumens
- Listed to UL1598 for use in wet locations
- Certified up to 25°C Ambient Operation

MADE-TO-ORDER ORDERING INFORMATION



SERIES	MOUNT	ENGINE-WATTS	CCT	DISTRIBUTION	VOLTAGE	CORD	CONTROL OPTIONS	OPTIONS
VFS	Y Yoke	63L-440 440w, 45,000 lm	3K7 3000K, 70 CRI	2 2x2	277 277V	3C 3' Prewired SEOWA cord	CD Continuous dimming	LGC Less Glare Control
	UMY Under Mount Yoke	84L-660 660w, 60,000 lm	4K7 4000K, 70 CRI	3 3x3	347 347V	6C 6' Prewired SEOWA Cord	SWP SiteSync pre-Comm	SF Single Fuse
		126L-880 880w, 90,000 lm	5K7 5000K, 70 CRI	4 4x4	480 480V	12C ² 12' Prewired SEOWA Cord	SWF SiteSync field-Comm	DF Double Fuse
			4K8 4000K, 80 CRI	5 5x5			NXWE NX Fixture Module	GL Glass Lens
			5K8 5000K, 80 CRI	AV Aviation Optics ¹			DMX DMX/RDM	
			57K8 5700K, 80 CRI					
			4K9 4000K, 90 CRI					
			5K9 5000K, 90 CRI					
			57K9 5700K, 90 CRI					



¹ Includes glass lens
² 12' cord is default option

ACCESSORIES (ORDER SEPARATELY)

Accessories	
VFSVISOR	Top Visor
Control Accessories	
SWUSB*	SiteSync interface software loaded on USB flash drive for use with owner supplied PC (Windows based only). Includes SiteSync license, software and USB radio bridge node
SWTAB*	Windows tablet and SiteSync interface software. Includes tablet with pre loaded software, SiteSync license and USB radio bridge node.
SWBRG	SiteSync USB radio bridge node only. Order if a replacement is required or if an extra bridge node is requested.

* When ordering SiteSync at least one of these two interface options must be ordered per project.
 + If needed, an additional Bridge Node can be ordered.

DIMENSIONS

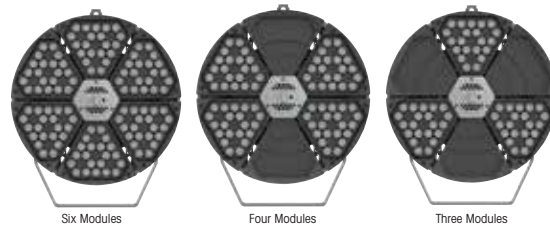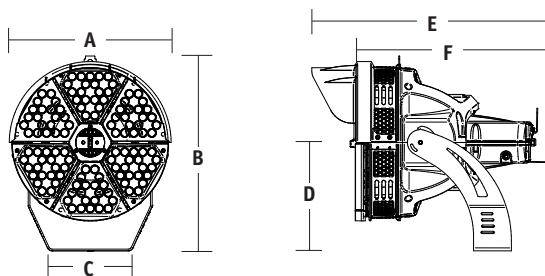

A	B	C	D	E	F	Weight	EPA
23.5"	28.3"	12.0"	15.6"	32.66"	26.32	100 lbs.	4.2
597 mm	719 mm	305 mm	401 mm	812 mm	668 mm	45 kg	Ft. ²

EPA without visor 3.9

