

KLVL716/KLVL711

Scarab Accent Lighting

LANDSCAPE



FEATURES

- LED light sources with sealed light engine
- Narrow flood distributions for accent lighting
- The Scarab series combines integrated design and application flexibility to produce a landscape accent system that meets the broadest range of illumination needs
- Unique swivel mount provides superior aiming without loosening over time
- Available in aluminum finish for excellent value and rugged service, or brass offering long life and natural weathering to blend into landscape




ORDERING INFORMATION (Example)

KLVL716	3L3K	VG	AGS71	JBR-2	
BRASS FIXTURE		FIXTURE FINISH	FIXTURE OPTIONS	MOUNTING OPTIONS	
KLVL716* Narrow Flood		BRASS	3 LED	12 VOLT MOUNTING OPTIONS	
ALUMINUM FIXTURE		NB Natural Brass	HL71 Hex Cell Louvers ^{1,2}	EP17 Landscape Light Post Mount	KLV432 #8-2 12 Volt Cable
KLVL711* Narrow Flood		VG Verde Green Patina	SL71 Spread Lens ^{1,3}	KLV400 Low Voltage Spear Mount	KLV600 200W Above-grade Transformer
		ALUMINUM	PL71 Prismatic Lens ^{1,3}	KLV405 Low Voltage Surface Mount	KLV605 300W Above-grade Transformer
		BL Black	AGS71 Adjustable Glare Shield ^{4,5}	KLV410 Sealed Connector	KLV625 900W Above-grade Transformer
		DB Dark Bronze	FGS71 Full Glare Shield ^{4,5}	KLV415 Extension Module	KLV640 300W Below-grade Transformer, 120V
		GR Verde Green	DS71 Debris Screen for Full Glare Shield		KLV660 300W Below-grade Transformer, 277V
					KLV645 600W Below-grade Transformer, 120V
					KLV665 600W Below-grade Transformer, 277V
ELECTRICAL MODULE 12V					
Source	Color Temperature				
3 LEDs, 10W	3K 3000K				
	4K 4000K				
	5K 5000K				

¹ Inserts behind lens into existing lens gasket.
² Cannot be used in combination with SL Spread or PL
³ Prismatic Lens.
 Cannot be used in combination with HL Hex Cell Louver.
⁴ Finished to match fixture.
⁵ Replaces standard lens ring/hood on fixture.

*Dimmable driver

SCARAB ACCENT LIGHTING

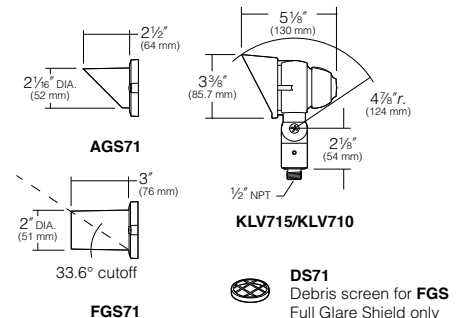

DS71
Debris screen for FGS Full Glare Shield only

C700/EL700

Scarab Accent Lighting

FEATURES

- LED light sources with sealed light engine
- Spot illumination for dramatic lighting, narrow flood distributions for accent lighting
- The Scarab series combines integrated design and application flexibility to produce a landscape accent system that meets the broadest range of illumination needs
- Unique swivel mount provides superior aiming without loosening over time
- Available in aluminum finish for excellent value and rugged service, or brass offering long life and natural weathering to blend into landscape



LANDSCAPE


ORDERING INFORMATION (Example)

C700S3	7L3K	-	VG	AGS73	JBR-2
BRASS FIXTURE		FIXTURE FINISH		FIXTURE OPTIONS	
C700S3 350mA Spot		BRASS		7 LED	
C700F3 350mA Narrow Flood		NB Natural Brass		AGS72 Adjustable Glare Shield ^{1,2}	
ALUMINUM FIXTURE		VG Verde Green Patina		FGS72 Full Glare Shield ^{1,2}	
EL700S3 350mA Spot		ALUMINUM		DS72 Debris Screen for Full Glare Shield	
EL700F3 350mA Narrow Flood		BL Black		9 LED	
		DB Dark Bronze		AGS73 Adjustable Glare Shield ^{1,2}	
		GR Verde Green		FGS73 Full Glare Shield ^{1,2}	
				DS73 Debris Screen for Full Glare Shield	
				12 LED	
				AGS74 Adjustable Glare Shield ^{1,2}	
				FGS74 Full Glare Shield ^{1,2}	
				DS74 Debris Screen for Full Glare Shield	
ELECTRICAL MODULE		VOLTAGE		MOUNTING OPTIONS	
Source	Color Temperature	UV Universal Voltage from 120 to 277V with a ±10% tolerance		120 VOLT MOUNTING OPTIONS	
7L 7 LEDs, 9W	3K 3000K			EP17 Landscape Light Post Mount	JBR-24 Brass in-grade J-box (4) 1/2" NPT in sides, (2) 1/2" NPT in bottom
9L 9 LEDs, 11W	4K 4000K			JB1 Architectural J-box ²	JBR-30 Brass in-grade staked J-box
12L 12 LEDs, 14W	5K 5000K			J-25N Portable Spear Mount ²	JBR-32 Brass in-grade staked J-box with cord
				JBR-2 Brass in-grade J-box (2) 1/2" NPT in bottom	SM18 Stanchion Mount ²
				JBR-3 Brass in-grade J-box (2) 3/4" NPT in bottom	J-27N Surface Mount ²
				JBR-21 Brass in-grade J-box (2) 1/2" NPT in sides, (2) 1/2" NPT in bottom	JWBR Brass Architectural Wall Mount ²


¹ Replaces standard lens ring/hood on fixture.
² Finish to match fixture. Specify finish, **BL** - Black, **DB** - Dark Bronze, **GR** - Verde Green.

SCARAB ACCENT LIGHTING

**C700/7L
EL700/7L**

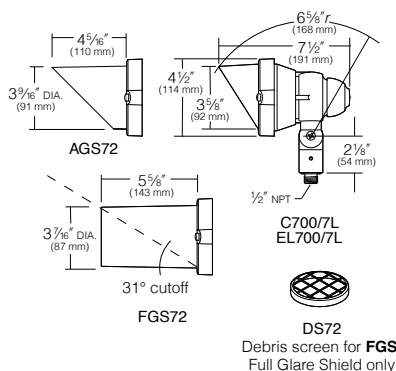

**C700/9L
EL700/9L**

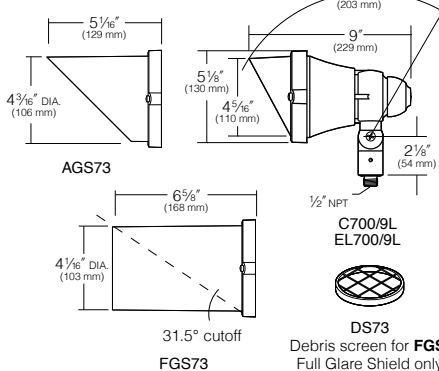

**C700/12L
EL700/12L**

