


Center-Lens Troffer

FEATURES

- 3,300 - 5,000 nominal lumens
- Up to 118 lumens per watt
- 3500k and 4000k
- 0-10V dimming, standard
- Fully assembled for quick installation
- Frosted acrylic lens
- Recessed mount
- Universal voltage (120-277V)
- 80+ CRI
- IC rated
- >54,000 hour LEDs at L70 for reduced maintenance
- Emergency battery backup available
- 5-Wire Flex available
- DLC® (DesignLights Consortium) Qualified - see www.designlights.org

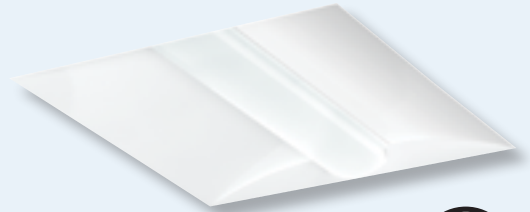

tradeSELECT™



ORDERING INFORMATION

CATALOG NUMBER	DESCRIPTION	LUMENS	WATTS	LPW	QTY ON PALLET
CCL22-3335	2 x 2 Center Lens LED Troffer, 3,300 Lumens, 3500K				
CCL22-3335-C588	2 x 2 Center Lens LED Troffer, 3,300 Lumens, 3500K, 5-Wire Flex ¹	3223	28.9	112	40
CCL22-3335-ELL14	2 x 2 Center Lens LED Troffer, 3,300 Lumens, 3500K, Emergency Battery Pack ¹				
CCL22-3340	2 x 2 Center Lens LED Troffer, 3,300 Lumens, 4000K				
CCL22-3340-C588	2 x 2 Center Lens LED Troffer, 3,300 Lumens, 4000K, 5-Wire Flex ¹	3345	28.9	116	40
CCL22-3340-ELL14	2 x 2 Center Lens LED Troffer, 3,300 Lumens, 4000K, Emergency Battery Pack ¹				
CCL24-5035	2 x 4 Center Lens LED Troffer, 5,000 Lumens, 3500K				
CCL24-5035-C588	2 x 4 Center Lens LED Troffer, 5,000 Lumens, 3500K, 5-Wire Flex ¹	5001	43.9	114	20
CCL24-5035-ELL14	2 x 4 Center Lens LED Troffer, 5,000 Lumens, 3500K, Emergency Battery Pack ¹				
CCL24-5040	2 x 4 Center Lens LED Troffer, 5,000 Lumens, 4000K				
CCL24-5040-C588	2 x 4 Center Lens LED Troffer, 5,000 Lumens, 4000K, 5-Wire Flex ¹	5191	43.9	118	20
CCL24-5040-ELL14	2 x 4 Center Lens LED Troffer, 5,000 Lumens, 4000K, Emergency Battery Pack ¹				

¹ Not stocked; ships in 5-10 days

Accessories (Order Separately)

FK22	2' x 2' Single Flange Kit (Shipped separately)
FK24	2' x 4' Single Flange Kit (Shipped separately)

DIMENSIONS

